

## LED STEP & WALL LIGHTS

**P6827** and **P6828** LED step/wall lights are available in a vertical or horizontal configuration for mounting into a single-gang wallbox

- cCSAus listed for wet locations
- Integral power supply module in a compact package
- Consumes less than 5w of power per fixture
- Warm white 3000K LED's included
- CRI: 84+
- Beam spread: 120 degrees



P6827-0930K



P6828-0930K



P6827-3030K




P6828-3030K

Product No.	Finish	Description	Size	Lamp
<b>P6827-0930K</b>	Brushed Nickel	Mini horizontal step/wall light	4-13/16" W.	4w LED, included.
<b>P6827-3030K</b>	White	Mini horizontal step/wall light	3" ht.	
<b>P6828-0930K</b>	Brushed Nickel	Mini vertical step/wall light	3" W.	4w LED, included.
<b>P6828-3030K</b>	White	Mini vertical step/wall light	4-13/16" ht.	

**P6829** and **P6832** LED step/wall lights provide an attractive solution for a variety of illumination tasks

- cCSAus listed for outdoor as well as indoor applications
- Integral power supply module in a compact package
- Consumes less than 4w of power per fixture
- Warm white 3000K LED's included
- CRI: 84+
- Beam spread: 120 degrees

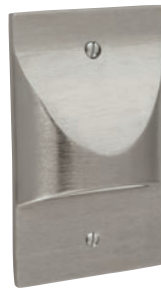

P6829-0930K



P6829-2030K



P6829-3030K



P6829-3130K



P6832-0930K



P6832-3130K

Product No.	Finish	Description	Size	Lamp
<b>P6829-0930K</b>	Brushed Nickel	Mini vertical step/wall light	3" W.	4w LED, included.
<b>P6829-2030K</b>	Antique Bronze	Mini vertical step/wall light	4-3/4" ht.	
<b>P6829-3030K</b>	White			
<b>P6829-3130K</b>	Black			
Product No.	Finish	Description	Size	Lamp
<b>P6832-0930K</b>	Brushed Nickel	Mini vertical step/wall light	4-3/4" W.	4w LED, included.
<b>P6832-2030K</b>	Antique Bronze	Mini vertical step/wall light	3" ht.	
<b>P6832-3030K</b>	White			
<b>P6832-3130K</b>	Black			

U.S. Patent #.  
6357891, 5379199