

Small partitions

Small partitions type TSch

Partitions can be retrofitted between the cross-connections or the sockets for terminals up to max. 12 mm.



Type	Cat. No.	Qty.
TSch 1	0319160000	100

For use between fixed cross-connections with differing potentials for terminal types: SAK 2.5...SAK 16 and DK 4.



Type	Cat. No.	Qty.
TSch 2	0353660000	100

For use between removable cross-connections with differing potentials for terminal types: SAK 4...16 and disconnect test terminals SAKT and WTL 6/1



Type	Cat. No.	Qty.
TSch 2 (orange)	0132460000	100
TSch 3	0366860000	100

with cut-out for SAKT 2
For use with terminal type SAKD 2.5 N



Type	Cat. No.	Qty.
TSch 4	0363360000	100

For terminal types: AKZ 4, AKB 4, AK 4, DK 4 and DKB 4/10



Type	Cat. No.	Qty.
TSch 6	0190260000	100


For terminal types: DK 4 S, DK1 4, DKIS 4 and DKIT 4

Partitions

WTW/TW

Depending on the operating voltage, a partition may be needed between neighbouring cross-connection groups. This is essential to maintain creepage and clearance distances.

For some terminals we supply partitions in tropical-grade cardboard (HP 020628). Partitions in cardboard type 020610 are available on request.

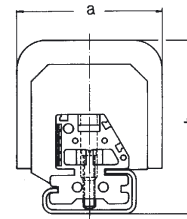

EExi



Assembly on TS 35/TS 32

Cat. No.	Material	Thick.	a b b (Dimensions in mm)			for terminal type
			TS 32	TS 35	W-Reihe/EExi	
1058800000	WEMID	3	80	63	63	SAK 2.5...16/EExi
0302820000	KrG	2.5	50	59.5	50	SAK 2.5
0302830000	KrS	2.5	50	59.5	50	SAK 2.5
0302860000	PA	1.5	50	59.5	50	SAK 2.5
0130120000	KrG	2.5	50	59.5	52	SAK 4, 6 N, 10
0130130000	KrS	2.5	50	59.5	52	SAK 4, 6 N, 10
0130160000	PA	1.5	50	59.5	52	SAK 4, 6, 10
0281120000	KrG	3	60	65.5	-	SAK 4, 6 N, 10
0281130000	KrS	3	60	65.5	-	SAK 16
0303660000	PA	1.5	58	67	60.5	SAK 16
0304320000	KrG	3	74	75.5	68	SAK 35, 35 N
0304330000	KrS	3	74	75.5	-	SAK 35, 35 N
0304360000	PA	1.5	74	75.5	68	SAK 35, 35 N
0242920000	KrG	3	75	58.5	54.5	SAKB 10, C 10
0242960000	PA	1.5	75	58.5	54.5	SAKB 10, C 10
0191860000	PA	1.5	42.5	49	44	SAKD 2.5 N
1050100000	WEMID	1.5	51	-	63	WDU 2.5...10
0257120000	KrG	3	80	-	70	EExi, SAK 2.5...16
	KrS	3	80	-	70	EExi, SAK 2.5...16

Partitions in cardboard TW-HP

Cat. No.	Material	Thick.	a b b (Dimensions in mm)			for terminal type
			TS 32	TS 35	W-Reihe/EExi	
0307500000	HP T*	0.5	32.5	48.5	48.5	SAKD 2.5 N
0297100000	HP T*	1	50	54.5	54.5	SAK 2.5
0197100000	HP	0.5	40	57.5	57.5	SAK 4, SAK 6 N, SAK 10, AST 3, AST 4
0474700000	HP	0.5	65	62.6	62.6	AST 1/AST 5
0151400000	HP	2	120	75.6	75.6	SAKG 28
0164600000	HP T*	2	120	75.5	75.5	SAKG 32 II, SAKG 70
0177100000	HP	2	160	90.5	90.5	SAKG 32
0179900000	HP T*	2	160	90.5	90.5	SAKG 40, 46, 54 I + III
0369800000	HP T*	2	80	72.5	72.5	SAK 2.5
0369900000	HP	2	80	72.5	72.5	

between fused and non-fused circuits

Assembly on TS 15

0318560000	PA	1.5	32.5	34	34	AKZ 2.5, 2.5 K
0318580000	PA bl	1.5	32.5	34	34	AKZ 2.5, 2.5 K
0118930000	KrS	2	38	38	38	AKZ 4, AKB 4

T* = tropical grade

End plates

WAP/AP

With few exceptions, the last terminal in a row must be covered with a type WAP / AP end plate.

End plates must also be inserted in terminal strips with different sized terminals. The external dimensions of the end plates correspond to the outer dimensions of the respective terminals. The end plate is fixed by an end bracket.




Type	Cat. No.	Use with
WAP WDU 2.5 N	1060000000	WDU 2.5 N
WEMID		
WAP 2.5...10	1050000000	WDU 2.5...10
WEMID		
WAP 16 and 35	1050100000	WDU 16 and 35
WEMID		
WAP WDL 2.5/S	1067700000	WDL 2.5/S
WEMID		
WAP WDL WEMID	1067800000	WDL 2.5
WAP WTL	1068300000	WTL 6/1/WTD 6/1
WEMID		
WAP WDK	1059100000	WDK
WEMID		
AP	0150960000	SAKD 2.5 N
AP 2.5	KrG 0279520000	SAK 2.5 and TT
	PA 0279560000	KB 2.5/10,
	KrS 0279530000	SAK 2.5 L and LL
AP	KrG 0117920000	SAK 4, 6 N, 10, SAKC 4, NT 2, SLK 1, SAK 4 S and SS
	PA 0117960000	KB 4, 6 and 10
	KrS 0117930000	
AP 16	KrG 0271120000	SAK 16
	PA 0271160000	

Type	Cat. No.	Use with
AP 35	KrG 0303620000	SAK 35, 35 N
	PA 0303660000	
AP 70	KrG 0340920000	SAK 70
	PA 0340960000	
	KrS 0340930000	
AP 95	KrG 0550920000	SAK 95
AP 2.5	KrG 0309220000	SAK 2.5 L
AP	PA 0438560000	DK 4/380 Q
AP	KrG 0266420000	AST 1, 5 and 5 T
AP	KrG 0298120000	AST 3 and 4
AP	PA 0582560000	AST 6, TOP 2.5
AP	PA 0483460000	TOP 4 SF / FF
AP	KrG 0294420000	AKZ 4
AP	PA 0294460000	AKZ 4 S and SS, AKZ 4, AKZ 4 L and LL, AKZ 4 T
AP	KrG 0146720000	SAKT 1, SAKC 10, SAKB 10, SAKS 7
AP	KrG 0329120000	SAKT 2
AP	PA 0211360000	SAKR, SAKR-L, SAKR-D
AP	KrG 0134220000	SAKA 10
AP	KrG 0191320000	SAKS 1 and 3
AP	PA 0340560000	AKZ 1.5, AKZ 1.5 T
AP	PA 0329660000	AKZ 1.5 W
AP	KrS 0131730000	SAKH 6 - 10

End plates

EP end plates for SAKG

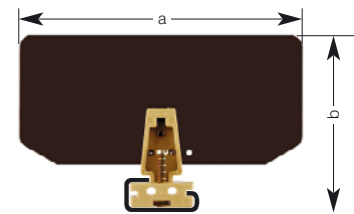

Cat. No.	Material	Thick.	Dimensions (mm)			for terminal types
			a	b	b	
Mounting on TS 32 rail						
0205100000	HP	2	120	75.5	75.5	SAKG 28, 32 II, 70
0205200000	HP T*	2	120	75.5	75.5	
0205300000	HP	2	160	90.5	90.5	SAKG 32 I + III,
0205400000	HP T*	2	160	90.5	90.5	40, 46, 54
Mounting on TS 35 rail						
0180500000	HP	2	120	75.5	75.5	SAKG 32 II, 70
0180600000	HP T*	2	120	75.5	75.5	
0180700000	HP	2	160	90.5	90.5	SAKG 32 I + III,
0180800000	HP T*	2	160	90.5	90.5	40, 46, 54

T* = tropical grade