

Terminal Blocks - W Series

W Series - Feed Through Terminal Blocks



WDU 2.5



WDK 2.5 ZQV

W Series - Ground Terminal Blocks




WPE 2.5



WDK 2.5PE

W Series - Fuse Terminal Blocks

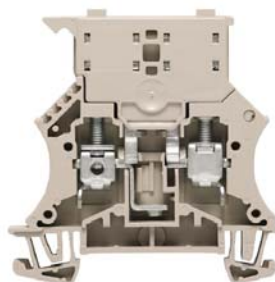

WSI 6

* Note: WSI 6 uses 5x20mm fuses
WSI 6/2 uses 1¼"x¼" fuses

Ratings/Width	Wire Range	Part Number	Description
600V/20A/5mm	26-12 AWG	102000000	WDU 2.5
600V/20A/6mm	26-10 AWG	102010000	WDU 4
600V/45A/8mm	20-8 AWG	102020000	WDU 6
600V/65A/10mm	16-6 AWG	102030000	WDU 10
600V/65A/12mm	14-6 AWG	102040000	WDU 16
600V/120A/16mm	12-2 AWG	102050000	WDU 35
600V/205A/27mm	6-2/0 AWG	102460000	WDU 70/95
600V/285A/32mm	2-250MCM	102450000	WDU 120/150
600V/400A/36mm	1/0-500MCM	180278000	WDU 240
300V/10A/5mm	26-12 AWG	102150000	WDK 2.5
300V/25A/5mm	26-12 AWG	104110000	WDK 2.5 ZQV
300V/10A/5mm	26-12 AWG	102230000	WDK 2.5V
300V/20A/5mm	26-12 AWG	104160000	WDK 2.5N
300V/20A/5mm	26-12 AWG	104161000	WDK 2.5NV
300V/30A/6mm	26-10 AWG	104190000	WDK 4N
300V/30A/6mm	26-10 AWG	104191000	WDK 4NV
600V/5mm	26-12 AWG	101000000	WPE 2.5
600V/6mm	26-10AWG	101010000	WPE 4
600V/8mm	20-8 AWG	101020000	WPE 6
600V/10mm	16-6 AWG	101030000	WPE 10
600V/12mm	14-6 AWG	101040000	WPE 16
600V/16mm	12-2 AWG	101050000	WPE 35
600V/27mm	6-2/0 AWG	103730000	WPE 70/95
600V/32mm	2-250MCM AWG	101970000	WPE 120/150
300V/5mm	26-12 AWG	103630000	WDK 2.5PE
300V/5mm	26-12 AWG	104162000	WDK 2.5N PE
300V/6mm	26-10 AWG	104192000	WDK 4N PE
300V/10A/8mm	20-8 AWG	101100000	WSI 6 *
300V/10A/8mm	20-8 AWG	101130000	WSI 6 LD 10-36VAC/DC *
300V/10A/8mm	20-8 AWG	101220000	WSI 6 LD 30-70VAC/DC *
300V/10A/8mm	20-8 AWG	101230000	WSI 6 LD 60-150VAC/DC *
300V/10A/8mm	20-8 AWG	101240000	WSI 6 LD 140-250VAC/DC *
300V/10A/12mm	20-8 AWG	101400000	WSI 6/2 *
300V/10A/12mm	20-8 AWG	101410000	WSI 6/2 LD 10-36VAC/DC *
300V/10A/12mm	20-8 AWG	101420000	WSI 6/2 LD 30-70VAC/DC *
300V/10A/12mm	20-8 AWG	101430000	WSI 6/2 LD 60-150VAC/DC *
300V/10A/12mm	20-8 AWG	101440000	WSI 6/2 LD 140-250VAC/DC *