





Shown actual size: Rotary dimmer and 1-gang Fassada wallplate in White (WH).



Product family features

- The original electronic dimmer— first patented in 1959
- Easy-turn knob adjusts light to your favorite level
- eco-dim® model available
- 100% factory tested
- Coordinating Fassada® and Stainless Steel wallplates only available separately
- Custom engraving available for wallplates, see pg. 164

Control types

-  Single-pole (one location)
-  3-way or 4-way (two or more locations)

Direct load type compatibility

-  Incandescent/halogen lighting
-  Ceiling fans

Lighting load interfaces are not compatible with this family.

[Download high resolution product image](#)

Available finishes

Use **BOLD** color code in model number (Example: D-600P-**IV**)

Gloss finishes*



WH
White



IV
Ivory

*Coordinating wallplates only available separately. For wallplate information, see pg. 175.

Dimmer with rotate on/off knob



- Rotate on/off; rotate to adjust light level

Dimmers with push on/off knob



- Push on/off; rotate to adjust light level
- **eco-dim®** model guarantees at least 15% energy savings and triples lamp life compared to a standard switch†

Incandescent/halogen dimmers

Dimmer with rotate on/off knob

Single-pole	D-600R- XX ¹
120V 600W	

Incandescent/halogen dimmers

Dimmers with push on/off knob

Single-pole	D-600P- XX ¹
120V 600W	
3-way	D-603P- XX ¹
120V 600W	

eco-dim® dimmer with push on/off knob†

3-way/single-pole	D-603PG- XX ¹
120V 600W	

XX¹: Gloss White (WH) and Ivory (IV), see pg. 118 (Wallplates not included. Order separately, see pg. 175)

All models must be derated if ganged unless otherwise noted, see pg. 179.

[†]Maximum light output of 85% guarantees 15% energy savings over standard switches.

Dimmers with push on/off knob and locator light



- Push on/off; rotate to adjust light level
- Includes locator light

Fan controls with rotate on/off knob



- Rotate on/off; rotate to adjust fan speed
- Quiet 3-speed available for use with one paddle fan
- Quiet 3-speed designed to prevent motor hum
- Fully variable models available for use with multiple paddle or exhaust fans

Incandescent/halogen dimmers

Dimmers with push on/off knob and locator light

Single-pole 120V 600W	DNG-600P- XX ¹
3-way 120V 600W	DNG-603P- XX ¹

Fan controls

Fan controls with rotate on/off knob—fully variable

Single-pole fan control factory set minimum speed 120V 5A	FS-5F- XX ¹
Single-pole fan control user adjustable minimum speed 120V 5A	FS-5E- XX ¹

Fan control with rotate on/off knob—quiet 3-speed

Single-pole 120V 1.5A	FSQ-2F- XX ¹
--------------------------	--------------------------------

Replacement knobs


Standard knob	RK- XX ¹
3-speed fan control knob, White	280-324-01
3-speed fan control knob, Ivory	280-324-06

XX¹: Gloss White (WH) and Ivory (IV), see pg. 118 (Wallplates not included. Order separately, see pg. 175)

All models must be derated if ganged, unless otherwise noted, see pg. 179.



Connections overview

Load connections*

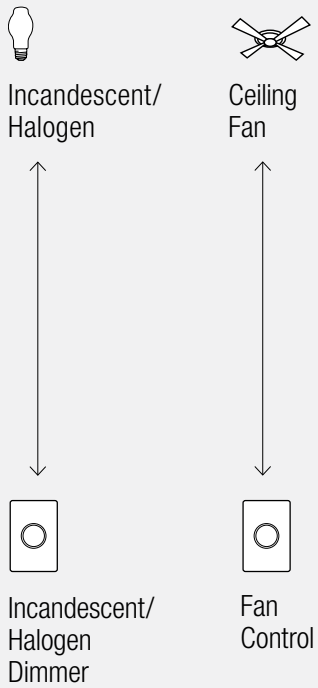

Control types (for 2 or more locations)

Dim from one location, switch from the others

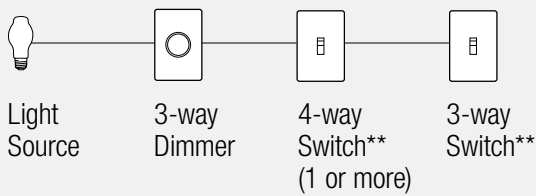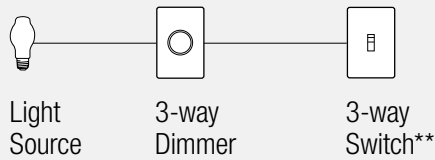

** For 3-way and 4-way control, use 3-way dimmer with mechanical 3-way or 4-way switches.

***For illustration purposes only.**
Consult model number pages for specific voltage and capacity information.

[Download complete Connection Diagrams](#)

Accessories

Wallplates

4.67 in (119 mm)



4.60 in (117 mm)

.23 in (5.8 mm) profile

Shown actual size: 2-gang Fassada® wallplate in White (WH).

For more information about Traditional wallplates, see pg. 175.

Coordinated electrical devices



Tamper resistant GFCI receptacle



Customizable 6-port frame



Cable jack

For more information about coordinated Designer electrical devices, see pg. 172.