

switches



- paddle turns on/off
- use with any 15A load
- general purpose switching of all sources and motor loads
- no derating if ganged

general purpose switches (120/277 V)

single pole	15A	CA-1PSH-	
		SC-1PS-	
3-way	15A	CA-3PSH-	
		SC-3PS-	
4-way	15A	CA-4PSH-	
		SC-4PS-	

general purpose switch with locator light

(120 V only)

single pole	15A	CA-1PSNL-	
		SC-1PSNL-	
3-way	15A	CA-3PSNL-	
		SC-3PSNL-	
4-way	15A	CA-4PSNL-	
		SC-4PSNL-	


colors & finishes key

- available in gloss finish
- available in satin finish
- available in all gloss and satin finishes

See page 85 for available colors.
To order, add color suffix to model number.
Example: **CA-1PSH- WH**

telephone and cable jacks

- 6-conductor telephone jack, RJ11
- F-style, 75-Ohm coaxial cable

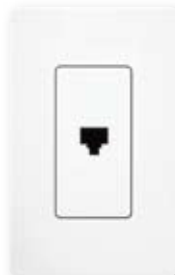

single telephone jacks

CA-PJH-	
SC-PJ-	

single cable jacks

CA-CJH-	
SC-CJ-	

receptacles and GFCI receptacles

- press test button to confirm LED indicator status
- press reset button to reset GFCI after circuit interruption



receptacles

15A, 125V	CAR-15H-	
	SCR-15-	
20A, 125V	SCR-20-	

tamper resistant receptacles

15A, 125V	CARS-15-TR-	
	SCRS-15-TR-	
20A, 125V	SCRS-20-TR-	

tamper resistant GFCI receptacles

15A, 125V	CAR-15-GFTR-	
	GFCI SCR-15-GFTR-	
20A, 125V	GFCI SCR-20-GFTR-	