

vallen

Working Smart Starts Here

BRADY

WHEN PERFORMANCE MATTERS MOST™

BMP21-PLUS PORTABLE LABEL PRINTER

Tough on the outside. Smart on the inside. The BMP21-PLUS portable label printer takes on the toughest labeling jobs in the field. Whether you're in a server room, servicing a breaker box or organizing your workplace, you can count on the BMP21-PLUS. With smart automatic formatting, all you need to do is drop a label cartridge in, type and print. It also takes advantage of Brady's reliable material offering wire makers, cable flags, all-purpose vinyl, self-laminating, nylon cloth - you name it. Finding the right label to get the job done is easy.

PART #	DESCRIPTION	PRICE
BRD BMP21-PLUS	BMP21-PLUS PRINTER	\$99.95 EA

**TOUGH
ON THE OUTSIDE
SMART
ON THE INSIDE**



BRADY CAUTION TAGS-ACCIDENT PREVENTION

PART #	DESCRIPTION	PRICE
BRD 76168	CAUTION TAGS 5.75X3" 25PK	\$30.88 PK
BRD 76171	DANGER TAGS BLANK 5.75X3" 25 PK	\$30.88 PK
BRD 65520	LOCKOUT TAGS BLANK 5.75X3" 25 PK	\$44.62 PK

ECONOMY GRADE BARRICADE TAPE

Ideal for temporary use outdoors or permanent indoor warning. Made of lightweight polyethylene (2 mm).

PART #	DESCRIPTION	PRICE
BRD 92303	CAUTION BLACK/YELLOW 3"X200'	\$7.92 EA
BRD 92320	DO NOT ENTER BLACK/RED 3"X200'	\$7.92 EA
BRD 92327	DANGER BLACK/RED 3"X200'	\$7.92 EA



Pricing in effect until September 30, 2016.
Prices do not include GST / PST / HST
Stock may vary by branch. Prices subject to change.

Safety | Industrial | Facilities Maintenance | Technical Services vallen.ca





3M™ SOLUS™ 1000 SERIES SAFETY SPECTACLES

Removable temple, soft nose bridge, optional elastic strap, padded temples, vented removable foam gasket to help reduce eye exposure

PART #	DESCRIPTION	PRICE
3MS S1101SGAF-KT	KIT - BLACK/BLUE FRAME CLEAR AF LENS	\$14.95 EA
3MS S1101SGAF	BLACK/BLUE FRAME CLEAR AF LENS	\$9.95 EA
3MS S1102SGAF	BLACK/BLUE FRAME GREY AF LENS	\$9.95 EA
3MS SOLUS-FOAM	FOAM GSKT REPLACEMENT	\$2.95 EA
3MS SOLUS-STRAP	REPLACEMENT STRAP	\$1.95 EA

SCOTCH® PROFESSIONAL GRADE VINYL ELECTRICAL TAPE SUPER 33+

Scotch® Vinyl electrical tape Super 33+ is a premium, 7 mil insulating tape.



PART #	DESCRIPTION	PRICE
3MT SUPER-33 PLUS	SCOTCH® PROFESSIONAL GRADE VINYL ELECTRICAL TAPE SUPER 33	\$5.49 EA

SCOTCH® HEAVY DUTY VINYL ELECTRICAL TAPE SUPER 88

Scotch® Vinyl electrical tape Super 88 is a premium grade, 8.5-mil thick, all-weather vinyl insulating tape.



PART #	DESCRIPTION	PRICE
3MT SUPER-88	SCOTCH® HEAVY DUTY VINYL ELECTRICAL TAPE SUPER 88	\$5.95 EA



Now Proudly part of 3M:



ULTRA-LOK™ SELF RETRACTING LIFELINE - CABLE

- Rugged and extremely lightweight thermoplastic housing
- Semi-sealed design
- 3/16" (5mm) galvanized steel cable lifeline
- Stainless steel dynamic components
- Internal energy absorption system
- Anti-ratcheting twin disk brake system
- Constant moving brake system pawls
- Swiveling anchorage point
- Swiveling snap hook with impact indicator



PART #	DESCRIPTION	PRICE
DBI 3504430C	30 FT CABLE	\$ 1153.91 EA
DBI 3504450C	50 FT CABLE	\$1433.64 EA



LAD-SAF™ FOR FIXED LADDER (BOLT-ON) - GALVANIZED

30 ft. (9.1 m) fixed ladder safety system, galvanized, top bracket with energy absorber, bottom bracket with tensioner, cable lifeline and guide(s), order safety sleeve separately.



PART #	DESCRIPTION	PRICE
DBI LADSAF-30	30 FT	\$567.06 EA
DBI 6160030	DETACHABLE CABLE SLEEVE	\$449.00 EA

DELTA™ VEST-STYLE CLIMBING HARNESS

Back and front D-rings, quick connect buckle leg straps

PART #	DESCRIPTION	PRICE
DBI 1102090C	HARNESS-SIZE UNIVERSAL	\$226.28 EA





FR LONG RAINCOAT

(A) Flame resistant long rain coat made of 0.35 mm FR treated PVC/ polyester/PVC. 100% waterproof - meets CGSB 155.20, 2000 Type 3. Zip and snap front placket. Detachable snap hood.

PART #	DESCRIPTION	PRICE
PIO 580-SIZE	RAINCOAT FR YELLOW SZ:S-4XL	\$13.95 EA

SUPPORTED PVC 3-PIECE RAIN SUIT

(B) 3 pieces: jacket, detachable hood and bib pant. .35 mm PVC/ polyester/PVC, 100% waterproof and windproof. JACKET: Vented back and underarms, 2 large front cargo pockets, zipper plus snap storm flap, welded seams, corduroy collar, detachable hood.

PART #	DESCRIPTION	PRICE
PIO 577-SIZE	RAINSUIT YELLOW SZ:S-4XL	\$17.95 EA

FR PU STRETCH HI-VIZ RAINCOAT

(C) FR treated 100% polyurethane/poly. Meets CGSB 155.20, 2000 Type 3. CSA Z96-09 Class 1 Level 2 and Class 1 Level FR. Oil and chemical resistant. 100% waterproof and windproof. Lightweight and tough 4-way stretch PU. StarTech™ FR reflective tape. Heat welded seams. Extra-large detachable hood. Full front zipper with snap closure storm flap. Sizes: S-5XL

PART #	DESCRIPTION	PRICE
PIO 5896-SIZE	RAINCOAT FR HI-VIZ ORANGE SZ:S-4XL	\$125 EA



FR PU STRETCH HI-VIZ RAIN JACKET

(D) FR treated 100% polyurethane/poly. Meets CGSB 155.20, 2000 Type 3. CSA Z96-09 Class 1 Level 2 and Class 1 Level FR. Oil and chemical resistant. 100% waterproof and windproof. Lightweight and tough 4-way stretch PU. StarTech™ FR reflective tape. Heat welded seams, extra-large detachable hood, full front zipper with snap storm flap.

PART #	DESCRIPTION	PRICE
PIO 5892-SIZE	JACKET HI-VIZ ORANGE SZ:S-4XL	\$82.50 EA

FR PU STRETCH HI-VIZ RAIN BIB PANT

(E) FR treated 100% polyurethane/poly. Meets CGSB 155.20, 2000 Type 3. CSA Z96-09 Class 1 Level 2 and Class 1 Level FR when worn with 5892. Oil and chemical resistant. 100% waterproof and windproof. Lightweight and tough 4-way stretch PU. StarTech™ FR reflective tape. Heat welded seams, heavy-duty suspenders with quick-release clips, adjustable waist with snaps. Sizes: XS-7XL.

PART #	DESCRIPTION	PRICE
PIO 5893-SIZE	OVERALL HI-VIZ ORANGE SZ:S-4XL	\$61.18 EA

Energizer®



ENERGIZER® INDUSTRIAL ALKALINE BATTERIES

Industrial alkaline batteries offer the longest lasting power source of all primary batteries over a range of sizes. No mercury added. Special disposal is not required. Operate well in temperature extremes (-180 to 550 °C). Excellent shelf life - up to 10 years of storage.

PART #	DESCRIPTION	PRICE
EVR EN22	ALKALINE 9V	\$1.89 EA
EVR EN91	ALKALINE 1.5V AA	\$0.59 EA
EVR EN92	ALKALINE 1.5V AAA	\$0.59 EA

PART #	DESCRIPTION	PRICE
EVR EN93	ALKALINE 1.5V C	\$0.99 EA
EVR EN95	ALKALINE 1.5V D	\$1.29 EA

LX

SMALL IS THE NEW HUGE

- ▶ Award winning pocket-sized design
- ▶ Quick Free-Chain and Hook Positioning
- ▶ Huge Durability and Performance.

The essential professional grade tool, for any tool box.
Get your LX lever hoist today!

UNMATCHED
PRECISION
PLACEMENT



OPTIONAL
CARRYING CASE



KITO

CONTACT YOUR LOCAL VALLEN REP FOR MORE INFO



TEROSON

TEROSON® SI 9160™ RTV ADHESIVE SEALANT

PRODUCT BENEFITS

- Provides a tough, flexible, waterproof, oil-resistant seal
- Non-slumping
- Superior adhesion and flexibility
- Seals out moisture and contaminants
- Available in 300 ml cartridges
- Tack-free in 45 minutes/full cure in 24 hours
- Fills large cracks and seams
- Nonflammable, nontoxic

TYPICAL APPLICATIONS

- Bonds and seals plastic, wood, glass, ceramic, metal and other substrates
- Seals ductwork, vents, flues, doors, windows, skylights, trim and molding, siding, roofing and gutters
- Insulates and seals electrical wires and terminals

INDUSTRIES

Agricultural Equipment, Mining & Aggregate, Oil & Gas, Pulp & Paper, HVAC, General Plant & Facility Maintenance, Sign & Display Manufacturing, Specialty Vehicle, Construction, and more.

PART #	DESCRIPTION	PRICE
LCT 32391	TEROSON SI 9160 SILICONE SEALANT WHITE	\$3.99 EA
LCT 32392	TEROSON SI 9160 SILICONE SEALANT ALUMINUM	\$3.99 EA
LCT 32394	TEROSON SI 9160 SILICONE SEALANT RED HI-TEMP	\$4.99 EA
LCT 32389	TEROSON SI 9160 SILICONE SEALANT CLEAR	\$3.99 EA



vallen
Working Smart Starts Here



GASALERT MICROCLIP SERIES

The industrial GasAlertMicroClip is the world's most popular multi-gas portable detector, delivering long runtime and reliability — plus small size, low cost and the easiest user experience.

FEATURES AND BENEFITS

- NEW! GasAlertMicroClip X3 for extended reliability with 3-year warranty
- GasAlertMicroClip XL for standard operation with 2-year warranty
- Guaranteed to run an entire shift — even at -4°F (-20°C)
- NEW! IP68 rating — unmatched water protection
- Compact, lightweight and easy to use — with one-button operation and no extensive training

QUICK SPECS

- Rechargeable battery — survives harsh temperatures, punctures and 20-foot drops
- Flashing green IntelliFlash™ light for compliance at a glance
- Reflex™ Technology ensures sensor responsiveness for safety, uptime and worker confidence

PART #	DESCRIPTION	PRICE
BWT MCX3-XWHM-Y-NA	MONITOR GAS XL% LEL H2S CO & O2	\$615.00EA



PRM™ PVC FOOTWEAR

Seamless, injection molded footwear is 100% waterproof. Steel midsole provides outstanding under-foot puncture protection. Open pattern outsole design is self-cleaning, helping to prevent slip and trip hazards. Removable FOOT FORM contour cushion insoles. Meets CAN/CSA Z195-09 Grade 1.

PART #	DESCRIPTION	PRICE
NOR 75125C-SIZE	BOOT PVC BLACK SZ 7-14	\$31.39 PR



by Honeywell

FIRMFIT™ DISPOSABLE EARPLUGS

Significantly Softer. Less Pressure. Great Protection. Easy to insert. Easy to see.

PART #	DESCRIPTION	PRICE
HOW FF-1	UNCORDED NRR30 POLY BAG 200 PER BOX	\$15.11 BX
HOW FF-30	CORDED NRR30 POLY BAG 100 PER BOX	\$19.18 BX





DRIVER / ROPER - SNAPBACK

Keystone thumb. Rolled cuff. Clute cut back. Snap back wrist. Standard grade leather. Applications: utilities industry, steel and iron works operations, farming and ranching.

PART #	DESCRIPTION	PRICE
GAN 20-1-981-SIZE	GLOVE GRAIN LEATHER WRIST SZ: 8-12	\$10.99 PR

GRAIN FITTER - INDUSTRIAL

Industrial grade leather. Applications: construction, maintenance, lumber industry, machine shops.

PART #	DESCRIPTION	PRICE
GAN 40-1-1511PP	GLOVE FLEECE PALM LINED	\$3.99 PR



WATSON
GLOVES
Quality since 1918



SCAPE GOAT

Full-grain goatskin leather. Drivers style with keystone thumb. Shirred elastic wrist. Slip-on style cuff.

PART #	DESCRIPTION	PRICE
GLO 546-SIZE	GLOVE GOATSKIN UNLINED SZ:S-2XL	\$7.99 PR



STEALTH ORIGINAL

Exceptionally strong nitrile coating has excellent abrasion and puncture resistance; handles well in oil slick applications. Seamless knit shell keeps hands cool and comfortable. Ergonomically formed to help reduce hand fatigue. Extended snug-fitting seamless knit wrist keeps out dirt and debris.

PART #	DESCRIPTION	PRICE
GLO 390-SIZE	GLOVE NITRILE COAT BLACK SZ: S-XL	\$2.99 PR

SUPERTORQUE® SOCKET SET

All tools are professional quality, made of high-grade chrome vanadium steel. Sockets feature SUPERTORQUE® lobular openings for greater turning power without deforming the fastener. Packed in rugged compact high-density polyethylene (HDPE) cases that are strong and durable yet light in weight.

ITEM #	DESCRIPTION	PRICE
WLL 50664	3/8" DR. 18 PIECE SAE SOCKET & DRIVE TOOL SET (3/8" TO 3/4")	\$59.95 ST




WILLIAMS®

CHROME WRENCH SET

High polish chrome textured finish provides great feel and extra gripping power. 12 point box end provides easy socket engagement and maximum versatility. Recessed corners in box end provide extra turning power. Sets are packed in a vinyl pouch.

ITEM #	DESCRIPTION	PRICE
WLL 11009	HI POL-WRENCH SET 16 PCS (1/4" TO 1-1/4")	\$195.00 ST

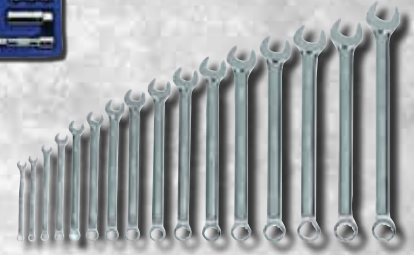

SUPERTORQUE® DEEP SOCKET SET

SUPERTORQUE® lobular openings for greater turning power without deforming the fastener. Designed for quick engagement on both 6 and 12 point fasteners.

ITEM #	DESCRIPTION	PRICE
WLL 32947	1/2" DR. 15 PIECE DEEP METRIC SOCKET SET 6 PT (9MM TO 24MM)	\$79.95 ST



SHEET METAL SNIPS SET

Color-coded handles help quickly identify the cutting direction. Bi-mold handles provide comfortable grip, reduces hand fatigue. Meet ANSI and DIN standards.

ITEM #	DESCRIPTION	PRICE
WLL 28251	3 PIECE SHEET METAL SNIP SET	\$36.95 ST



NU-CLEAR THREAD CUTTING OIL

ITEM #	DESCRIPTION	PRICE
RID 70835	OIL THREAD CUTTING 1 GAL	\$35.95 EA

RIDGID®



MODEL 300 POWER DRIVE

RIDGID® Speed Chuck. Reversible 1/2" HP Universal Motor. Recessed On/Off/Reverse Switch. Ideal For Use With RIDGID Roll Groovers.

ITEM #	DESCRIPTION	PRICE
RID 15682	THREADER 300 COMPLETE 115V	\$5497.00EA



PORTABLE TRISTAND® 460

Portable TRISTAND® vice model 460 integrates a chain vice into the base.

ITEM #	DESCRIPTION	PRICE
RID 36273	VICE TRISTAND MODEL 460-6 1/2" TO 6" PIPE CAP	\$569.00 EA

K-60SP DRAIN CLEANER

Machine with A-1 operator's mitt, A-12 pin key, and A-60-12 rear, guide hose, plus: A-61 tool kit and A-62 cable kit. A compact machine for institutional, commercial or residential cleaning. Also ideal for septic tank vacuum truck operators. Small enough to fit into cramped spaces, yet powerful enough to clear tough blockages. Ideal for rooftop vent stacks. Rear handle allows for easy transporting up ladders and onto rooftops. Remove only two bolts to access jaw set for cleaning or replacement. Removal of same bolts provides access to belt drive. Equipped with 1/2" HP motor. CSA approved. Approved to UL standards (NRTLCL).

ITEM #	DESCRIPTION	PRICE
RID 66497	DRAIN CLEANER	\$2600 EA



vallen

Working Smart Starts Here

British Columbia

ELKFORD

P 250 865 7555 F 250 865 7559

TRAIL

P 250 364 2573 F 250 364 2393

QUESNEL

P 250 255 6497 F 250 992 6131

Alberta

BONNYVILLE

P 780 826 3131 F 780 826 6167

CALGARY

P 403 287 1690 F 403 287 3526

EDMONTON EASTGATE

P 780 490 2700 F 780 490 2895

EDMONTON SOUTH

P 780 430 4000 F 780 430 0200

EDMONTON WEST

P 780 454 0471 F 780 452 2092

FORT MCMURRAY

P 780 743 4336 F 780 791 6512

FORT SASKATCHEWAN

P 780 912 1414 F 780 912 9090

GRANDE PRAIRIE

P 780 532 0843 F 780 532 0819

LETHBRIDGE

P 403 329 4747 F 403 329 1718

LLOYDMINSTER

P 780 875 6223 F 780 875 2968

NISKU / LEDUC

P 780 986 1525 F 780 986 6272

RED DEER

P 403 343 6671 F 403 347 9970

Saskatchewan

REGINA

P 306 721 2223 F 306 721 2344

SASKATOON

P 306 242 1166 F 306 242 0015

Manitoba

THOMPSON

P 204 677 1158 F 204 677 1159

WINNIPEG

P 204 668 8886 F 204 668 3260

Ontario

MISSISSAUGA

P 905 565 1686 F 905 565 0390

ST. CATHARINES

P 905 688 1866 F 905 688 5020

SUBBURY

P 705 222 7870 F 705 222 7880



Pricing in effect until September 30, 2016.
Prices do not include GST / PST / HST

Stock may vary by branch. Prices subject to change. Safety | Industrial | Facilities Maintenance | Technical Services vallen.ca

