

RELAY RACKS

Electron Metal offers many cost effective open relay computer rack options. If you need a 2 Post Relay Rack, Zone 4 Rack or 4 Post Open Rack, we are sure to have an option that will work for your application. And, if we don't, we'll build one specifically tailored to your needs.

Series 710 Relay Rack

The two post, Series 710 heavy duty relay rack is perfect for installations that require minimum space and maximum versatility. Our Series 710 relay racks come fully assembled and are available in many different sizes, along with a full line of cable management options and accessories.

FEATURES

- Fully welded frame made from 12 ga. steel is ready to use
- Base plates are made from thick, 3" x 5" steel angles
- Rack is designed to be bolted to the floor
- Holes tapped 10-32 at standard EIA spacing on front or both front and rear of the uprights
- Sides of rack feature holes to mount cable management accessories or to gang racks together
- Also available for 23" rackmount

Many sizes available

Part No.	Description	Height	RU
RK1FC2-I94400	Square hole cage nuts style 2 sides	82.6	44
RK1FRI-I92400	Tapped 1 side	47.6	24
RK1FRI-I94400	Tapped 1 side	82.6	44
RK1FRI-I94800	Tapped 1 side	89.6	48
RK1FR2-I92400	Tapped 2 sides	47.6	24
RK1FR2-I94400	Tapped 2 sides	82.6	44
RK1FR2-I94800	Tapped 2 sides	89.6	48
RK1FR2-I95200	Tapped 2 sides	96.6	52

Relay Racks: Aluminium Racks

RKAFRA-I94400-BK	Aluminum knock-down rack 44RU black
------------------	-------------------------------------

Relay Racks: Grounding and Bonding

RKZISK-I90000	Zone 4 rack isolation kit, 2 pcs glastic 1/8 x 24 x 6 / 4 nylon bushings
ELEGH2-I90103	19x1x3/16 tap 1/4-20 @ 5/8c-c
ELEGHK-I90010	Horizontal grounding kit with 10ft #6AWG
ELEGWI-061005-GN	6AWG FT4 5ft ground cable w/lug
ELEGWI-061010-GN	6AWG FT4 10ft ground cable w/lug



ELEGWI-061005-GN



ELEGHK-I90010



RK1FRI-I94400

RELAY RACKS


Series 800 Relay Rack

The two post, Series 800 relay rack is for installations that do not permit bolting the rack to the floor. It has a large, free-standing base that can even be mounted on casters for easy mobility. Includes pre-drilled and tapped uprights, comes fully assembled.

FEATURES

- Fully welded frame made from 12 ga. steel is ready to use
- Free standing rack, no need to bolt to floor
- Base can easily be equipped with casters
- Holes tapped 10-32 at standard E.I.A. spacing on front or both front and rear of the uprights
- Sides are equipped with holes for cable management or to gang racks together
- Rack is available in many sizes
- Side cable management optional
- Also available for 23" rackmount

Part No.	Description	Height	RU
RK8FR1-I92600	Tapped 1 side	45.5	26
RK8FR1-I94600	Tapped 1 side	80.5	46
RK8FR1-I95000	Tapped 1 side	87.5	50
RK8FR2-I92600	Tapped 2 sides	45.5	26
RK8FR2-I94600	Tapped 2 sides	80.5	46
RK8FR2-I95000	Tapped 2 sides	87.5	50

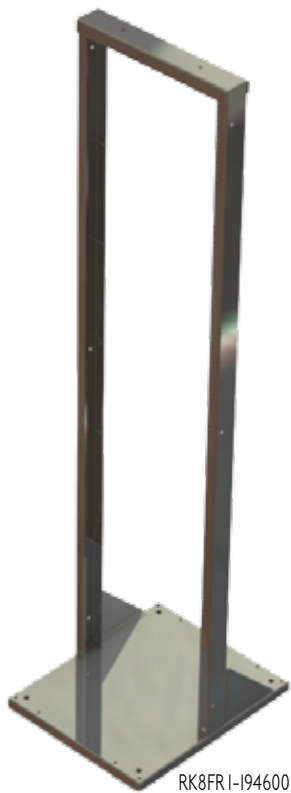

RK8FR1-I94600

Zone 4 Relay Rack

Our Zone 4 relay rack is BELLCORE GR-63-CORE tested and certified compliant. Designed for maximum durability and resistance during earthquakes or other vibrations. Extra heavy duty construction will help protect your expensive equipment from damage during a seismic event.

FEATURES

- Ultra-heavy duty welded 11 ga. steel construction
- Heavy duty 6" x 3" side channels for maximum rigidity
- Extra welds provide superior strength
- Mounting holes tapped 10-32 at standard EIA spacing
- Large, bolt down base
- Rack accepts cable management accessories
- Available in 19" or 23" rackmount sizes

Part No.	Description	Width	Height	RU
RKZFR2-I94400	19" rack mount, tapped 2 sides	24	84.060	44
RKZFR2-234400	23" rack mount, tapped 2 sides	28	84.060	44



RKZFR2-I94400