



FLUORO BAR AND XENO BAR SYSTEM HARDWIRE BOX

UNDERCABINET LIGHTING

ALFT6300-WH



PROJECT

FIXTURE TYPE

MODEL

LAMP

CONTACT/TELEPHONE

Specifications

Description

Fluoro Bar and Xeno Bar System Hardwire Box, with an on/off switch and 1/2-inch knock-out. Designed for use with both T4/T5 2-wire and 3-wire systems.

Features

- Hardwire Box with a switch
- Can be connected directly to the fixture or by using a flexible connector
- For 120V Power Input
- Equipped with 10 amp 120V rocker switch
- Easy wiring - no splicing and no wire nuts required
- Approved for hardwire applications
- Provided with 1 standard 1/2" knock out for electrical connections

Electrical

ETL Listed

Input/Output

120V AC 60Hz/120V AC

Note

Not for outdoor use

Optional Accessories

- ALFT90-WH : 90° Flexible Connector
(only available in 3-wire systems)
- Flexible wire connectors, available in various lengths
 - FBT6106: 6" Connector Cable
 - FBT6100: 12" Connector Cable
 - FBT6124: 24" Connector Cable
 - FBT6136: 36" Connector Cable


Dimensions & Ordering Guide

Model

ALFT6300-WH

Colour

White

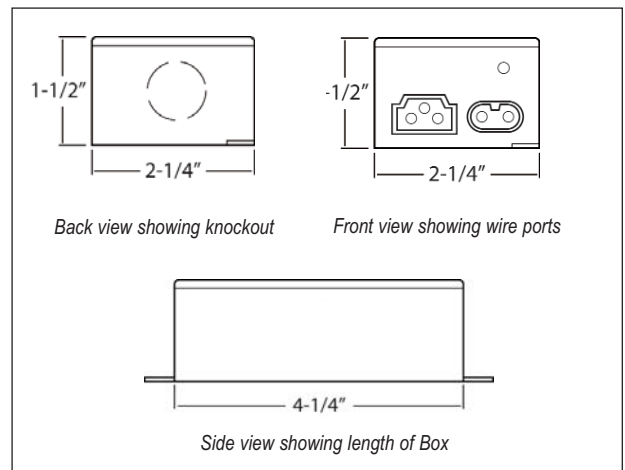

All dimensions are in inches / millimeters

Listings



LITELINE CORPORATION

8 Abacus Road, Brampton, Ontario, Canada L6T 5B7
Tel: 416-996-1856 • Fax: 905-794-1990 / 1-888-738-9736
E-mail: sales@liteline.com • Website: www.liteline.com

Product specifications subject to change without notice.