



**XENON
PUCK FIXTURE**
*UNDERCABINET
LIGHTING*
CL-1JC20X



PROJECT
FIXTURE TYPE
MODEL
LAMP
CONTACT/TELEPHONE

Specifications

Description

Single Xenon Puck Light Fixtures, includes 1 - 20W Xenon JC Lamp. All Xenon puck lights can be surface mounted or recessed. Should you be mounting 2 or 3 pucks with the wiring harness (CL-WH3-BK/WH), the maximum spacing apart is 32". Available in six colours.

Lamp Wattage / Type

- Supplied with 1 Xenon JC lamps, Bi-Pin G4 base, 20W, 12V. (# LJCX20-12-2)

Features

- Runs cooler than halogen.
- 10,000 hour average life. (Last up to eight times longer than halogen)
- Can replace existing halogen bulbs.

Input/Output

- 120V AC/12V AC

Transformer

- 60W solid state electronic transformer provides noise-free voltage reduction and operation.
- Vibration resistant.

Accessories

- See Liteline Catalogue/Illustrated List Price Schedule for details.


Dimensions & Ordering Guide

Model

- CL-1JC20X-BK
- CL-1JC20X-BC
- CL-1JC20X-CH
- CL-1JC20X-GL
- CL-1JC20X-PT
- CL-1JC20X-WH

Colour

- Black
- Brush Chrome
- Chrome
- Gold
- Pewter
- White

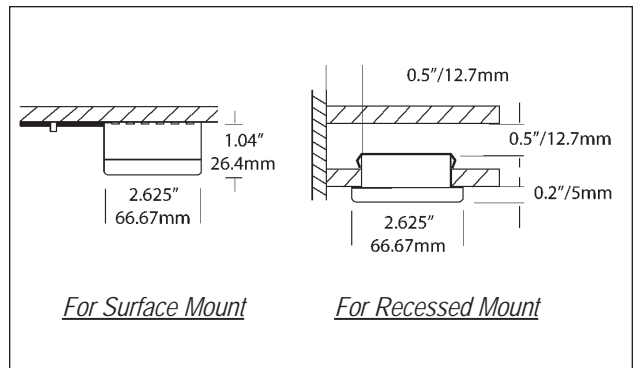

All dimensions are in inches and millimeters

Listings



LITELINE CORPORATION

8 Abacus Road, Brampton, Ontario, Canada L6T 5B7
 Tel: 416-996-1856 • Fax: 905-794-1990 / 1-888-738-9736
 E-mail: sales@liteline.com • Website: liteline.com

Product specifications subject to change without notice.