



TRANSFORMERS
UNDER CABINET

CL-THW60-JB-BK1



PROJECT
FIXTURE TYPE
MODEL
LAMP
CONTACT/TELEPHONE

Specifications

Description

Electronic, solid state low voltage transformer box, 60W, with 4-in black & white wire, plug and Molex™ connector.

Features

- Approved for remote application.
- Short circuit and overload protection.
- May be dimmed with regular incandescent dimmers.
- CSA® listed.
- For indoor use only.
- 6' Maximum Distance.
- Dimensions: Length: 6-3/4" (171.5mm)
Width: 3-1/4" (82.5mm)
Height: 1-1/8" (28.6mm)

Electrical

- Class II remote transformer.

Input/Output

120V AC 60Hz/12V AC 60W max per circuit.


Dimensions & Ordering Guide

Model

CL-THW60-JB-BK1

Colour

Black

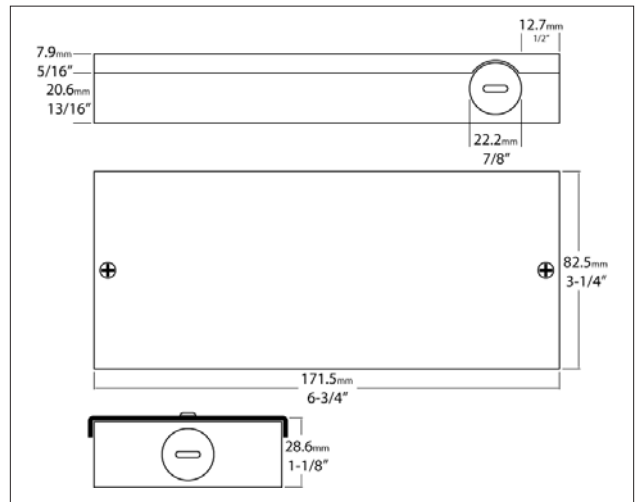

All dimensions are in millimeters / inches

Listings



LITELINE CORPORATION

8 Abacus Road, Brampton, Ontario, Canada L6T 5B7
Tel: 416-996-1856 • Fax: 905-794-1990 / 1-888-738-9736
E-mail: sales@liteline.com • Website: www.liteline.com

Product specifications subject to change without notice.