

# HV4-TH4013

4" Shower Trim with Frosted Glass Lens  
Recessed Lighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

## Features

### Trim

Constructed of stamped steel with a spun aluminum reflector, HV4-TH4013 is a 4" shower trim with a frosted glass lens and neoprene gasket. Suitable for wet location. Available in White, Brushed Nickel, Chrome and Flat White finishes.

### Mounting

Three pressure clips provide enhanced rigidity within the housing.

### Lamps

- MR16 (GU5.3 base), 35W max., 12V.
- MR16 (E26 base) 35W max. 120V.


SPECIFICATION	
Aperture	4"
Application	Recessed
Approved Location	Wet
Lamp Loading	Rear Loading
Lamp Type	MR16
Lens Type	Frosted
Material	Steel
Max. Watt	35
Trim Style	Shower



## Description

The HV4-TH4013 is a 4" shower trim with frosted glass lens and neoprene gasket suitable for wet locations. Available in White, Brushed Nickel, Chrome and Flat White finishes.

**Notes:** For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

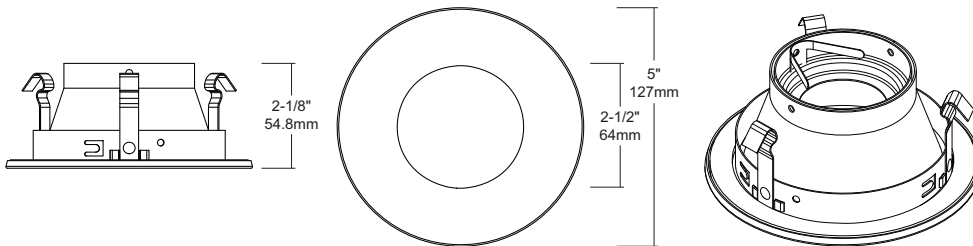

## Ordering Guide

- 
**HV4-TH4013-CH**  
4" Shower Trim, Chrome, 12V and 120V
- 
**HV4-TH4013-BN**  
4" Shower Trim, Brushed Nickel, 12V and 120V
- 
**HV4-TH4013-FWH**  
4" Shower Trim, Flat White, 12V and 120V
- 
**HV4-TH4013-WH**  
4" Shower Trim, White, 12V and 120V