






 
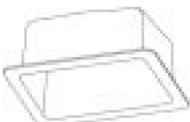




Lighting Products

Line Voltage (120V) – RECESSED LIGHTING – 4-in. housings

Catalogue #	Description	Case Qty.
	HV4-HR01-NC 4" New Construction Housing, MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	HV4-HR02-RM 4" Remodel Housing, MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	HV4-HR02C-RM 4" Remodel Housing, with screw down clamp. MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	P-4000 4" New Construction premounting plate for use with HV4-HR02C remodel housings.	6
	HV4-HR05-IC 4" Housing for Insulated Ceiling, MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V - Air tight.	6
	HV4S-HR01-NC 4" New Construction Housing, with adjustable socket height. MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	HV4S-HR02-RM 4" Remodel Housing, with adjustable socket height. MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	HV4S-HR05-IC 4" Housing for Insulated Ceiling, with adjustable socket height - Air tight. MR16 E26 lamp with glass cover and aluminum reflector, R20/PAR20, 50W max., 120V.	6
	VBE-1 Vapour Barrier Extender for use with all Liteline recessed I.C. fixtures to prevent moisture from entering into the attic. Made from UL recognized PVC material rated to 90° C	Bulk