

# HV4-TH4014

4" Shower Trim with Dropped Frosted Glass Lens  
Recessed Lighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

## Features

### Trim

Constructed of stamped steel with a spun aluminum reflector, HV4-TH4014 is a 4" shower trim with a dropped frosted glass lens and neoprene gasket. Suitable for wet location. Available in a White finish.

### Mounting

Three pressure clips provide enhanced rigidity within the housing.

### Lamps

- PAR20 (E26 base), 35W max.


SPECIFICATION	
Aperture	4"
Application	Recessed
Approved Location	Wet
Lamp Loading	Rear Loading
Lamp Type	PAR20
Lens Type	Frosted
Material	Steel
Max. Watt	35
Trim Style	Shower



## Description

The HV4-TH4014 is a 4" shower trim with a dropped frosted glass lens and neoprene gasket suitable for wet locations. Available in a White finish.

**Notes:** For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

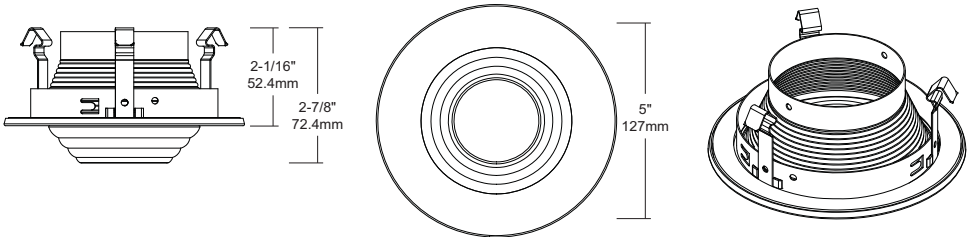

## Ordering Guide



### HV4-TH4014-WH

4" Shower Trim with Dropped Frosted Glass Lens, Chrome, 12V and 120V

