



35W MR16 Medium Base Halogen Lamp

Line Voltage Halogen Lamps

| |
|-------------------|
| PROJECT |
| FIXTURE TYPE |
| MODEL |
| LAMP |
| CONTACT/TELEPHONE |

Product No. *LMP16E26AC-35-BX*

Description

An MR16 line voltage multi-faceted reflector halogen lamp, with clear cover. For use in track or recessed fixtures.

General Characteristics

| | |
|------------|-----------------------------|
| Lamp Type | <i>Line Voltage Halogen</i> |
| Bulb Size | <i>MR16</i> |
| Base | <i>Medium base (E26)</i> |
| Wattage | <i>35W</i> |
| Voltage | <i>120V AC</i> |
| Rated Life | <i>2,000 hours</i> |
| Reflector | <i>Aluminum</i> |

Operating Characteristics

| | |
|-------------------------------|-----------------|
| Approx. Initial Lumens | <i>NA</i> |
| Approx. Mean Lumens | <i>350</i> |
| Colour Temperature | <i>2700K</i> |
| Colour Rendering Index. (CRI) | <i>99</i> |
| Beam Spread | <i>36°</i> |
| Dimmable | <i>Dimmable</i> |

Dimensions

| | |
|------------------------------|------------------------|
| Maximum Overall Length (MOL) | <i>2.13" (54.00mm)</i> |
| Bulb Diameter (DIA) | <i>2.00" (50.80mm)</i> |

Applications:



- Retail store display
- Focus lighting
- Recessed

Caution

- Lamp may shatter and cause injury if broken
- Do not use excessive force when installing lamp.
- Use only on dry location.

Warning

- Risk of Electric Shock
- Turn power off before inspection, installation or removal.

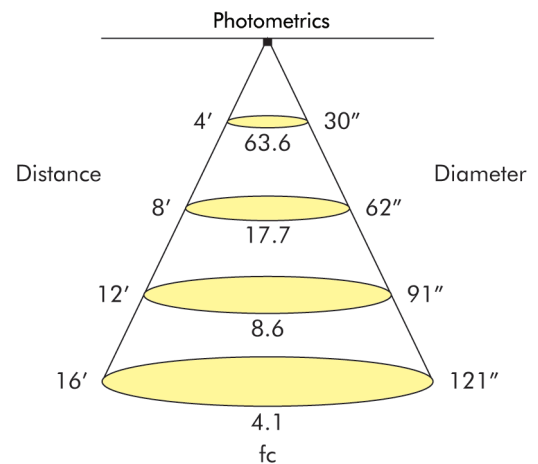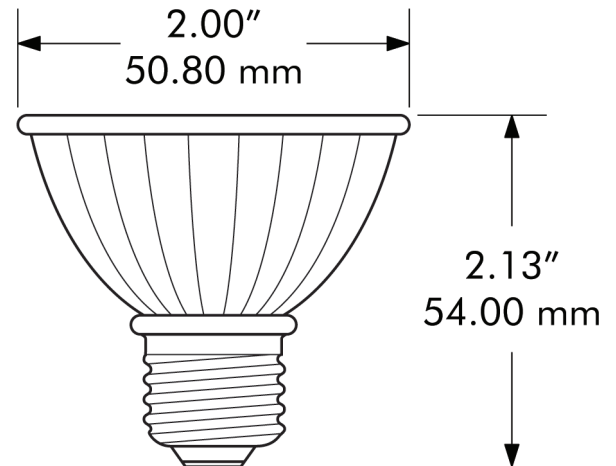

LITELINE CORPORATION

8 Abacus Road, Brampton, Ontario, Canada L6T 5B7
 Tel: 416-996-1856 • Fax: 905-794-1990 / 1-888-738-9736
 Email: sales@liteline.com • Website: liteline.com

Product specifications subject to change without notice.