


# RTM6024

## 6" Line Voltage Tilting Rear Load Gimbal Trim

### For PAR30 75W Max. Lamp

Catalog # : \_\_\_\_\_  
 Project : \_\_\_\_\_  
 Type : \_\_\_\_\_  
 Comments : \_\_\_\_\_

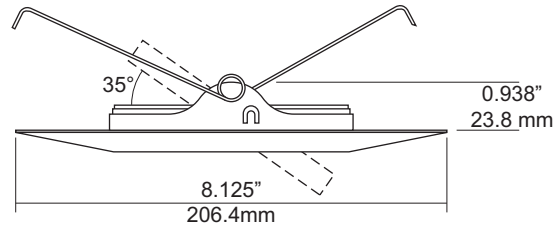

### DESCRIPTION

The RTM6024 is a 6" aperture line voltage tilting round rear load metal gimbal trim. The RTM6024 is used for PAR30 lamps. The RTM6024 is available in White and Brushed Nickel.

### DESIGN FEATURES

- **Trim**
  - Precision spun .040" thick painted steel.
  - Wire spring to hold trim in place.
- **Lamp Holder**
  - Precision spun .040" thick painted steel.
  - Tilttable up to 35° for directional lighting.
- **Lamp**
  - PAR30, 70W Max. (for IC or Non-IC applications)
- **Housing**
  - Designed to work with 6" recessed housings.
    - \* RF6011CAT
    - \* RF6021CAT
- **Listing**
  - cULus Listed.

### Ordering Information

Trim	Color
RTM6024	-WH -BN

Example : RTM6024-BN



**Liteline Corporation**  
 8 Abacus Road, Brampton, ON  
 L6T 5B7

Tel: 416-996-1856  
 Fax: 905-794-1990

Email: sales@liteline.com  
 Website: liteline.com