


RTM6025

6" Line Voltage Tilting Rear Load Gimbal Trim For PAR38 150W Max. Lamp

Catalog # : _____
 Project : _____
 Type : _____
 Comments : _____

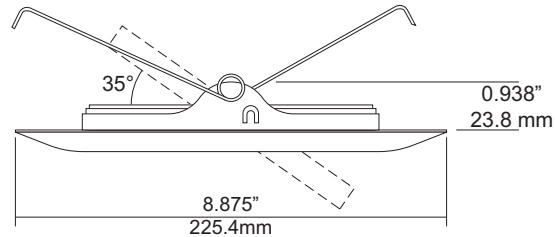

DESCRIPTION

The RTM6025 is a 6" aperture line voltage tilting round rear load metal gimbal trim. The RTM6025 is used for PAR38 lamps. The RTM6025 is available in White and Brushed Nickel.

DESIGN FEATURES

- **Trim**
 - Precision spun .040" thick painted steel.
 - Wire spring to hold trim in place.
- **Lamp Holder**
 - Precision spun .040" thick painted steel.
 - Tiltable up to 35° for directional lighting.
- **Lamp**
 - PAR38, 150W Max. (for IC or Non-IC applications)
- **Housing**
 - Designed to work with 6" recessed housings.
 - * RF6011CAT
 - * RF6021CAT
- **Listing**
 - cULus Listed.

Ordering Information

Trim	Color
<input type="text"/> RTM6025	<input type="text"/> -WH -BN

Example : RTM6025-WH



Liteline Corporation
 8 Abacus Road, Brampton, ON
 L6T 5B7

Tel: 416-996-1856
 Fax: 905-794-1990

Email: sales@liteline.com
 Website: liteline.com