

HWB-DIM-MDC-24V-60W

60W Indoor/Outdoor Dimmable Class 2 Magnetic Driver, 24V

Cabinet, Cove & Display

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

Features

Construction

White painted metal enclosure with mounting holes for vertical mounting. Enclosure is Nema 3R rated for indoor/outdoor use. Two 7/8" knockouts, one on each side, to enable easy installation that complies with electrical code requirements.

Electrical Performance

- Max load: 60W (output).
- 24V DC output.

Circuit Protection

Circuit breaker protection on both input and output. Auto-reset breakers quickly respond to abnormal conditions. The breakers automatically reset once the condition is resolved.

Dimming

Requires 120V AC magnetic low voltage TRIAC dimmer. See page 2 for compatible dimmers.

Compatibility

Compatible with all DazzLED 24 volt LED lighting fixtures.

Approvals

- Class 2
- cETLus Listed


SPECIFICATIONS	
Amperage	0.95
Application	Undercabinet
Approved Location	Wet
Ballast/Transformer	LED Driver Magnetic
Box Type	White
Certification	cETLus
Classification	Class II
Colour1	WH
Dimming	Yes
Enclosure Type	NEMA 3R
Link Connector	Hard Wire
Max. Op. Temp. °C	70°C
Min. Start Temp. °C	-30°C
Power Factor	>0.8
Power Supply Type	Constant Voltage
Primary Voltage	120
Secondary Voltage	24V DC
Warranty	5 Years
Watt	60




Description

The HWB-DIM-MDC-24V-60W is a compact magnetic driver equipped with two auto-reset breakers which protect both the load and the driver. All enclosed in a coated metal box that includes 2 knockouts to enable easy installation.

Dimensions

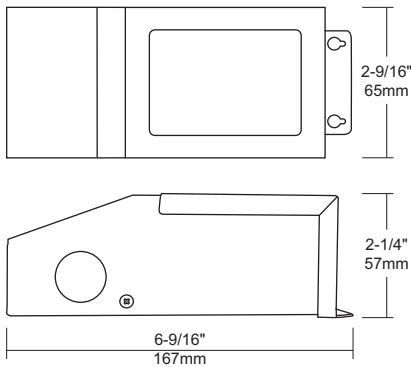

Wiring Diagram

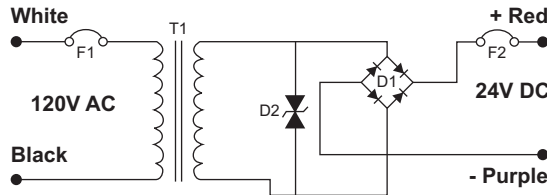

Notes: Accessories should be ordered separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

Ordering Guide



HWB-DIM-MDC-24V-60W
60W indoor/outdoor dimmable class 2 LED magnetic driver, 24V.

See page 2 for compatible dimmers.



Compatible Dimmers

Brand	Series	Model No.					
Lutron®	Ariadni®	AYLV-603P	AYLV-603P-CSA	AYLV-603P-S	AYLV-600P	AYLV-600P-CSA	AYLV-600P-S
	Aycl®	153-PH					
	Ceana®	CNLV-603P	CNLV-600P				
	Diva®	DVLV-103P DVLV-103P-S DVLV-603V DVLV-10P-S SC-3PSNL	DVLV-603P DVLV-603P-S DVLV-600P DVLV-10PH-S SC-4PSNL	DVSCLV-103P DVLV-103PH-S DVLV-10P DVSCLV-10P-L SC-1PSNL	DVSCLV-603P DVLV-603PH-S DVSCLV-10P SC-3PS	DVLV-103P-CSA DVSCLV-103P-L DVSCLV-600P SC-4PS	DVLV-603P-CSA DVSCLV-603P-L DVLV-10P-CSA SC-1PS
	Glyder®	GLV-600	GLV-600-CSA				
	Lyneo®	LXLV-103PL	LXLV-603PL	LXLV-10PL	LXLV-600PL		
	Maestro®	MALV-600	MACL-153m				
	Nova®	NTLV-1000 NTLV-1503P NTLV-603P-CSA NT-3PS-CSA NT-1PS-CSA	NTLV-1500 NTLV-2003P NTLV-1503P-S NT-3PS-S NT-1PS-S	NTLV-600 NTLV-1003P NTLV-2003P-S NT-4PS	NTLV-1500-S NTLV-603P NTLV-1003P-S NT-4PS-CSA	NTLV-600-S NTLV-1503P-CSA NTLV-603P-S NT-4PS-S	NTLV-1000-S NTLV-1003P-CSA NT-3PS NT-1PS
Lutron®	Nova T®	NTLV-1500	NTLV-1000	NTLV-1000-277	NTLV-600	NTLV-600-277	
	Skylark®	S-600P SLV-600PH-CSA	SLV-603P	SLV-603P-CSA	SLV-603PH-CSA	SLV-600P	SLV-600P-CSA
	Vareo®	V-1000 VETS-1000-CSA VETS-1000-SL-S	V-600 VETN-1000-S VETS-A-SL	V-1000-S VETS-1000-S VETS-A-SL-S	V-600-S VETS-R	VETN-1000 VETS-R-S	VETS-1000 VETS-1000-SL
Leviton®	Illumatech®	IPM06-1LZ	IPM06-1LX	IPM10-1LZ			
	Incandescent ol	OC5504	1C3005				
	Mural™	MDM06-1LI	MDM06-1LW	MDM06-1LA	MDM10-1LI	MDM10-1LW	MDM10-1LA
	Sureslide®	6613-PLT	6613-PLI	6613-PLW	6613-PLA		
	ToggleTouch™	TGM10-1LI	TGM10-1LA	TGM10-1LT			
Vizia®	VPM06-1LZ						
Legrand	Pass and Seymour	HLV1103PW H703P	CDLV1103-PW LSLV600-PW	HLV703PTC LSLV600-W	WSLV703PW	H703PTUTC	CDLV703-PW