




## XENON THREE PUCK PACKS

UNDERCABINET LIGHTING

CL-3JC20X

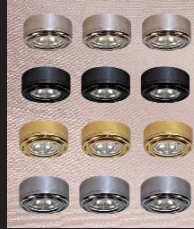

PROJECT
FIXTURE TYPE
MODEL
LAMP
CONTACT/TELEPHONE

### Specifications

#### Description

Three Xenon Puck Light Fixtures, includes 3 - 20W Xenon JC Lamps, 60W transformer and wiring harness. All Xenon puck lights can be surface mounted or recessed. Should you be mounting 2 or 3 pucks with the wiring harness the maximum spacing apart is 32". Available in six colours - Black, White, Brushed Chrome, Chrome, Gold and Pewter.

#### Lamp Wattage / Type

- Supplied with 3 Xenon JC lamps, Bi-Pin G4 base, 20W, 12V.

#### Features

- Runs cooler than halogen.
- 15,000 hour average life.  
(Last up to twenty times longer than halogen)
- Can replace existing halogen bulbs.
- Comes with a 6-ft. power cord and 3 light wiring harness, with 10-ft. cord.

#### Input/Output

- 120V AC/12V AC

#### Transformer

- 60W solid state electronic transformer provides noise-free voltage reduction and operation.

#### Accessories

- See Liteline Catalogue/Illustrated List Price Schedule for details.


### Dimensions & Ordering Guide

#### Model

CL-3JC20X-BK  
CL-3JC20X-WH  
CL-3JC20X-BC  
CL-3JC20X-CH  
CL-3JC20X-GL  
CL-3JC20X-PT

#### Colour

Black  
White  
Brush Chrome  
Chrome  
Gold  
Pewter

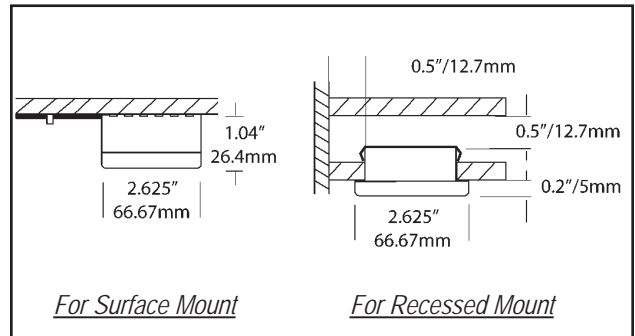

All dimensions are in inches / millimeters

#### Listings



### LITELINE CORPORATION

8 Abacus Road, Brampton, Ontario, Canada L6T 5B7  
Tel: 416-996-1856 • Fax: 905-794-1990 / 1-888-738-9736  
E-mail: sales@liteline.com • Website: liteline.com

Product specifications subject to change without notice.