

RTM4018R3

4" Line Voltage Trim with Tilting Gimbal
Recessed Lighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

Features

Trim

Constructed of precision spun .040" steel. RTM4018R3 tilting gimbal trim is available in seven colours: Antique Brass, Black, White, Flat White, Brushed Brass, Brushed Nickel and Stainless Steel.

- PAR20,(E26 Medium Base) 50W max., 120V.

Housing Compatibility

RTM4018R3 is designed to be used with Liteline 4" Medium base (E26) Recessed Housings.

Mounting

Three chrome plated steel clips provide enhanced rigidity within the housing.

Aiming Adjustment

The trim includes a tilting center (lamp holder) that adjusts up to 35° and maintains the set angle, providing a wide range of accent and task applications.


Lamps



Description

The RTM4018R3 is a round tilting gimbal trim with 3 clips. The adjustable aiming capability (35° tilt) provides versatility for a wide range of accent and task applications.

Notes: For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

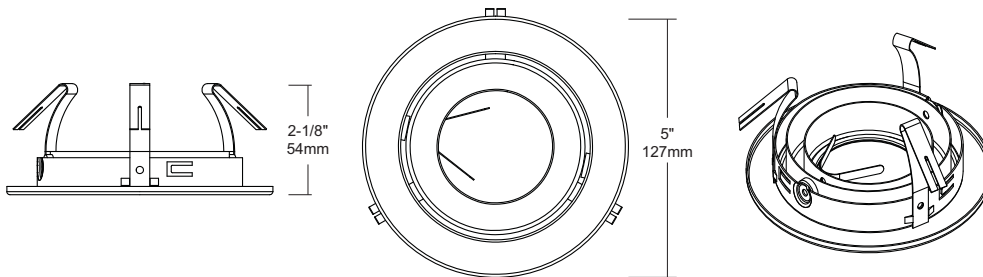

Ordering Guide



RTM4018R3-AB
4" Line Voltage Tilting Gimbal Trim, Antique Brass.



RTM4018R3-FWH
4" Line Voltage Tilting Gimbal Trim, Flat White



RTM4018R3-BB
4" Line Voltage Tilting Gimbal Trim, Brushed Brass.



RTM4018R3-STS
4" Line Voltage Tilting Gimbal Trim, Stainless Steel.



RTM4018R3-BK
4" Line Voltage Tilting Gimbal Trim, Black.



RTM4018R3-WH
4" Line Voltage Tilting Gimbal Trim, White



RTM4018R3-BN
4" Line Voltage Tilting Gimbal Trim, Brushed Nickel.

