

HV4-TH4007A

4" Aluminum Airtight Reflector Trim
Recessed Lighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

Features

Trim

This airtight trim is constructed of high-grade spun aluminum in a self-flanged design and finished with enamel paint. Provided with neoprene gasket to protect from moisture. Available in a Flat White, Taupe and White finish.

Mounting

Two pressure clips provide enhanced rigidity within the housing.

Lamps

- PAR20 (E26 base), 50W max.
- PAR30 (E26 base) 75W max.
- LED PAR20 (E26 base)
- LED PAR30S (short neck)

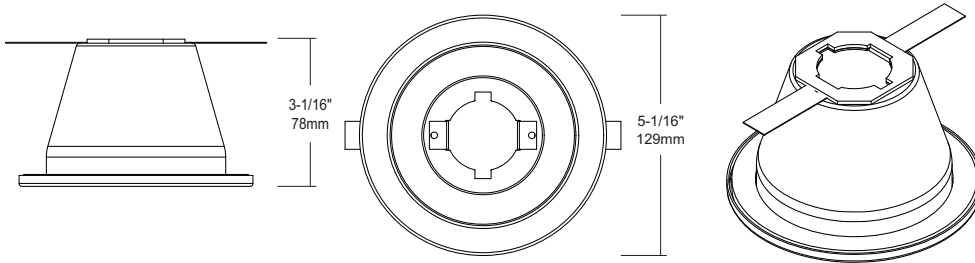
SPECIFICATION	
Airtight	Yes
Aperture	4"
Application	Recessed
Approved Location	Damp
Box Type	White
Lamp Type	PAR20
Material	Aluminum
Max. Watt	75W
Profile	






Description

The HV4-TH4007A is a 4" aluminum smooth airtight reflector trim. Available in a Flat White, Taupe and White finish. Provides a wide range of accent and task applications.

Notes: For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.



Ordering Guide

- 
HV4-TH4007A-FWH
 4" Aluminum Reflector Trim, Flat White, 120V.
- 
HV4-TH4007A-TP
 4" Aluminum Reflector Trim, Taupe, 120V.
- 
HV4-TH4007A-WH
 4" Aluminum Reflector Trim, White, 120V.