

ATK

Track Track & Power Feeds

| Job Information | | |
|-----------------|--|------|
| Project Name | | Type |
| Location | | |
| Quantity | | Date |
| Contact/Phone | | |
| Notes | | |

Features

Extrusion

Constructed of 0.06" extruded aluminum with 0.045" PVC bus bar support holding 12 gauge round bus bars. Polarity groove is located on face of track to indicate location of grounding conductor.

Labels

cULus listed.

Electrical

Single circuit power distribution system designed to supply lighting unit flexibly. Single hot and neutral conductors are rated for max. 20 Amps. Copper electrical conductors are concealed in thermo-plastic, low-profile track section.

Compatibility

Track system is compatible with all A-Line® and Juno® style track fixtures, accessories and connectors.


Mounting

This track is surface mounted using the supplied mounting hardware.



Description

The ATK series is an extruded aluminum track for use with A-Line track fixtures. Available in 2', 4', 6', 8' and 12' nominal length.

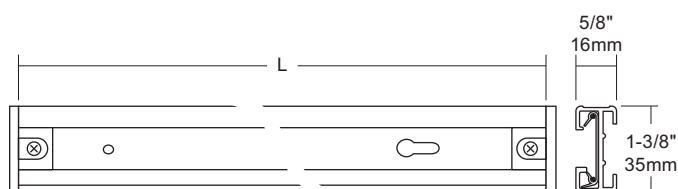

| Part No. | Length (Excluding end caps) |
|----------|--------------------------------|
| ATK02 | 20-1/8" (511mm) |
| ATK04 | 44-1/8" (1121mm) |
| ATK06 | 68-1/8" (1730mm) |
| ATK08 | 92-1/8" (2340mm) |
| ATK12 | 140-1/8" (3559mm) |



Notes: Accessories should be ordered separately. For additional options please consult your A-Line Lighting representative. Juno is a registered trademark of Juno Lighting Group.

Due to our continued efforts to improve our products, product specifications are subject to change without notice.

Ordering Guide

| Length | Colour |
|----------|---------------------|
| ATK -- | -- |
| 02 : 2' | BK : Black |
| 04 : 4' | BN : Brushed Nickel |
| 06 : 6' | WH : White |
| 08 : 8' | |
| 12 : 12' | |

Example: ATK04-BN