


LUNA™ LED

3" Gimbal Recessed Light



Liteline's directional LED recessed lighting fixtures are perfect for residential or commercial lighting applications. The adjustable gimbal fixture has a 30° tilt on 360° rotation. These low maintenance LED fixtures are 80% more efficient than incandescent recessed fixtures, designed to reduce lighting costs without compromising lighting levels. Perfect choice for sloped ceilings, wall washing, highlight artwork, task or general lighting.

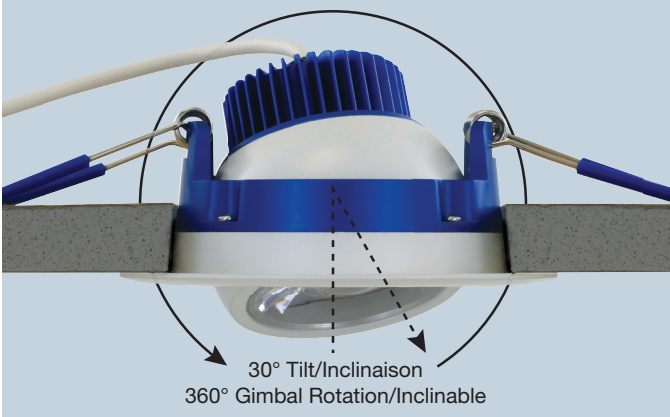

FEATURES

- Up to 650 lumens
- 7 Watts
- IC rated
- Available in 2700°K, 3500°K, 3000°K & 4000°K colour temperatures
- Lifetime warranty
- Energy Star approved
- Dimmable
- Ideal for sloped ceilings
- LED technology fits anywhere you need general light source
- Tilting gimbal light source for directional lighting
- I.C. rated for direct contact with insulation
- Easy to install yourself
- No housing required
- Driver included



IC Rated



100%-10% Dimmable



Colour Accuracy



2700K/3500K
3000K/4000K



Damp Location

Colour Options



White



Brushed Nickel



Black



Intertek



ENERGY STAR



LITELINE CORPORATION | www.liteline.com
P 416-996-1856 | 1-866-730-7704
F 905-709-5255 | 1-888-738-9736

Ordering Guide

Part #	Description	UPC	Case Qty.	Master Qty.
3" LUNA™ LED Gimbal Fixtures				
RA3-7G-27K-90BK	3" LUNA™ LED round gimbal fixture, 7W, 2700°K, 90CRI, dimmable. Suitable for insulated ceilings, black.	771250258854	6	36
RA3-7G-27K-90BN	3" LUNA™ LED round gimbal fixture, 7W, 2700°K, 90CRI, dimmable. Suitable for insulated ceilings, brushed nickel.	771250258861	6	36
RA3-7G-27K-90WH	3" LUNA™ LED round gimbal fixture, 7W, 2700°K, 90CRI, dimmable. Suitable for insulated ceilings, white.	771250258878	6	36
RA3-7G-30K-90BK	3" LUNA™ LED round gimbal fixture, 7W, 3000°K, 90CRI, dimmable. Suitable for insulated ceilings, black.	771250258885	6	36
RA3-7G-30K-90BN	3" LUNA™ LED round gimbal fixture, 7W, 3000°K, 90CRI, dimmable. Suitable for insulated ceilings, brushed nickel.	771250220509	6	36
RA3-7G-30K-90WH	3" LUNA™ LED round gimbal fixture, 7W, 3000°K, 90CRI, dimmable. Suitable for insulated ceilings, white.	771250220516	6	36
RA3-7G-35K-90BK	3" LUNA™ LED round gimbal fixture, 7W, 3500°K, 90CRI, dimmable. Suitable for insulated ceilings, black.	771250258892	6	36
RA3-7G-35K-90BN	3" LUNA™ LED round gimbal fixture, 7W, 3500°K, 90CRI, dimmable. Suitable for insulated ceilings, brushed nickel.	771250258908	6	36
RA3-7G-35K-90WH	3" LUNA™ LED round gimbal fixture, 7W, 3500°K, 90CRI, dimmable. Suitable for insulated ceilings, white.	771250258915	6	36
RA3-7G-40K-90BK	3" LUNA™ LED round gimbal fixture, 7W, 4000°K, 90CRI, dimmable. Suitable for insulated ceilings, black.	771250258922	6	36
RA3-7G-40K-90BN	3" LUNA™ LED round gimbal fixture, 7W, 4000°K, 90CRI, dimmable. Suitable for insulated ceilings, brushed nickel.	771250220530	6	36
RA3-7G-40K-90WH	3" LUNA™ LED round gimbal fixture, 7W, 4000°K, 90CRI, dimmable. Suitable for insulated ceilings, white.	771250220547	6	36
Accessories				
SLM-60-FC	60" Flexible connector. Used to extend distance for remote driver location.	771250976079	12	48
P-2810	2¾" Pre-mounting plate. For use with LUNA™ series.	771250221605	–	30
P-NCMK-1	New construction mounting kit, includes hanger bars, brackets and screws.	771250224316	–	64
VBE-1	Vapour barrier extender. For use in new construction applications.	771250904942	–	50
VBE-2	Vapour barrier extender. For use in remodel applications.	771250971388	–	50
VBE-3	Vapour barrier extender. For use in remodel applications.	771250976086	–	50
VBE-4	Vapour barrier extender. For use in remodel applications.	771250190895	–	05