

GP1800

GP SERIES
Commercial/Residential
Portable Generators

1 of 2

A/C Rated Output Watts 1800
A/C Maximum Output Watts 2050

Model 5723-0

UPC Number: 696471057232

Emissions Certification: CSA Certified.

Not for sale in California



features

- OHV SPLASH LUBRICATION
- HIGH PERFORMANCE ALTERNATOR
- STEEL FUEL TANK WITH FUEL GAUGE
- HARDENED STEEL TUBE CRADLE
- CIRCUIT BREAKER PROTECTED OUTLETS
- LOW TONE MUFFLER

customer connections

Outlets


A (2) 5-20R 120V

Circuit Breakers

M (1) 20A

Other Features

H On/Off Switch

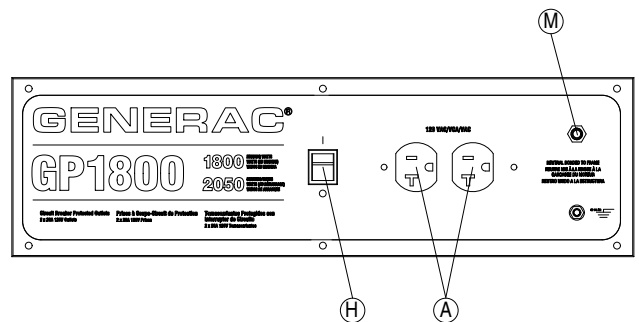

GP1800

specifications

Series	GP1800
Model	5723-0
Configuration/Emissions	CSA
A/C Rated Output Watts:	1800
A/C Maximum Output Watts:	2050
A/C Voltage	120/240VAC
A/C Frequency	60 Hz
Rated 120/240 VAC Amperage	7.5
Max 120/240 VAC Amperage	8.5
Engine Size	163cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	5W30
Lubrication Method	Splash Sump
Choke Type	Manual Lever
Fuel Shut Off	Manual Lever
Idle Control	Full Speed
Starting Method	Manual
Battery	na
Battery Size	na
Low Oil Shutdown Method	Low Level

Start Switch Type	On/Off Toggle
Switch Location	Control Panel
Single-Point Lifting Eye	None
Fuel Gauge	Yes
Fuel Tank Capacity (Gal)	4
Fuel Tank Capacity (Liters)	15.14
Run Time at 50% (Hours)	14
Cord Set	No
Handle Style	Folding
Wheel type	n/a
Maintenance Kit	Sold Separately
Warranty - Residential	2 Year
Warranty - Commercial	1 Year

dimensions and weights

Length (L)	23.5
Width (W)	17
Height (H)	17.5
Extended Length (EL)	23.5
Carton Length	24.25
Carton Width	18
Carton Height	18.25
Unit Weight (lbs)	79
Shipping Weight (lbs)	90.5

