


# TRACJACK® Faceplates

NOTE: All Ortronics product dimensions are listed by width, height and depth unless specified otherwise.

Ortronics offers a full range of TracJack faceplates in plastic or stainless steel, with a variety of port capacities to match your workstation applications. All TracJack plates offer recessed label fields and slotted screw holes to adjust alignment. They are ruggedly constructed from high impact thermo-plastic 94V-0 rated to ensure long life. Two to 12-port plastic wall plates now include the ability to rear-load TracJack modules.

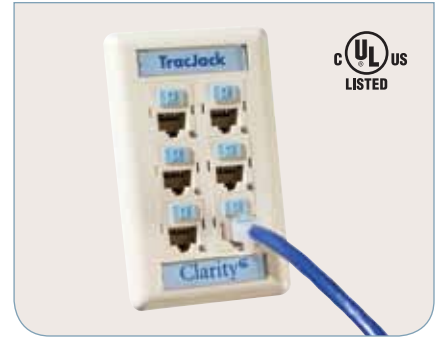

## Single Gang Plastic TracJack Faceplates

PART NO.	DESCRIPTION
OR-40300549	Holds one TracJack, 2.75" x 4.5"
OR-40300548	Holds two TracJacks, 2.75" x 4.5"
OR-40300547	Holds three TracJacks, 2.75" x 4.5"
OR-40300546	Holds four TracJacks, 2.75" x 4.5"
OR-40300545	Holds six TracJacks, 2.75" x 4.5"

NOTE: Standard color for plastic TracJack faceplates is fog white. For electrical ivory add -13, for white add -88 and for Wiremold® ivory add -99 to end of part number. For other colors, contact sales.

## Single Gang Stainless Steel TracJack Faceplates

PART NO.	DESCRIPTION
OR-403STJ11	Holds one TracJack, 2.75" x 4.5"
OR-403STJ12	Holds two TracJacks, 2.75" x 4.5"
OR-403STJ13	Holds three TracJacks, 2.75" x 4.5"
OR-403STJ14	Holds four TracJacks, 2.75" x 4.5"
OR-403STJ16	Holds six TracJacks, 2.75" x 4.5"

## Double Gang Plastic TracJack Faceplates

PART NO.	DESCRIPTION
OR-40300555	Holds six TracJacks, 4.5" x 4.5"
OR-40300554	Holds eight TracJacks, 4.5" x 4.5"
OR-40300620	Holds twelve TracJacks, 4.5" x 4.5"

NOTE: Standard color for plastic TracJack faceplates is fog white. For other colors, contact sales.

## Double Gang Stainless Steel TracJack Faceplates

PART NO.	DESCRIPTION
OR-403STJ28	Holds eight TracJacks, 4.5" x 4.5"
OR-403STJ212	Holds twelve TracJacks, 4.5" x 4.5"