



Decorator Devices Tamper-Resistant GFCI Receptacles

2 Pole, 3 Wire Grounding 15 & 20A, 125VAC


Pass & Seymour

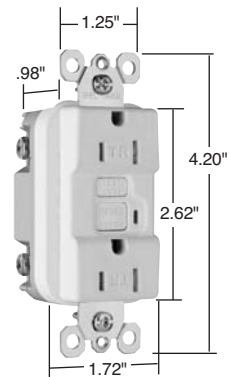

1595-TRWCC4

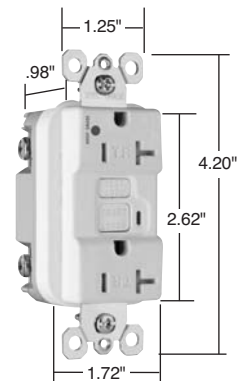

2095-HGTRW

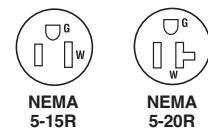

NEMA 5-15R

NEMA 5-20R

Features

- Protects children: patented, UL-Listed shutter system helps prevent improper insertion of foreign objects.
- Meets 2006 UL requirements.
- SafeLock™ Protection: if critical components are damaged and ground fault protection is lost, power to receptacle is disconnected.
- Prevents line-load reversal miswire: no power to the face or downstream receptacles if wired incorrectly.
- Exceeds UL943 voltage surge requirements; survives 100x the required UL 3kA/6kV voltage surge test cycles.
- FSUL Listed (Federal Specification WC596).
- Trip indicator light (red lamp).
- Side or internal screw-pressure-plate back wire with #10 – #14 AWG solid or stranded copper wire.
- Two back wire holes per terminal.
- Ground screw has a back wire clamp for easy installation.
- 1/4" thinner than competitors' GFCIs; leaves more room for wires in the box.
- Mounting screws are shipped captive in the device and wall plate for easier installation.
- High-impact-resistant thermoplastic construction.
- Extra-long strap.
- Button colors match the device face.
- Dual-direction test and reset buttons.
- Class A rated GFCI.
- Supplied with matching TP26 nylon wall plate.
- Tri-drive screws.

Specifications

- Supply Voltage: 125VAC, 60 Hz
- Supply Voltage Range: 102-132 VAC
- Trip Threshold: 5± 1mA
- Trip Time: 0.025 sec., nominal per UL Standard
- 20 Amp feed-thru capacity

Catalog Number	Rating A.	VAC	Color	NEMA Config. No.	3rd Party Compliance		
					UL943 C22.2 No. 144	UL498 C22.2 No. 42	FSUL WC596
NEW TradeMaster®/Spec Grade Tamper-Resistant 15 Amp Duplex GFCI							
1595-TRICC4	15	125	Ivory	5-15R	•	•	•
1595-TRWCC4	15	125	White	5-15R	•	•	•
1595-TRBKCC4	15	125	Black	5-15R	•	•	•
1595-TRLACC4	15	125	Light Almond	5-15R	•	•	•
NEW Specification Grade Tamper-Resistant 20 Amp Duplex GFCI							
2095-TRI	20	125	Ivory	5-20R	•	•	•
2095-TRW	20	125	White	5-20R	•	•	•
2095-TR	20	125	Brown	5-20R	•	•	•
2095-TRGRY	20	125	Gray	5-20R	•	•	•
2095-TRBK	20	125	Black	5-20R	•	•	•
2095-TRRED	20	125	Red	5-20R	•	•	•
2095-TRLA	20	125	Light Almond	5-20R	•	•	•
NEW Hospital Grade Tamper-Resistant 15 Amp Duplex GFCI							
1595-HGTRI	15	125	Ivory	5-15R	•	•	•
1595-HGTRW	15	125	White	5-15R	•	•	•
1595-HGTR	15	125	Brown	5-15R	•	•	•
1595-HGTRGRY	15	125	Gray	5-15R	•	•	•
1595-HGTRRED	15	125	Red	5-15R	•	•	•
1595-HGTRLA	15	125	Light Almond	5-15R	•	•	•
NEW Hospital Grade Tamper-Resistant 20 Amp Duplex GFCI							
2095-HGTRI	20	125	Ivory	5-20R	•	•	•
2095-HGTRW	20	125	White	5-20R	•	•	•
2095-HGTR	20	125	Brown	5-20R	•	•	•
2095-HGTRGRY	20	125	Gray	5-20R	•	•	•
2095-HGTRRED	20	125	Red	5-20R	•	•	•
2095-HGTRLA	20	125	Light Almond	5-20R	•	•	•

Available Spring 2006.

For Configurable Solutions, see Page U-1.

All devices listed on this page conform to NEMA WD-1 and WD-6.