


Pass &amp; Seymour

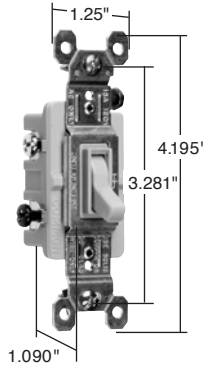

663IG

## Switches

# TradeMaster® Grounding Toggle Switches

15A, 120VAC

### Features

- Thermoplastic toggle and frame.
- Extra-long strap.
- High-impact resistant construction.
- Side wire #12 and #14 AWG.
- Push wire #14 AWG.
- Tri-drive ground, terminal and mounting screws.
- Easy-access green hex head ground screw.
- Smooth, quiet toggle action.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			UL20	C22.2 111
<b>Single Pole Toggle Switches</b> Grounding				
660IG*	15 120	Ivory	•	•
660WG*	15 120	White	•	•
660G*	15 120	Brown	•	•
660BKG	15 120	Black	•	•
660LAG*	15 120	Light Almond	•	•
<b>Single Pole Toggle Switches</b> Grounding (Without Ears)				
660IGMH	15 120	Ivory	•	•
660WGMH	15 120	White	•	•
660GMH	15 120	Brown	•	•
<b>Three-Way Toggle Switches</b> Grounding				
663IG**	15 120	Ivory	•	•
663WG**	15 120	White	•	•
663G**	15 120	Brown	•	•
663BKG	15 120	Black	•	•
663LAG**	15 120	Light Almond	•	•
<b>Three-Way Toggle Switches</b> Grounding (Without Ears)				
663IGMH	15 120	Ivory	•	•
663GMH	15 120	Brown	•	•
<b>Four-Way Toggle Switches</b> Grounding				
664IG	15 120	Ivory	•	•
664WG	15 120	White	•	•
664G	15 120	Brown	•	•
664BKG	15 120	Black	•	•
664LAG	15 120	Light Almond	•	•
🇨🇦 664ICN	15 120	Ivory	•	•
🇨🇦 664WCN	15 120	White	•	•
🇨🇦 Denotes Canadian catalog number. All Canadian products have Combination Slotted/Robertson Head Brass Screws.				

\*Available in bulk packs of 120. Add "U" to end of Catalog Number. Example: 660WGU.

\*\*Available in bulk packs of 90. Add "U" to end of Catalog Number. Example: 663WGU.