



Pass & Seymour

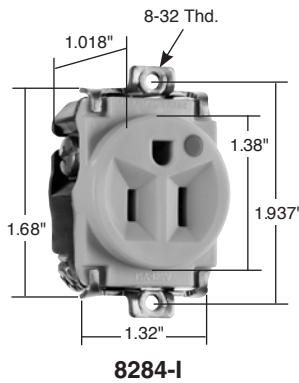

# Straight Blade Receptacles Hospital Grade Single Receptacles

15 & 20A, 125V; 20A, 250V

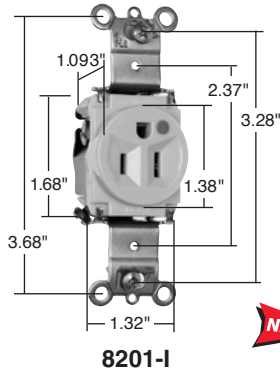

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL498	FSUL WC596	cUL/CSA
<b>Single Receptacles Back &amp; Side Wire</b>						
8201I	15 125	Ivory	5-15R	•	•	•
8201W	15 125	White	5-15R	•	•	•
8201	15 125	Brown	5-15R	•	•	•
8201GRY	15 125	Gray	5-15R	•	•	•
8201BK	15 125	Black	5-15R	•	•	•
8201RED	15 125	Red	5-15R	•	•	•
8201LA	15 125	Light Almond	5-15R	•	•	•
8301I	20 125	Ivory	5-20R	•	•	•
8301W	20 125	White	5-20R	•	•	•
8301	20 125	Brown	5-20R	•	•	•
8301GRY	20 125	Gray	5-20R	•	•	•
8301RED	20 125	Red	5-20R	•	•	•
8801I	20 250	Ivory	6-20R	•	•	•
8801W	20 250	White	6-20R	•	•	•
8801	20 250	Brown	6-20R	•	•	•
8801GRY	20 250	Gray	6-20R	•	•	•
8801RED	20 250	Red	6-20R	•	•	•
<b>Short Strap Single Receptacles 1.937" Screw Spacing, Back &amp; Side Wire</b>						
8284I	15 125	Ivory	5-15R	•	•	•
8284	15 125	Brown	5-15R	•	•	•
8384I	20 125	Ivory	5-20R	•	•	•
8384	20 125	Brown	5-20R	•	•	•

For Hospital Use Power Interrupting Device consult Turnlok® Section I.

2 Pole, 3 Wire



NEMA  
5-15R



NEMA  
5-20R



NEMA  
6-20R