

Straight Blade Receptacles TradeMaster® Decorator Receptacles


15A, 125V

Pass & Seymour



Straight Blade Receptacles

Features	
<ul style="list-style-type: none"> ■ High impact-resistant thermoplastic construction. ■ Extra-long strap. ■ Quickloop wire looping aid. ■ Long-term blade retention. ■ Tri-drive screws. ■ Extra-large circuit break-off tabs. 	<ul style="list-style-type: none"> ■ Side-access push wire release. ■ Ultrasonic welding of face to back body. ■ Side wire accepts #12 – #14 AWG solid. ■ Push wire accepts #14 AWG solid only. ■ Self-grounding models provide automatic ground clip.

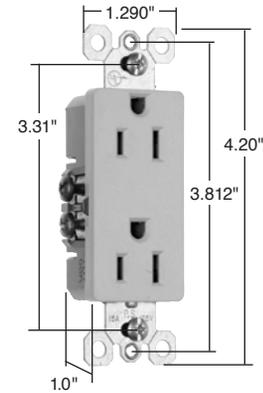


885I

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance	
				UL498	C22.2 42
Decorator Duplex Receptacles					
885I	15 125	Ivory	5-15R	•	•
885W	15 125	White	5-15R	•	•
885	15 125	Brown	5-15R	•	•
885BK	15 125	Black	5-15R	•	•
885LA	15 125	Light Almond	5-15R	•	•
Self-Grounding Decorator Duplex Receptacles					
885SI	15 125	Ivory	5-15R	•	•
885SW	15 125	White	5-15R	•	•
885SLA	15 125	Light Almond	5-15R	•	•

For Configurable Solutions, see Page U-1.

Features	
<ul style="list-style-type: none"> ■ Longer steel straps than competitive devices, still fits under a standard wall plate. ■ High-impact thermoplastic face and back body eliminate cracks, breaks and callbacks. ■ Ultrasonic welding of face to back body. ■ Patented design provides better plug retention. ■ External screw-pressure-plate back wire on all four terminal screws and ground screw eliminates wrapping. 	<ul style="list-style-type: none"> ■ Accepts #12 and #14 stranded and solid wire. ■ Break-off tabs that are big enough to grab hold of – even if the contact screws are backed-out. Scored deeper, for fast, clean breaks every time. ■ All four contact screws and the ground screw are backed-out. ■ All screws are tri-drive.

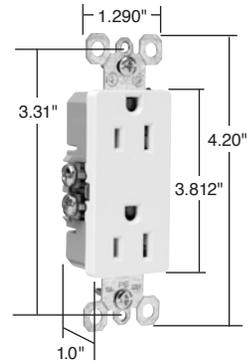

TM885W

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance
				cULUS UL498
Decorator Duplex Receptacles with Pressure Plates				
TM885I	15 125	Ivory	5-15R	•
TM885W	15 125	White	5-15R	•
TM885	15 125	Brown	5-15R	•
TM885GRY	15 125	Gray	5-15R	•
TM885BK	15 125	Black	5-15R	•
TM885LA	15 125	Light Almond	5-15R	•
Decorator Duplex Receptacles with Pressure Plates Self-Grounding				
TM885SI	15 125	Ivory	5-15R	•
TM885SW	15 125	White	5-15R	•
TM885SLA	15 125	Light Almond	5-15R	•
Decorator Duplex Receptacles with Pressure Plates Bulk Pack of 150				
TM885I150	15 125	Ivory	5-15R	•
TM885W150	15 125	White	5-15R	•
TM885LA150	15 125	Light Almond	5-15R	•

2 Pole, 3 Wire



**NEMA
5-15R**

All devices listed on this page conform to NEMA WD-1 and WD-6.

TradeMaster® Receptacles