


# Specialties Decorator Hallway Lights & Combination Devices

**Pass & Seymour**




Wall Plates & Specialties


Features	
<ul style="list-style-type: none"> <li>Impact-resistant face and body.</li> <li>GE Lexan™ high impact-resistant lens.</li> <li>External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.</li> <li>Ground screw position under the end of the strap minimizes the risk of contact.</li> <li>Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement.</li> <li>Sensor automatically turns light ON in the dark.</li> </ul>	<ul style="list-style-type: none"> <li>Increased light output for better illumination.</li> <li>Light sensor for enhanced sensitivity.</li> </ul> <p><b>Tamper-Resistant Combination Version:</b></p> <ul style="list-style-type: none"> <li>UL tested shutter mechanism for protection against improper object insertion per UL478.</li> <li>Specially designed for increased protection of children in their homes.</li> <li>Superior protection than traditional outlet “caps” or “protection plates.”</li> </ul>

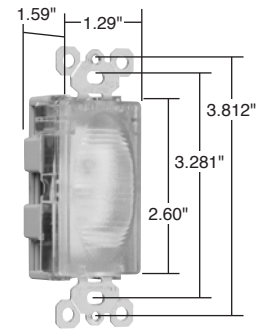


**TMHWLCC**

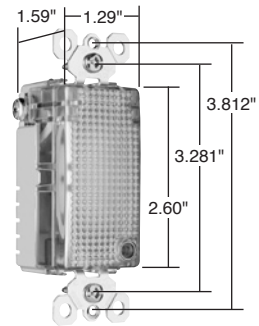

**TMHWLECC**

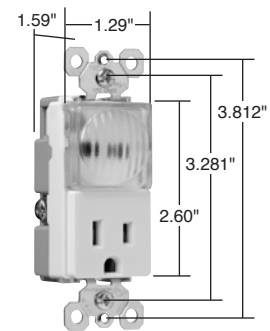

**TM8HWLWCC**

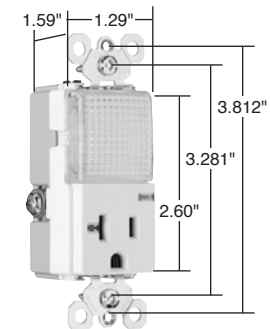

**PS8HWLLA**

Hallway Lights & Combination Devices

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance	
					UL1598
<b>TradeMaster® Decorator Full Hallway Light</b>					
TMHWLCC	— 120	0.1328	Clear		•
<b>Enhanced Decorator Full Hallway Light with Light Sensor</b>					
TMHWLECC	— 120	1.079	Clear		•
<b>Enhanced Decorator Full Hallway Light without Light Sensor</b>					
TMHWLENSCC	— 120	1.113	Clear		•
<b>Full Hallway Decorator Light for use with P&amp;S Metal Louver Plates**</b>					
TMHWLLOUVCC	— 120	0.0843	Clear		•

\*FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See page U-55 for more information.

\*\*For Louver Plates, see Page S-19.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance	
						UL498
<b>TradeMaster® Decorator Hallway Light &amp; Single Receptacle</b>						
TM8HWLIC	15 120/125	0.1442	Ivory	5-15R		•
TM8HWLWCC	15 120/125	0.1442	White	5-15R		•
TM8HWLBKCC	15 120/125	0.1442	Black	5-15R		•
TM8HWLCC	15 120/125	0.1442	Brown	5-15R		•
TM8HWLLACC	15 120/125	0.1442	Light Almond	5-15R		•
<b>Enhanced Decorator Hallway Light &amp; Single Receptacle</b>						
TM8HWLEICC	15 120/125	0.2561	Ivory	5-15R		•
TM8HWLEWCC	15 120/125	0.2561	White	5-15R		•
TM8HWLELACC	15 120/125	0.2561	Light Almond	5-15R		•
<b>Specification Grade Enhanced Decorator Hallway Light &amp; Single Receptacle</b>						
PS8HWLI	20 120/125	0.2561	Ivory	5-20R		•
PS8HWLW	20 120/125	0.2561	White	5-20R		•
PS8HWLLA	20 120/125	0.2561	Light Almond	5-20R		•
<b>TradeMaster® Enhanced Decorator Hallway Light &amp; Tamper-Resistant Single Receptacle</b>						
TM8HWLTRICC	15 120/125	0.2561	Ivory	5-15R		•
TM8HWLTRWCC	15 120/125	0.2561	White	5-15R		•
TM8HWLTRBKCC	15 120/125	0.2561	Black	5-15R		•
TM8HWLTRCC	15 120/125	0.2561	Brown	5-15R		•
TM8HWLTRLACC	15 120/125	0.2561	Light Almond	5-15R		•

\*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See page U-55 for more information.

For complete line of Decorator Combination Devices, see Pages E-7 – E-11, E-17, E-18, E-21, E-30, E-36, and E-72.

All devices listed on this page conform to NEMA WD-1 and WD-6.