




Pass & Seymour

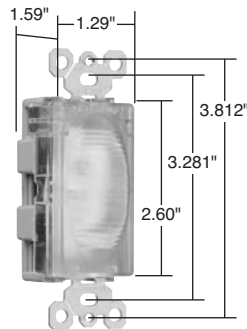


TMHWL-CC

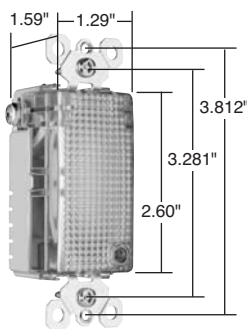

TMHWL-ECC

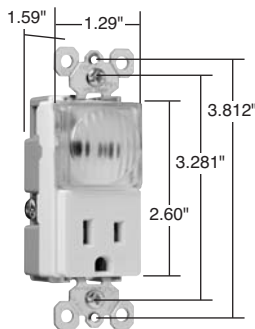

TM8HWL-WCC

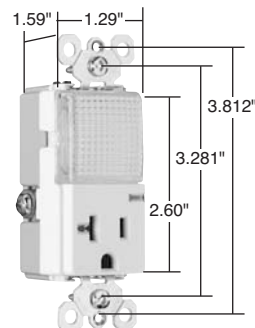

PS8HWL-LA

Specialties

Decorator Hallway Lights & Combination Devices

Features

- Impact-resistant face and body.
 - GE Lexan™ high impact-resistant lens.
 - External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
 - Ground screw position under the end of the strap minimizes the risk of contact.
 - Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement.
 - Sensor automatically turns light ON in the dark.
 - Increased light output for better illumination.
 - Light sensor for enhanced sensitivity.
- Tamper-Resistant Combination Version:*
- UL tested shutter mechanism for protection against improper object insertion per UL478.
 - Specially designed for increased protection of children in their homes.
 - Superior protection than traditional outlet “caps” or “protection plates.”

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	3rd Party Compliance	
				cULUS	UL1598
TradeMaster® Decorator Full Hallway Light					
TMHWL-CC	— 120	0.1328	Clear		•
Enhanced Decorator Full Hallway Light with Light Sensor					
TMHWL-ECC	— 120	1.079	Clear		•
Enhanced Decorator Full Hallway Light without Light Sensor					
TMHWL-ENSCC	— 120	1.113	Clear		•
Full Hallway Decorator Light for use with P&S Metal Louver Plates**					
TMHWL-LOUVCC	— 120	0.0843	Clear		•

*FCD = Foot Candle Distance, 1 Lumen = 1 FCD. See page U-42 for more information.

**For Louver Plates, see Page S-19.

Catalog Number	Rating A. VAC	Light Output In 1' FCD*	Color	NEMA Config. No.	3rd Party Compliance	
					cULUS	UL498
TradeMaster® Decorator Hallway Light & Single Receptacle						
TM8HWL-ICC	15 120/125	0.1442	Ivory	5-15R		•
TM8HWL-WCC	15 120/125	0.1442	White	5-15R		•
TM8HWL-BKCC	15 120/125	0.1442	Black	5-15R		•
TM8HWL-CC	15 120/125	0.1442	Brown	5-15R		•
TM8HWL-LACC	15 120/125	0.1442	Light Almond	5-15R		•
Enhanced Decorator Hallway Light & Single Receptacle						
TM8HWL-EICC	15 120/125	0.2561	Ivory	5-15R		•
TM8HWL-EWCC	15 120/125	0.2561	White	5-15R		•
TM8HWL-ELACC	15 120/125	0.2561	Light Almond	5-15R		•
Specification Grade Enhanced Decorator Hallway Light & Single Receptacle						
PS8HWL-I	20 120/125	0.2561	Ivory	5-20R		•
PS8HWL-W	20 120/125	0.2561	White	5-20R		•
PS8HWL-LA	20 120/125	0.2561	Light Almond	5-20R		•
TradeMaster® Enhanced Decorator Hallway Light & Tamper-Resistant Single Receptacle						
TM8HWLTR-ICC	15 120/125	0.2561	Ivory	5-15R		•
TM8HWLTR-WCC	15 120/125	0.2561	White	5-15R		•
TM8HWLTR-BKCC	15 120/125	0.2561	Black	5-15R		•
TM8HWLTR-CC	15 120/125	0.2561	Brown	5-15R		•
TM8HWLTR-LACC	15 120/125	0.2561	Light Almond	5-15R		•

*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See page U-42 for more information.

For complete line of Decorator Combination Devices, see Pages D-6 – D-10, D-17, D-19, D-25, and D-26.

All devices listed on this page conform to NEMA WD-1 and WD-6.