
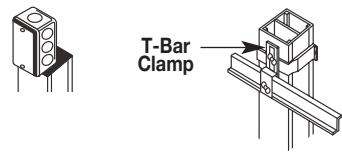


Aluminum Tele-Power Poles (continued)




 
Aluminum Tele-Power Poles Ordering Information

Catalog No./Item	Description/Specifications															
<p>NP600 NP620</p>  	<p>Tele-Power Pole – Two-compartment pole (power and communications). Nominal wall thickness .050" [1.8mm]. Factory wired with two duplex receptacles and a utility box (10' [3m] power cord in Canada only). An opening for communications is provided at top. Removable front cover for making wire connection. All mounting and trim hardware included. 30" [762mm] communication cover includes two rectangular KOs and one mouse hole.</p>															
<p>PART NUMBER MATRIX</p> <p>EXAMPLE: NP600-2-10-2B</p> <table style="width: 100%; text-align: center; border-collapse: collapse;"> <tr> <td style="border-bottom: 1px solid black;">NP6</td> <td style="border-bottom: 1px solid black;">00</td> <td style="border-bottom: 1px solid black;">2</td> <td style="border-bottom: 1px solid black;">10-2</td> <td style="border-bottom: 1px solid black;">B</td> </tr> <tr> <td>Series:</td> <td>Device Amperage:</td> <td>Wired/Unwired:</td> <td>Length:</td> <td>End Option:</td> </tr> <tr> <td></td> <td>00 = 15A 20 = 20A</td> <td>2 = # of Duplexes C = Unwired</td> <td>XX = FT X = IN</td> <td>B = Box Ended Blank = Cord Ended (Cord ended version only available in Canada for NP600 Series – MTO)</td> </tr> </table> <p>NOTE: For a complete list of part numbers, see the charts on page 6 for wired and page 7 for vertical drop Aluminum Tele-Power Poles.</p>		NP6	00	2	10-2	B	Series:	Device Amperage:	Wired/Unwired:	Length:	End Option:		00 = 15A 20 = 20A	2 = # of Duplexes C = Unwired	XX = FT X = IN	B = Box Ended Blank = Cord Ended (Cord ended version only available in Canada for NP600 Series – MTO)
NP6	00	2	10-2	B												
Series:	Device Amperage:	Wired/Unwired:	Length:	End Option:												
	00 = 15A 20 = 20A	2 = # of Duplexes C = Unwired	XX = FT X = IN	B = Box Ended Blank = Cord Ended (Cord ended version only available in Canada for NP600 Series – MTO)												

Aluminum Vertical Drop Poles

A full range of accessories enables fast and easy field configurability. Additional receptacles or devices can be added to existing poles for maximum flexibility. The NP800 pole is the epitome of flexibility, featuring a snap-in divider which permits up to six channels of varying sizes and accommodates up to 60A devices (#6 AWG max). The NP800 may be wired with up to 12 receptacles with the number of circuits limited by the feed method.

Aluminum Vertical Drop Poles Ordering Information

Catalog No./Item	Description/Specifications	Catalog No./Item	Description/Specifications
<p>AMTC-4 AMTC-412 AMTC-415</p> <p>CUSTOM OPTIONS: Features such as colors or other lengths (20' [6.1m] maximum) available on custom orders.</p> 	<p>Blank Aluminum Pole – Two-compartment pole. Nominal material thickness .050" [1.8mm]. Furnished unwired without outlets. Two 8" [203mm] removable covers with KOs for modular jacks and modular furniture communication outlets. Mounting hardware, entrance end plate, and ceiling trim plates furnished. Available lengths: 10' 5" [3.2m] (AMTC-4), 12' 5" [3.8m] (AMTC-412) and 15' 5" [4.7m] (AMTC-415).</p>	<p>NP800C-10-2B</p> 	<p>Blank Aluminum Pole – Two-compartment large capacity pole. Furnished unwired without outlets. Box ended with industry sized knockouts. Standard heights: 10'2" [3.1m] (NP800C-10-2B), 12'8" [3.9m] (NP800C-12-8B), 15'2" [4.6m] (NP800C-15-2B).</p> <p>Other heights available – consult factory. 30" [762mm] communication cover with industry standard knockouts.</p>
<p>NP600C-10-2B NP600C-12-8B NP600C-15-2B</p> 	<p>Blank Aluminum Pole – Two-compartment pole. Furnished unwired without outlets. Box ended (not shown) with industry sized knockouts. Standard heights: 10'2" [3.1m] (NP600C-10-2B), 12'8" [3.9m] (NP600C-12-8B), 15'2" [4.6m] (NP600C-15-2B).</p> <p>Other heights available – consult factory. 30" [762mm] communication cover with industry standard knockouts.</p>	<p>ALTC-2S ALTC-20W ALTC-2P</p> 	<p>Blank Round Aluminum Pole – Nominal wall thickness .060" [1.5mm], length 10'3" [3.1m]. ALTC-2S has satin anodized finish, ALTC-20W has painted white finish, and ALTC-2P has a polished aluminum finish. Provided with one 1/2" [12.7mm] trade size KO at base. T-bar mounting hardware, ceiling trim kit, foot assembly, and grommet included. Feed box not furnished.</p>