 
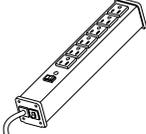
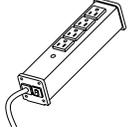
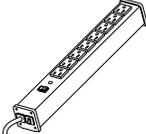
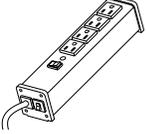
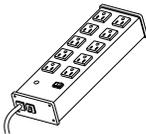
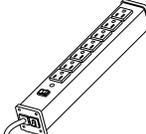
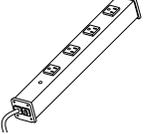
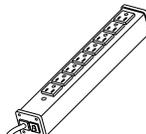
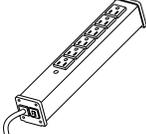
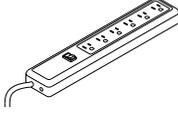
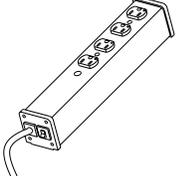
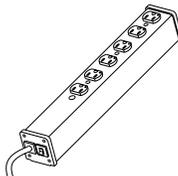


Compact Plug-In Outlet Centers

Catalog No./Item	Description/Specifications	Catalog No./Item	Description/Specifications
 <p>UL100BC/UL100BD Compact Plug-In Outlet Center – Five outlets, 6' [1.8m] or 15' [4.6m] cord. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>UL207BC/UL207BD Compact Plug-In Outlet Center – Six outlets, lighted switch. 6' [1.8m] or 15' [4.6m] cord. Length 12 1/4" [311mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>		
 <p>UL101BC/UL101BD Compact Plug-In Outlet Center – Four outlets, 6' [1.8m] or 15' [4.6m] cord. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>UL218BC/UL218BD Compact Plug-In Outlet Center – Eight outlets, lighted switch. 6' [1.8m] or 15' [4.6m] cord. Length 15" [381mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>		
 <p>UL104BC/UL104BD Compact Plug-In Outlet Center – Four outlets, lighted switch. 6' [1.8m] or 15' [4.6m] cord. Length 9 1/4" [235mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>UL210BC/UL210BD Compact Plug-In Outlet Center – Ten outlets, lighted switch. Putty white finish. 6' [1.8m] or 15' [4.6m] cord. Length 13" [330mm]. Width 3 1/2" [89mm]. Receptacle center-to-center 1 15/16" [49mm].</p> <p style="text-align: right;"> </p>		
 <p>UL204BC/UL204BD Compact Plug-In Outlet Center – Seven outlets, lighted switch. 6' [1.8m] or 15' [4.6m] cord. Length 13" [330mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>UL1090BC/UL1090BD Compact Plug-In Outlet Center – Four outlets. Receptacles rotated 90° and spaced to accommodate transformers. 6' [1.8m] or 15' [4.6m] cord. Length 16" [406mm]. Receptacle center-to-center 3" [76mm].</p> <p style="text-align: right;"> </p>		
 <p>UL205BC/UL205BD Compact Plug-In Outlet Center – Eight outlets, 6' [1.8m] or 15' [4.6m] cord. Length 13" [330mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>R610/R612 Compact Plug-In Outlet Center – Six outlets, lighted switch. Putty white finish, 6' [1.8m] or 15' [4.6m] cord. Length 12 1/4" [311mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>		
 <p>UL206BC/UL206BD Compact Plug-In Outlet Center – Six outlets. 6' [1.8m] or 15' [4.6m] cord. Length 12 1/4" [311mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>	 <p>P6/P6-15 Compact Plug-In Outlet Center – Six outlets, lighted switch. Putty white finish, plastic housing. 6' [1.8m] or 15' [4.6m] cord. Length 12" [305mm]. Receptacle center-to-center 1 1/4" [32mm].</p> <p style="text-align: right;"> </p>		

Special Use Plug-In Outlet Center Units

Catalog No./Item	Description/Specifications	Catalog No./Item	Description/Specifications
 <p>ULBH4-6/ULBH4-15 Special Use Plug-In Outlet Center – Four outlets, white finish. 6' [1.8m] or 15' [4.6m] cord. Length 10 3/4" [237mm]. Receptacle center-to-center 1 1/2" [38mm].</p> <div style="border: 1px solid black; padding: 5px; margin: 10px 0;"> <p style="text-align: center;">IMPORTANT Not for use in critical care environments.</p> </div> <p style="text-align: right;"> </p>	 <p>ULBH6-6/ULBH6-15 Special Use Plug-In Outlet Center – Six outlets, white finish. 6' [1.8m] or 15' [4.6m] cord. Length 13 1/4" [337mm]. Receptacle center-to-center 1 1/2" [38mm].</p> <div style="border: 1px solid black; padding: 5px; margin: 10px 0;"> <p style="text-align: center;">IMPORTANT Not for use in critical care environments.</p> </div> <p style="text-align: right;"> </p>		

Plug-In Outlet Center® Units

Bring power safely and conveniently to wherever you need it with a full line of standard and custom Plug-In Outlet Centers from Wiremold. These units are ideal for use in a wide variety of settings, including relay racks and cabinets, laboratories, workshops, classrooms and offices.

Plug-In Outlet Centers include rack mount, CabinetMATE, compact, 90 degree, deluxe control, industrial, and international units. Most units are available in both 15 and 20 Amp configurations.



JO880B (Front & Back)



UL207BC



ULBH6-6



P6

Features & Benefits

- **User-ready outlets.** Plug-In Outlet Center units provide power distribution in a portable, plug-in unit.
- **Rugged construction.** Durable 2" x 1 3/4" [44mm x 51mm] or 3 1/2" x 2" [89mm x 44mm] aluminum housing. Some Plug-In Outlet Center units are available with an impact-resistant plastic housing.
- **Space saving.** Rack mount units fit standard 19" [482mm] relay racks. Compact 1U design takes up minimum space. 23" [584mm] units available, consult factory.
- **Low profile.** CabinetMATE units offer a narrow 1 1/2" x 1 3/16" [38mm x 20mm] aluminum housing.
- **Aesthetically pleasing.** Rack mount units have a black matte finish and a black cord. CabinetMATE, compact and industrial units have a gray finish and a black cord. Deluxe control and 20A units have a putty white finish and a black cord. Most units with a putty white finish have a putty white cord. Special Use units have a white finish and a white cord.
- **Flexible mounting.** Each unit features one of four different mounting types. Each mounting method has been designed to optimize the performance of the product. Complete mounting hardware and installation instructions are included with every unit.
- **Cord properly rated to load requirements.** 15A units have a 14/3 SJT cord and a NEMA 5-15P plug. 20A units have a 12/3 SJT cord and a NEMA 5-20P or NEMA L5-20P plug.
- **Lighted switch.** Most units have lighted on/off switch(es) to control power to the unit.
- **Resettable circuit breaker.** Provides overload protection.
- **Two-Year product warranty.**
- **UL Recognized or Listed and CSA Certified.** Rack mount units are UL Recognized components. All other units are UL Listed and meet UL1363 standards. All 15A units are also CSA Certified.