


Pass & Seymour




# Plastic Boxes Floor Box Assembly


2 Pole, 3 Wire Grounding 15A, 125V

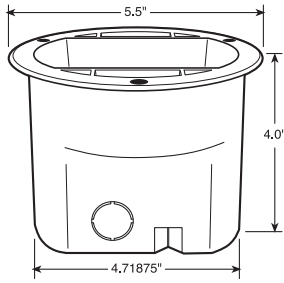


TM1542-BOX

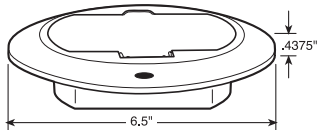

TM1542-LA\*

 


TM1542-FM

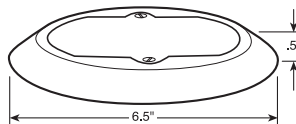


TM1542-CF

\*See available colors at left.

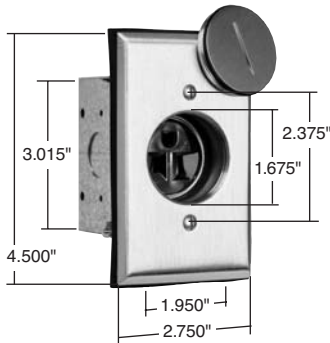

1542-FBA

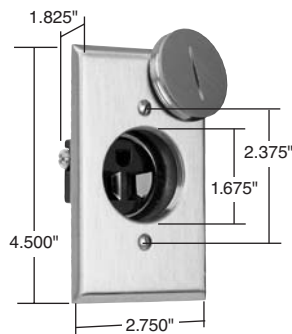

1542-DR

### Features

- Hinged door is removable and easily replaceable.
- Durable construction, impact and scratch resistant PVC construction.
- Standard Decorator opening that accepts GFCI, TVSS, DataCom or other Decorator devices.
- Auto/Clamps® and knockouts on both sides of box.
- Meets UL514(c) scrub water exclusion test.
- Threaded device mounting holes.
- Simple mounting box, fits into a 4-3/4" hole and mounts with 3 screws included.
- Ready for low-voltage wiring, drill guides on underside of cover.
- UL and CUL Listed.
- Captive screws on TM1542 series – screws will not be lost – new.
- Made in USA.

Catalog Number	Description	Color	NEMA Config. No.
<b>Floor Box</b>			
TM1542-BOX	38 cu. in., with knockouts and Auto/Clamps®, 3 screws for mounting to floor.	Gray	5-15R
<b>Thermoplastic Covers</b>			
TM1542-W	Includes 15A, 125V Decorator receptacle, matching detachable and replaceable hinged door; threaded device-mounting holes; drill guides for low-voltage poke-through holes; accepts any Decorator device; mounts on carpeting, hardwood, linoleum, tile floors; 4 mounting/leveling screws.	White	5-15R
TM1542-BR		Brown	5-15R
TM1542-GRY		Gray	5-15R
TM1542-N		Paintable Gray	5-15R
TM1542-BK		Black	5-15R
TM1542-LA		Light Almond	5-15R
<b>Brass Covers</b>			
TM1542-FM	Low-profile cover requires minimum 3/8" hardwood floor thickness.	Brass	5-15R
TM1542-CF	High-profile cover fits any floor finish – including carpeting, linoleum, tile, etc. Both covers include a Brown 15A, 125V Decorator receptacle and will accept any Decorator device. Covers include captive screws to prevent loss.	Brass	5-15R

UL listed in accordance with 314.27(e).

### Features

- Solid brass covered plate with matching flush fitting brass cap.
- 15A, 125V receptacle made of durable thermoplastic.
- UL and FSUL listed.

Catalog Number	Rating A. V.	Description	Color	NEMA Config. No.
<b>Floor Box Assembly</b>				
1542-FBA	15 125	Receptacle, brass plate, plug, gasket, O-ring, and metal 18 cu. in. box	Brown	5-15R

UL listed in accordance with 314.27(e). Conforms to NEMA OS2.

### Display Receptacle

1542-DR	15 125	Receptacle, brass plate and plug	Brown	5-15R
---------	--------	----------------------------------	-------	-------

UL listed in accordance with 314.27(e) exception.

**2005 National Electrical Code® Section 314.27(e) Floor Boxes** Boxes listed specifically for this application shall be used for receptacles located in the floor. Exception: Boxes located in elevated floors of show windows and similar locations where the authority having jurisdiction judges them to be free from physical damage, moisture, and dirt. Receptacles and covers shall be listed as an assembly for this type of location. The products used in this application are identified as display receptacles.