


Straight Blade Devices Hard Use Receptacles Specification Grade


15 & 20A, 125 & 250V

Features

- Impact-resistant nylon face & thermoplastic back body.
- Corrosion-resistant, plated steel strap locked in to face & back body to resist pulling away from face/body assembly.
- 8 hole back wire terminals accept #10 - 14 AWG solid or stranded copper or copper-clad conductors (5252 series only).
- Terminal compartments isolated from each other for positive conductor containment.
- Easily accessible break-off tab on line contact for split circuit wiring.
- One-piece, triple-wipe brass power contact.
- Automatic grounding to metallic boxes.

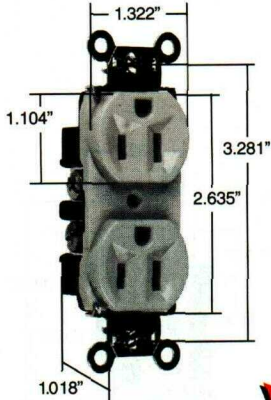



Duplex Receptacle

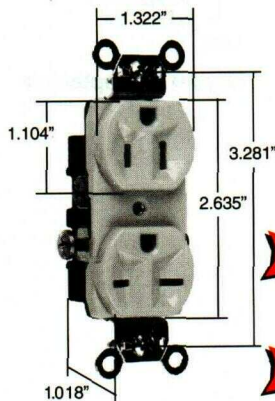

Combination Duplex Receptacle



2-Pole 3-Wire

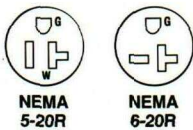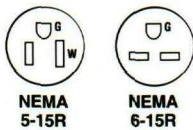

All devices listed on this page conform to NEMA WD-1.

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance		
				UL498	FSUL WC596-G	CS C22.2 42M
Duplex Receptacles Back & Side Wire						
5252-I	15 125	Ivory	5-15R	•	•	•
5252-W	15 125	White	5-15R	•	•	•
5252	15 125	Brown	5-15R	•	•	•
5252-GRY	15 125	Gray	5-15R	•	•	•
5252-BK	15 125	Black	5-15R	•	•	•
5252-LA	15 125	Lt. Almond	5-15R	•	•	•
✦ 5252-ICN	15 125	Ivory	5-15R			•
✦ 5252-WCN	15 125	White	5-15R			•
✦ 5252-CN	15 125	Brown	5-15R			•
✦ 5252-GRYCN	15 125	Gray	5-15R			•
✦ 5252-BKCN	15 125	Black	5-15R			•
✦ 5252-REDCN	15 125	Red	5-15R			•
5352-I	20 125	Ivory	5-20R	•	•	•
5352-W	20 125	White	5-20R	•	•	•
5352	20 125	Brown	5-20R	•	•	•
5352-GRY	20 125	Gray	5-20R	•	•	•
5352-BK	20 125	Black	5-20R	•	•	•
5352-LA	20 125	Lt. Almond	5-20R	•	•	•
5652-I	15 250	Ivory	6-15R	•	•	•
5652	15 250	Brown	6-15R	•	•	•
5652-BK	15 250	Black	6-15R	•	•	•
5652-LA	15 250	Lt. Almond	6-15R	•	•	•
Duplex Receptacles Side Wire Only						
5242-I	15 125	Ivory	5-15R	•	•	•
5242-W	15 125	White	5-15R	•	•	•
5242	15 125	Brown	5-15R	•	•	•
5242-GRY	15 125	Gray	5-15R	•	•	•
✦ 5242-ICN	15 125	Ivory	5-15R			•
✦ 5242-WCN	15 125	White	5-15R			•
✦ 5242-CN	15 125	Brown	5-15R			•
✦ 5242-GRYCN	15 125	Gray	5-15R			•
5342-I	20 125	Ivory	5-20R	•	•	•
5342-W	20 125	White	5-20R	•	•	•
5342	20 125	Brown	5-20R	•	•	•
5342-GRY	20 125	Gray	5-20R	•	•	•
5342-BK	20 125	Black	5-20R	•	•	•
✦ 5342-ICN	20 125	Ivory	5-20RCN			•
✦ 5342-WCN	20 125	White	5-20RCN			•
✦ 5342-CN	20 125	Brown	5-20RCN			•
5642-I	15 250	Ivory	6-15R	•	•	•
5642	15 250	Brown	6-15R	•	•	•
5290-I	15 125/250	Combination, Ivory	5/6-15R	•	•	•
5290	15 125/250	Combination, Brown	5/6-15R	•	•	•
5890-I	20 125/250	Combination, Ivory	5/6-20R	•	•	•
5890	20 125/250	Combination, Brown	5/6-20R	•	•	•

✦ Denotes Canadian catalog number. All Canadian products have Combination Slotted/Robertson Head Brass Screws.