


10-way RJ45 Telephone Module with RJ31X

TM1045

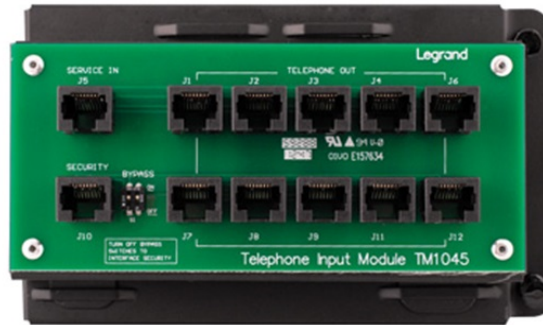

This telephone module distributes up to 4 incoming telephone lines (RJ45) to 10 locations.

features & benefits

- Supports up to 10 locations
- Includes RJ31X line seizure port for security installations
- Mounting bracket included
- UL listed

specifications

General Info

Color: Black
Connection Type: Phosphor Bronze contacts, plated Gold over Nickel
Type: Telecom Module
Input Plug Type: RJ45 Male

Listing Agencies/Third Party Information

UL Standard: Yes
UN SPS C: 43222819

Dimensions

Height Metric: 7.9 cm
Height U S: 3.1"
Length U S: 4.1 cm
Length Metric: 1.6"
Product Weight U S: 1.01 pounds
Width Metric: 14.7 cm

Width U S: 5.78 in

Technical Information

Connection Method: RJ45, RJ31X
Material: 18 Gauge Cold Rolled Steel
Mounting: Enclosure
Receptacle Type: RJ45, RJ31X
Number Of Receptacles: 12