


Pass & Seymour



# Decorator Devices Decorator & Specification Grade Combination Momentary & Maintained Contact Switches

15A, 120 & 120/277VAC

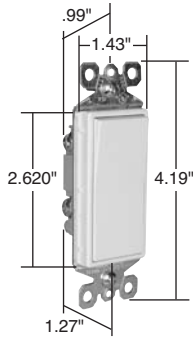


TM870-STMLACC

Features	
<ul style="list-style-type: none"> <li>Designer-style satin-finish rocker.</li> <li>High-impact resistant thermoplastic construction.</li> <li>External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.</li> <li>Push wire #14 AWG.</li> <li>Narrow back body leaves more room for wires in the box.</li> </ul>	<ul style="list-style-type: none"> <li>Extra-long, through-body strap eliminates floating installations and imperfect applications.</li> <li>Smooth, quiet paddle action.</li> <li>Easy-access green hex head ground screw.</li> <li>Tri-drive ground, terminal and mounting screws.</li> </ul>


Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			UL UL20	SP C22.2 111
<b>Single Pole Decorator Momentary Contact Switches</b>				
TM870-STMICC	15 120/277	Ivory	•	•
TM870-STMWCC	15 120/277	White	•	•
TM870-STMLACC	15 120/277	Light Almond	•	•
TM870-STMBKCC	15 120/277	Black	•	•



Features	
<ul style="list-style-type: none"> <li>Unique "Up/Down" switches match the look and feel of standard decorator switches.</li> <li>Impact-resistant face and body.</li> <li>Side and external screw-pressure-plate back wire accepts #12 and #14 AWG.</li> <li>All screws are tri-drive.</li> </ul>	<ul style="list-style-type: none"> <li>Full wraparound heavy-gauge steel strap is plated for corrosion resistance and features lock-in tabs.</li> <li>Patent-pending split circuit tab — easily accessible, and can be reinstalled without a tool.</li> </ul>

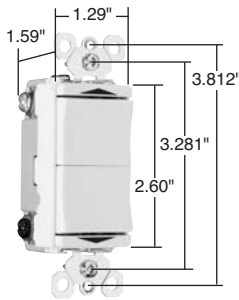

Momentary Contact

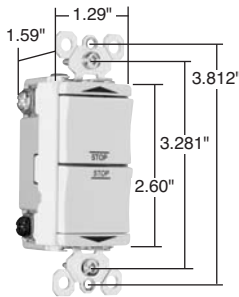

Maintained Contact

Catalog Number	Rating A. VAC	Color	3rd Party Compliance		
			cULus cULus	UL UL20	UL UL508
<b>NEW Specification Grade Double Throw Momentary Contact Switches</b>					
TM811-DTMOI	15 120	Ivory	•	•	•
TM811-DTMOW	15 120	White	•	•	•
TM811-DTMOLA	15 120	Light Almond	•	•	•
<b>NEW Specification Grade Double Throw Maintained Contact Switches</b>					
TM811-DTMAI	15 120	Ivory	•	•	•
TM811-DTMAW	15 120	White	•	•	•
TM811-DTMALA	15 120	Light Almond	•	•	•


# Decorator Devices Specification Grade Decorator Combination Switches

20A, 277VAC

Pass & Seymour



- | Features  |  |
|---|--|
| <ul style="list-style-type: none"> <li>Unique "Up/Down" switches match the look and feel of standard decorator switches.</li> <li>Impact-resistant face and body.</li> <li>Side and external screw-pressure-plate back wire accepts #12 and #14 AWG.</li> <li>All screws are tri-drive.</li> <li>Full wraparound heavy-gauge steel strap is plated for corrosion resistance and features lock-in tabs.</li> </ul> | <ul style="list-style-type: none"> <li>Patent-pending split circuit tab — easily accessible, and can be reinstalled without a tool.</li> <li>Patent-pending snap-in light module (sold separately) transforms a combination switch into an illuminated switch.</li> <li>Identification modules (sold separately) identifies each switch — light, fan, heat lamp. See Page A-20 for details.</li> </ul> |

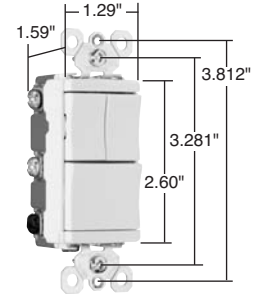

15 & 20 Amp

Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			cULus	UL20
<b>NEW Two Single Pole Switches</b>				
PS811-20I	20 277	Ivory	•	•
PS811-20W	20 277	White	•	•
PS811-20LA	20 277	Light Almond	•	•
<b>NEW Three Single Pole Switches</b>				
PS8111-20I	20 277	Ivory	•	•
PS8111-20W	20 277	White	•	•
PS8111-20LA	20 277	Light Almond	•	•
<b>NEW Snap-In Light Module*</b>				
PS8LM	— —	Clear		

\*For use with PS811-20 and PS8111-20 only.

Pass & Seymour



# Decorator Devices TradeMaster® Decorator Combination Switches




**Unique "Up/Down" switches** match the look and feel of standard Decorator switches.

**Easy-to-use oversized main switch** for primary load.

**Patented Snap-In Light Module** (sold separately) transforms a combination switch into an illuminated switch in seconds. See Page A-20 for details.

**Identification modules** (sold separately) identifies each switch — light, fan, heat lamp. See Page A-20 for details.

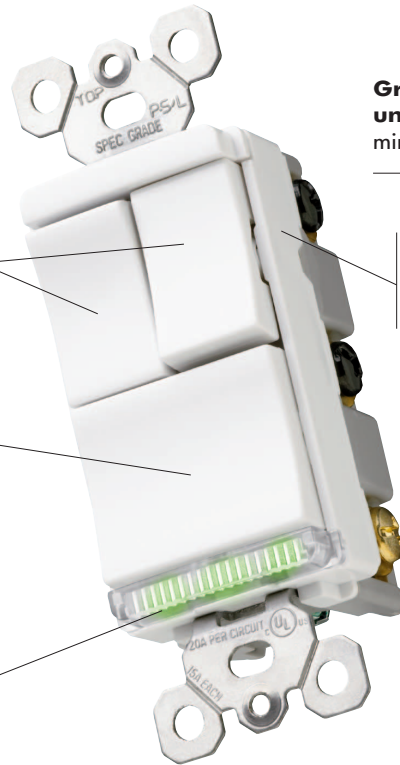

**TM8113-WCC**  
Shown with Snap-In Light Module TM8LMCC.

**Fully rounded back body** protects wires from being damaged by sharp edges.

**Ground screw position under the end of the strap** minimizes the risk of contact.

**Full wraparound metal strap**, commercial grade with lock-in tabs.

**Impact-resistant face and body.**




**All screws are tri-drive.**

**Patented split circuit tab** — easily accessible, and can be reinstalled without a tool.

**External screw-pressure-plate back and side wired.** Accepts #12 and #14 AWG.

## Adding a Snap-In Light Module

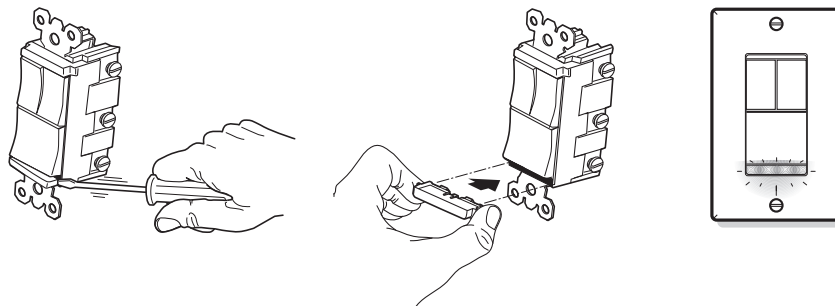

# Decorator Devices TradeMaster® Decorator Combination Switches

15A, 120VAC


Pass & Seymour




## Features

- Impact-resistant face and body.
- Fully rounded back body protects wires from being damaged by sharp edges.
- Clear identification of circuits.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Ground screw position under the end of the strap minimizes the risk of contact.
- Full wraparound metal strap with lock-in tabs.
- Patented split circuit tab – easily accessible, and can be reinstalled without a tool.
- Unique “Up/Down” switches match the look and feel of standard Decorator switches.
- Largest breadth of 15 amp offering.
- All screws are tri-drive.
- Patented Snap-In Light and Identification Modules (sold separately). See Page A-20 for details.


Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			UL <sub>20</sub>	cUL <sub>us</sub>
<b>Two Single Pole Switches</b>				
TM811-ICC	15 120	Ivory	•	•
TM811-WCC	15 120	White	•	•
TM811-CC	15 120	Brown	•	•
TM811-BKCC	15 120	Black	•	•
TM811-LACC	15 120	Light Almond	•	•
<b>Two Single Pole Switches with Pilot Light</b>				
TM811-PLICC	15 120	Ivory	•	•
TM811-PLWCC	15 120	White	•	•
TM811-PLBKCC	15 120	Black	•	•
TM811-PLLACC	15 120	Light Almond	•	•
<b>Single Pole Switch &amp; Three-Way Switch</b>				
TM813-ICC	15 120	Ivory	•	•
TM813-WCC	15 120	White	•	•
TM813-CC	15 120	Brown	•	•
TM813-BKCC	15 120	Black	•	•
TM813-LACC	15 120	Light Almond	•	•
<b>Single Pole Switch with Pilot Light &amp; Three-Way Switch</b>				
TM813-PLICC	15 120	Ivory	•	•
TM813-PLWCC	15 120	White	•	•
TM813-PLBKCC	15 120	Black	•	•
TM813-PLLACC	15 120	Light Almond	•	•
<b>Two Three-Way Switches</b>				
TM833-ICC	15 120	Ivory	•	•
TM833-WCC	15 120	White	•	•
TM833-CC	15 120	Brown	•	•
TM833-BKCC	15 120	Black	•	•
TM833-LACC	15 120	Light Almond	•	•
<b>Three Single Pole Switches</b>				
TM8111-ICC	15 120	Ivory	•	•
TM8111-WCC	15 120	White	•	•
TM8111-CC	15 120	Brown	•	•
TM8111-BKCC	15 120	Black	•	•
TM8111-LACC	15 120	Light Almond	•	•
<b>Two Single Pole Switches &amp; Three-Way Switch</b>				
TM8113-ICC	15 120	Ivory	•	•
TM8113-WCC	15 120	White	•	•
TM8113-CC	15 120	Brown	•	•
TM8113-BKCC	15 120	Black	•	•
TM8113-LACC	15 120	Light Almond	•	•
<b>Four Single Pole Switches</b>				
TM81111-ICC	15 120	Ivory	•	•
TM81111-WCC	15 120	White	•	•
TM81111-CC	15 120	Brown	•	•
TM81111-BKCC	15 120	Black	•	•
TM81111-LACC	15 120	Light Almond	•	•

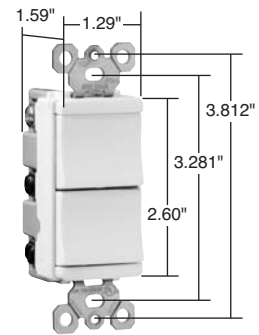

TM811-WCC

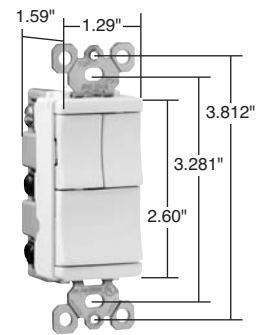


TM8111-WCC

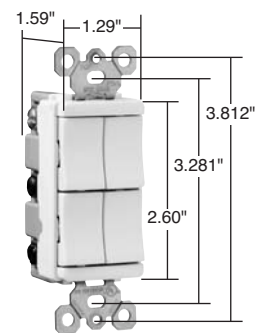


TM81111-WCC

All devices listed on this page conform to NEMA WD-1 and WD-6.

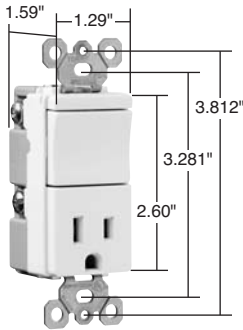

TM818-WCC

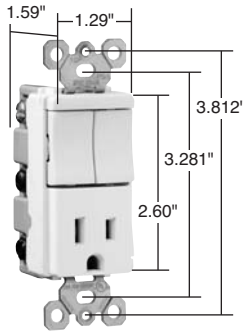

TM8118-WCC



TM8LMCC



TM8ID-WCC

# Decorator Devices TradeMaster® Decorator Combination Switches

15A, 120/125VAC

Catalog Number	Rating A. VAC	Color	NEMA Config. No.	3rd Party Compliance		
				UL20	UL498	cULus
<b>Single Pole Switch &amp; Single Receptacle</b>						
TM818-ICC	15 120/125	Ivory	5-15R	•	•	•
TM818-WCC	15 120/125	White	5-15R	•	•	•
TM818-CC	15 120/125	Brown	5-15R	•	•	•
TM818-BKCC	15 120/125	Black	5-15R	•	•	•
TM818-LACC	15 120/125	Light Almond	5-15R	•	•	•
<b>Single Pole Switch &amp; Single Receptacle with Pilot Light</b>						
TM818-PLICC	15 120/125	Ivory	5-15R	•	•	•
TM818-PLWCC	15 120/125	White	5-15R	•	•	•
TM818-PLBKCC	15 120/125	Black	5-15R	•	•	•
TM818-PLLACC	15 120/125	Light Almond	5-15R	•	•	•
<b>Three-Way Switch &amp; Single Receptacle</b>						
TM838-ICC	15 120/125	Ivory	5-15R	•	•	•
TM838-WCC	15 120/125	White	5-15R	•	•	•
TM838-CC	15 120/125	Brown	5-15R	•	•	•
TM838-BKCC	15 120/125	Black	5-15R	•	•	•
TM838-LACC	15 120/125	Light Almond	5-15R	•	•	•
<b>Two Single Pole Switches &amp; Single Receptacle</b>						
TM8118-ICC	15 120/125	Ivory	5-15R	•	•	•
TM8118-WCC	15 120/125	White	5-15R	•	•	•
TM8118-CC	15 120/125	Brown	5-15R	•	•	•
TM8118-BKCC	15 120/125	Black	5-15R	•	•	•
TM8118-LACC	15 120/125	Light Almond	5-15R	•	•	•
<b>Single Pole Switch &amp; Pilot Light</b>						
TM81-PLICC	15 120/125	Ivory		•	•	•
TM81-PLWCC	15 120/125	White		•	•	•
TM81-PLBKCC	15 120/125	Black		•	•	•
TM81-PLLACC	15 120/125	Light Almond		•	•	•
<b>Three-Way Switch &amp; Pilot Light</b>						
TM83-PLICC	15 120/125	Ivory		•	•	•
TM83-PLWCC	15 120/125	White		•	•	•
TM83-PLBKCC	15 120/125	Black		•	•	•
TM83-PLLACC	15 120/125	Light Almond		•	•	•

**Features**

- Module simply snaps-in for easy installation.
- Can be installed with the following devices: TM811, TM813, TM833, TM818, TM838, TM8111, TM8113, TM81111, TM8118 and the LS Series of Dimmers & Fan Speed Controls (see Pages M-8 and M-17).
- Snap-In Light Module:**
  - Lights when OFF.
  - Uses energy-efficient 1/4 watt LED light.
  - LED light will not generate heat and will last on average 47 years.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance
			cULus
<b>Snap-In Light Module</b>			
TM8LMCC	15 120/125	Clear	•
<b>Identification Modules</b>			
TM8ID-ICC	— —	Ivory	
TM8ID-WCC	— —	White	
TM8ID-CC	— —	Brown	
TM8ID-BKCC	— —	Black	
TM8ID-LACC	— —	Light Almond	

For Decorator Hallway Lights and Combination Devices, see Pages D-14, D-17, and D-19.

All devices listed on this page conform to NEMA WD-1 and WD-6.