

DIMMING SOLUTIONS FOR EVERY NEED

AND BUDGET.



LS SERIES DIMMERS

- Ergonomic design and solid, quality feel
- Sleek, sculpted contemporary design
- Patented Snap-In Light Module for easy nighttime location (sold separately)



DR SERIES DIMMERS

- Contemporary style matches P&S Decorator Combination Devices
- Illuminated knob indicates light level
- Snap-in LED modules make dimmers easy to find at night (sold separately)
- Available for incandescent and low-voltage lighting




ROTARY DIMMERS

- Full-range rotary dimming
- Ground lead included on all models
- All models fit standard toggle wall plate

 


TradeMaster® LS Series Dimmers

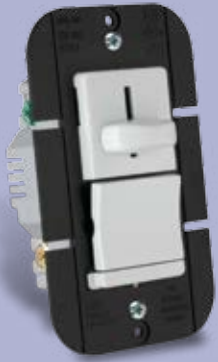


**COLOR DESIGNATION

W	White
LA	Light Almond
I	Ivory
BK	Black
-	Brown



PART NO.	DESCRIPTION	COLOR	RATING
LS1000**	Incandescent Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 1000W
LS1000P**	Incandescent Single Pole, Preset		
LS1003P**	Incandescent 3-Way, Preset		
LS600**	Incandescent Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 600W
LS600LWV	Incandescent Lighted, Single Pole, Non-Preset	White	
LS600P**	Incandescent Single Pole, Preset	Black, Brown, Ivory, Light Almond, White	
LS603P**	Incandescent 3-Way, Preset	White	
LS603PLWV	Incandescent Lighted, 3-Way, Preset		
LSCL450**	CFL/LED/Incandescent Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120VAC, 450W, CFL/LED; 700W Incandescent
LSCL453P**	CFL/LED/Incandescent 3-Way, Preset		
LSCLDC163P**	CFL/LED/Incandescent Single Pole/3-Way, Preset, Dimmer with Single Pole/3-Way, 3-Speed De-Hummer Fan Control	Black, Brown, Ivory, Light Almond, White	1.6A, (Fan Control); 120VAC, 150W CFL/LED; 300W Incandescent (Dimmer)
LSLV600**	Magnetic Low Voltage Single Pole, Non-Preset	Black, Brown, Ivory, Light Almond, White	120V, 600VA
LSLV600P**	Magnetic Low Voltage Single Pole, Preset		
LSLV603P**	Magnetic Low Voltage 3-Way, Preset		
LSDC16V**	Fan Speed Control 3-Speed De-Hummer Fan Speed Control, Non-Preset with Single Pole Incandescent Dimmer	Brown, Ivory, Light Almond, White	1.6A, (Fan Control); 120V, 150W CFL/LED; 300W Incandescent (Dimmer)
LSDC16PV**	Fan Speed Control 3-Speed De-Hummer Fan Speed Control, Preset with Single Pole Incandescent Dimmer	Brown, Black	
LSDH16V**	Fan Speed Control 4-Speed De-Hummer, Non-Preset	Black, Brown, Ivory, Light Almond, White	1.6A
LSSC5**	Fan Speed Control Single Pole with Adjustable Trim, Non-Preset		5A
LSSC5P**	Fan Speed Control Single Pole with Adjustable Trim, Preset		

All devices are  US LISTED.