


Wire Management Wiring Duct - DNG



High impact, rigid vinyl - won't peel, chip or crack; resists oils, grease, salt solutions, most mildly concentrated acids, fungus; non-flammable, warp-proof, non-brittle; high dielectric and will withstand temperatures to 150°F.

Flammability: Self extinguishing UL94V-0. Maintains dimensional stability under heat: ..65°C i.e. ..150°F as per DIN53458



Includes Base and Cover
2 Meter Lengths
-5°C to 65°C

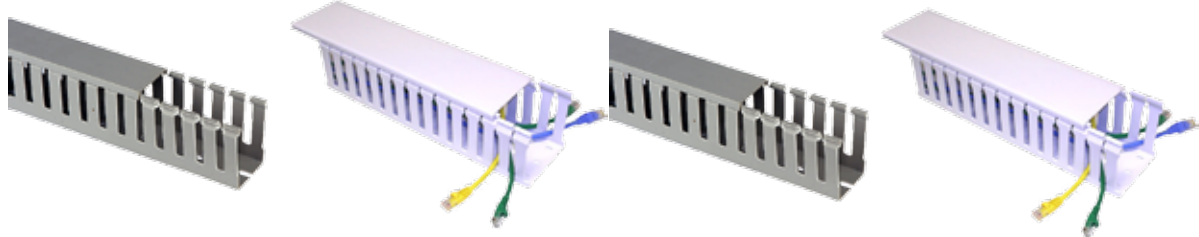

Type Size Color Configuration Approvals	DNG Grey 2 Meters Grey - RAL7030 A-Slot 	DNG White 2 Meters White A-Slot	DNG Grey 2 Meters Grey - RAL7030 B-Slot 	DNG White 2 Meters White B-Slot
-----------------------------------------------------	---------------------------------------------------------------------------------------------------------------------------------------	------------------------------------------	----------------------------------------------------------------------------------------------------------------------------------------	------------------------------------------

Nominal Inches Width x Height	Part Number	Std. Pack of	Part Number	Std. Pack of	Part Number	Std. Pack of	Part Number	Std. Pack of
	Model Number	2 m lengths	Model Number	2 m lengths	Model Number	2 m lengths	Model Number	2 m lengths
3/4" x 3/4"					34.286.2020.0 DNG 20020	32	34.286.2020.0 DNG 20020-W	32
3/4" x 1 1/2"					34.286.3720.0 DNG 37020	16	34.286.3720.2 DNG 37020-W	16
3/4" x 2"					34.286.5020.0 DNG 50020	10	34.286.5020.2 DNG 50020-W	10
1" x 1"	34.286.2525.0 DNG 25025	24	34.286.2525.2 DNG 25025-W	24				
1" x 2"	34.286.5025.0 DNG 50025	9	34.286.5025.2 DNG 50025-W	9				
1" x 3"	34.286.7525.0 DNG 75025	16	34.286.7525.2 DNG 75025-W	16				
1 1/2" x 1"	34.286.2537.0 DNG 25037	32	34.286.2537.2 DNG 25037-W	32				
1 1/2" x 1 1/2"	34.286.3737.0 DNG 37037	16	34.286.3737.2 DNG 37037-W	16				
1 1/2" x 2"	34.286.5037.0 DNG 50037	20	34.286.5037.2 DNG 50037-W	20				
1 1/2" x 3"	34.286.7537.0 DNG 75037	20	34.286.7537.2 DNG 75037-W	20				
2" x 2"	34.286.5050.0 DNG 50050	24	34.286.5050.2 DNG 50050-W	24				
2" x 3"	34.286.7550.0 DNG 75050	10	34.286.7550.2 DNG 75050-W	10				
2" x 4"	34.286.1050.0 DNG 100050	12	34.286.1050.2 DNG 100050-W	12				
3" x 2"	34.286.5075.0 DNG 50075	10	34.286.5075.2 DNG 50075-W	10				
3" x 3"	34.286.7575.0 DNG 75075	8	34.286.7575.2 DNG 75075-W	8				
3" x 4"	34.286.1075.0 DNG 100075	8	34.286.1075.2 DNG 100075-W	8				
4" x 2"	34.286.5100.0 DNG 50100	12	34.286.5100.2 DNG 50100-W	12				
4" x 3"	34.286.7510.0 DNG 75100	8	37.286.7510.0 DNG 75100 -W	8				
4" x 4"	34.286.1010.0 DNG 100100	6	34.285.1010.2 DNG 100100-W	6				
5" x 2"	34.286.5125.0 DNG 50125	9	34.286.5125.2 DNG 50125-W	9				
5" x 3"	34.286.7512.0 DNG 75125	6	34.286.7512.2 DNG 75125-W	6				

Slot Configuration

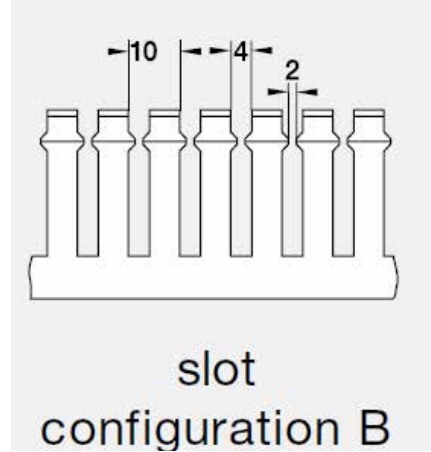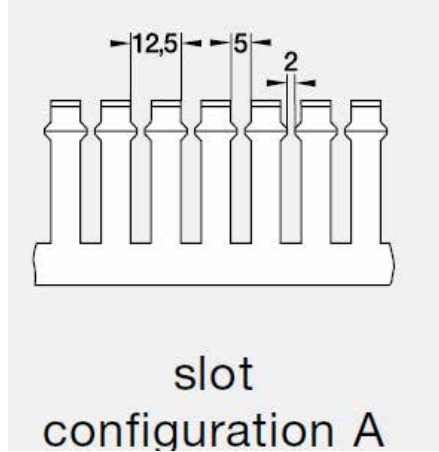

Dimensions

Nominal Inches
 Width x Height

Metric Dimensions
 Width x Height

3/4" x 3/4"	19 x 19 mm
3/4" x 1 1/2"	19 x 36 mm
3/4" x 2"	19 x 49 mm
1" x 1"	25 x 25 mm
1" x 2"	24 x 49 mm
1" x 3"	24 x 73 mm
1 1/2" x 1"	37 x 24 mm
1 1/2" x 1 1/2"	37 x 36 mm
1 1/2" x 2"	37 x 49 mm
1 1/2" x 3"	37 x 73 mm
2" x 2"	49 x 49 mm
2" x 3"	49 x 73 mm
2" x 4"	49 x 98 mm
3" x 2"	74 x 49 mm
3" x 3"	74 x 73 mm
3" x 4"	74 x 98 mm
4" x 2"	99 x 49 mm
4" x 3"	99 x 73 mm
4" x 4"	99 x 98 mm
5" x 2"	124 x 49 mm
5" x 3"	124 x 73 mm

