


Marking accessories DIN rail terminal blocks for junction boxes

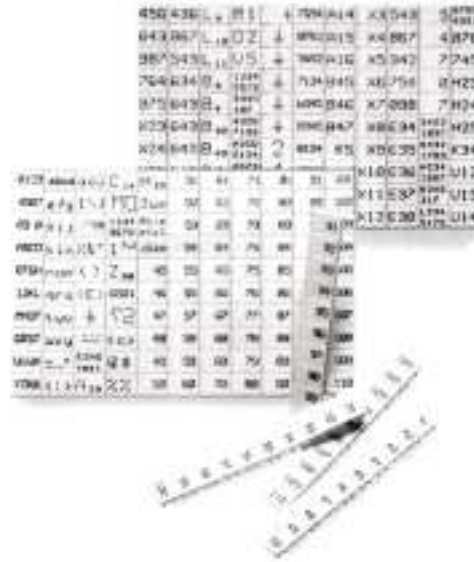

Material:
Polyamide 6.6
black figures on white background

DIN rail terminal blocks, type WKF, can accept marking tags on both sides on top of the block in a 3-chamber slot. It can be either 3 single number tags from the tear-off marking strip, or single tags, or marking strips.

- Marking strips** marked and unmarked made from Polyamide 6.6, suitable for 10 terminal blocks. Marking 1-10, 11-20 etc. up to 991-999.
Type 9705 A/5/10 (5 mm spacing) for DIN rail terminal blocks type WK/WKIF/WKIS 2,5...
Type 9705 A/6/10 (6 mm spacing) for DIN rail terminal blocks type WK/WKI/WKF 4...
Type 9705 A/5/10/5 B (10 mm spacing) for DIN rail terminal blocks type WKI/WKF 10...
Type 9705 A/6/10/5 B (12 mm spacing) for DIN rail terminal blocks type WKI/WKIF 16...
Type 9705 A/8/10/5 B (16 mm spacing) for DIN rail terminal blocks type WKI 35...
- Tear-off marking strips** with 10 marking tags made from Polyamide 6.6, white, marked and unmarked.
This marking system considerably reduces the time required for marking terminal block assemblies. For numerical of terminal block rows only 11 stock positions are required. As the time used for picking and attaching the tags is reduced, and as stockkeeping is low and the prices extremely favorable, attractive cost savings are the result from using these tear-off marking strips.
Type 9704 A...
- Single marking tag** made from Polyamide 6.6, white, marked and unmarked.
Type 9705 A...

Marking plates
for the **marcom** 2 marking computer
for the **wieplot** 500 plotter system

All terminal blocks / 5 mm wide and larger

Type	Part No.	Std. Pack	Type	Part No.	Std. Pack
Marking plate, unmarked			Single marking tag, unmarked		
Size 5 x 8.3 mm		110 tags per plate	Size 5 x 8.3 mm		
9705 A/5/10/11	Z4.242.5053.0	10	9705 A	04.242.0850.0	500
Size 5 x 14 mm		60 tags per plate	Size 5 x 14 mm		
9705 AL/5/10/6	Z4.242.5153.0	10	9705 AL	04.242.1553.0	500
Marking plate, unmarked			Single marking tag, unmarked		
Size 6 x 8.3 mm		110 tags per plate	Size 5 x 8.3 mm		
9705 A/6/10/11	Z4.242.6053.0	10	9705 AB*	04.842.0850.0	500
Size 6 x 14 mm		60 tags per plate	Size 5 x 14 mm		
9705 AL/6/10/6	Z4.242.6153.0	10	9705 ALB	04.842.1553.0	500
Marking plate, unmarked					
Size 8 x 8.3 mm		70 tags per plate			
9705 A/8/10/7	Z4.242.8053.0	10			
* Custom marking upon request					



2.5 mm²/5 mm wide

4 mm²/6 mm wide

**10 mm²/10 mm wide
16 mm²/12 mm wide
35 mm²/16 mm wide**

Type	Part No.	Std. Pack	Type	Part No.	Std. Pack	Type	Part No.	Std. Pack		
Marking strips, unmarked			Marking strips, unmarked			10 mm²/10 mm wide				
9705 A/5/10	04.242.5053.0	25	9705 A/6/10	04.242.6053.0	25	marked for 5 blocks (every 2nd tag) *				
Marking strips, marked			Marking strips, marked			16 mm²/12 mm wide				
9705 A/5/9 B	1 - 9	04.842.4953.0	25	9705 A/6/9 B	1 - 9	04.842.5953.0	25	9705 A/5/10/5 B	04.842.5553.0	25
9705 A/5/10 B*		04.842.5053.0	25	9705 A/6/10 B*		04.842.6053.0	25	marked for 5 blocks (every 2nd tag) *		
9705 A/5/10 B	1 - 10	04.845.0153.0	25	9705 A/6/10 B	1 - 10	04.846.0153.0	25	35 mm²/16 mm wide		
	11 - 20	04.845.0253.0	25		11 - 20	04.846.0253.0	25	marked for 5 blocks (every 2nd tag) *		
	21 - 30	04.845.0353.0	25		21 - 30	04.846.0353.0	25	9705 A/6/10/5 B		
	31 - 40	04.845.0453.0	25		31 - 40	04.846.0453.0	25	04.842.6553.0		
	41 - 50	04.845.0553.0	25		41 - 50	04.846.0553.0	25	25		
	51 - 60	04.845.0653.0	25		51 - 60	04.846.0653.0	25			
	61 - 70	04.845.0753.0	25		61 - 70	04.846.0753.0	25			
	71 - 80	04.845.0853.0	25		71 - 80	04.846.0853.0	25			
	81 - 90	04.845.0953.0	25		81 - 90	04.846.0953.0	25			
	91 - 100	04.845.1053.0	25		91 - 100	04.846.1053.0	25			
	⊕ (10 x)	04.855.0053.0	25		⊕ (10 x)	04.856.0053.0	25			
	⊖ (10 x)	04.855.0153.0	25		⊖ (10 x)	04.856.0153.0	25			
	+	04.855.0253.0	25		+	04.856.0253.0	25	marked for 5 blocks (every 2nd tag) *		
	-	04.855.0353.0	25		-	04.856.0353.0	25	9705 A/8/10/5 B		
	L1 (10 x)	04.855.0453.0	25		L1 (10 x)	04.856.0453.0	25	04.842.8553.0		
	L2 (10 x)	04.855.0553.0	25		L2 (10 x)	04.856.0553.0	25	25		
	L3 (10 x)	04.855.0653.0	25		L3 (10 x)	04.856.0653.0	25			
	PE (10 x)	04.855.0753.0	25		PE (10 x)	04.856.0753.0	25			
	SL (10 x)	04.855.3153.0	25		SL (10 x)	04.856.3153.0	25			
	N (10 x)	04.855.3253.0	25		N (10 x)	04.856.3253.0	25			
	F1 (10 x)	04.855.0953.0	25		F1 (10 x)	04.856.0953.0	25			
	F2 (10 x)	04.855.1053.0	25		F2 (10 x)	04.856.1053.0	25			
	L1, L2, L3, N, PE (2 x)	04.855.0853.0	25		L1, L2, L3, N, PE (2 x)	04.856.0853.0	25			
with enlarged marking area			with enlarged marking area							
9705 AL/5/10	04.242.5153.0	25	9705 AL/6/10	04.242.6353.0	25					
* Custom marking upon request			* Custom marking upon request			* Specify required marking with part no.				