


Ferrules DIN rail terminal blocks for junction boxes

Ferrules with insulating material sleeve

Materials:

Sleeve: Polypropylene, temperature resistance 105 °C, creepage resistant


Tube: E-Cu, galvanically tin-plated

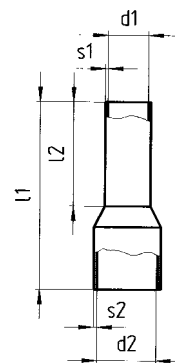

Ferrules without insulating material sleeve

Material:

Tube: E-Cu, galvanically tin-plated

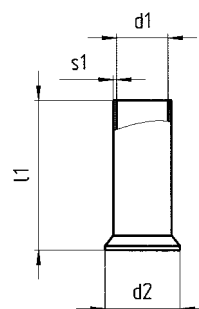

| | Cross section mm ² | Color | Part No. | Std. Pack | |
|--|-------------------------------|-----------|----------|---------------|------|
| Ferrules with insulating material sleeve | 0.50 | norm. | white | 06.600.2027.0 | 100 |
| according to DIN 46 228 T4 | 0.75 | norm. | gray | 06.600.2127.0 | 100 |
| | 1.00 | norm. | red | 06.600.2227.0 | 100 |
| | 1.50 | norm. | black | 06.600.2327.0 | 100 |
| | 1.50 | long | black | 06.600.2427.0 | 100 |
| | 2.50 | norm. | blue | 06.600.2527.0 | 100 |
| | 2.50 | long | blue | 06.600.2627.0 | 100 |
| | 4.00 | norm. | gray | 06.600.2727.0 | 100 |
| | 4.00 | long | gray | 06.600.2827.0 | 100 |
| | 6.00 | norm. | yellow | 06.600.2927.0 | 100 |
| | 6.00 | long | yellow | 06.600.3027.0 | 100 |
| | 10.00 | norm. | red | 06.600.3127.0 | 100 |
| | 10.00 | long | red | 06.600.3227.0 | 100 |
| | 16.00 | norm. | blue | 06.600.3327.0 | 100 |
| | 16.00 | long | blue | 06.600.3427.0 | 100 |
| | 25.00 | half-long | yellow | 06.600.3527.0 | 50 |
| | | | | | |
| | | | | | |
| Ferrules without insulating material sleeve | 0.50 | norm. | | 06.600.4027.0 | 1000 |
| according to DIN 46 228 T1 | 0.75 | norm. | | 06.600.4127.0 | 1000 |
| | 1.00 | norm. | | 06.600.4227.0 | 1000 |
| | 1.50 | norm. | | 06.600.4327.0 | 1000 |
| | 2.50 | norm. | | 06.600.4427.0 | 1000 |
| | 4.00 | norm. | | 06.600.4527.0 | 1000 |
| | 6.00 | norm. | | 06.600.4627.0 | 500 |
| | 10.00 | norm. | | 06.600.4727.0 | 500 |
| | 16.00 | norm. | | 06.600.4827.0 | 100 |
| | 25.00 | norm. | | 06.600.4927.0 | 100 |
| | 35.00 | norm. | | 06.600.5027.0 | 100 |
| | | | | | |
| | | | | | |
| | | | | | |