


Ferrules DIN rail terminal blocks for junction boxes

Ferrules with insulating material sleeve

Materials:

Sleeve: Polypropylene, temperature resistance 105 °C, creepage resistant


Tube: E-Cu, galvanically tin-plated

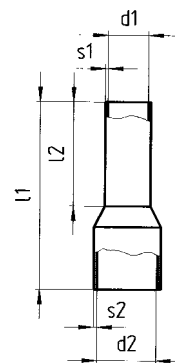

Ferrules without insulating material sleeve

Material:

Tube: E-Cu, galvanically tin-plated

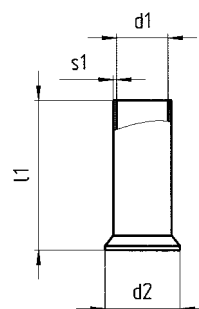

	Cross section mm ²	Color	Part No.	Std. Pack	
Ferrules with insulating material sleeve	0.50	norm.	white	06.600.2027.0	100
according to DIN 46 228 T4	0.75	norm.	gray	06.600.2127.0	100
	1.00	norm.	red	06.600.2227.0	100
	1.50	norm.	black	06.600.2327.0	100
	1.50	long	black	06.600.2427.0	100
	2.50	norm.	blue	06.600.2527.0	100
	2.50	long	blue	06.600.2627.0	100
	4.00	norm.	gray	06.600.2727.0	100
	4.00	long	gray	06.600.2827.0	100
	6.00	norm.	yellow	06.600.2927.0	100
	6.00	long	yellow	06.600.3027.0	100
	10.00	norm.	red	06.600.3127.0	100
	10.00	long	red	06.600.3227.0	100
	16.00	norm.	blue	06.600.3327.0	100
	16.00	long	blue	06.600.3427.0	100
	25.00	half-long	yellow	06.600.3527.0	50
Ferrules without insulating material sleeve	0.50	norm.		06.600.4027.0	1000
according to DIN 46 228 T1	0.75	norm.		06.600.4127.0	1000
	1.00	norm.		06.600.4227.0	1000
	1.50	norm.		06.600.4327.0	1000
	2.50	norm.		06.600.4427.0	1000
	4.00	norm.		06.600.4527.0	1000
	6.00	norm.		06.600.4627.0	500
	10.00	norm.		06.600.4727.0	500
	16.00	norm.		06.600.4827.0	100
	25.00	norm.		06.600.4927.0	100
	35.00	norm.		06.600.5027.0	100