

Wire Management Wiring Duct - BA7

selos

Flammability: Self extinguishing
UL94V-0. Maintains dimensional
stability under heat:

Other colors available

Halogen-free version available

Includes Base and Cover
2 Meter Lengths
-5°C to 60°C



Type

Size
Color

Approvals


BA7 Grey

2 Meters
Grey - RAL7030




Dimensions Width x Height mm (nominal inch)	Part Number	Std. Pack of 2 m lengths	Part Number Model Number	Part Number Model Number	Part Number Model Number
25 x 25 (1" x 1")	34.285.2525.0	25			
25 x 40 (1" x 1 1/2")	34.285.4025.0	24			
25 x 60 (1" x 2")	34.285.6025.0	30			
25 x 80 (1" x 3")	34.285.8025.0	10			
40 x 25 (1 1/2" x 1")	34.285.2540.0	24			
40 x 40 (1 1/2" x 1 1/2")	34.285.4040.0	25			
40 x 60 (1 1/2" x 2")	34.285.6040.0	20			
40 x 80 (1 1/2" x 3")	34.285.8040.0	10			
60 x 40 (2" x 1 1/2")	34.285.4060.0	20			
60 x 60 (2" x 2")	34.285.6060.0	12			
60 x 80 (2" x 3")	34.285.8060.0	10			
60 x 100 (2" x 4")	34.285.1060.0	8			
80 x 40 (3" x 1 1/2")	34.285.4080.0	15			
80 x 60 (3" x 2")	34.285.6080.0	10			
80 x 80 (3" x 3")	34.285.8080.0	6			
80 x 100 (3" x 4")	34.285.1080.0	8			
100 x 40 (4" x 1 1/2")	34.285.4100.0	10			
100 x 60 (4" x 2")	34.285.6100.0	8			
100 x 80 (4" x 3")	34.285.8100.0	6			
100 x 100 (4" x 4")	34.285.1100.0	6			
120 x 60 (5" x 2")	34.285.6120.0	6			
120 x 80 (5" x 3")	34.285.8120.0	8			


Dimensions

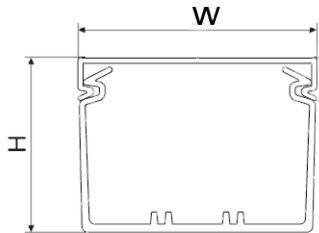


BA7A | HA7
lateral punched openings

 


for duct height 25 mm

 


for duct height 40 mm

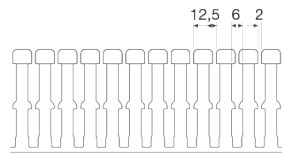

for duct height 60 mm

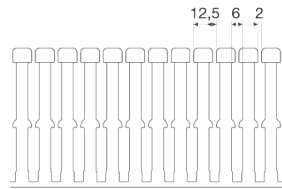


for duct height 80 mm

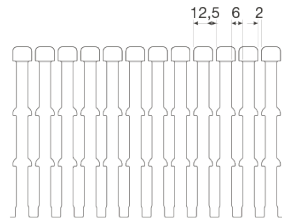


for duct height 100 mm


BA7A | BA7B | B7A | HA7
bottom holes EN50085

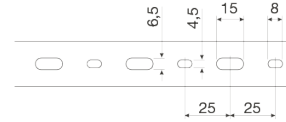


for duct width 25 mm

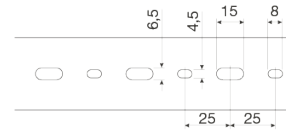


for duct width 40 mm

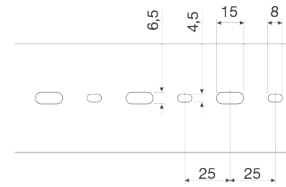


for duct width 60 mm

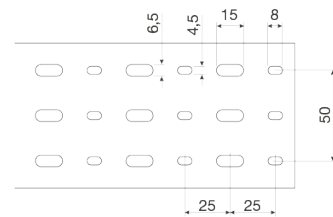

for duct width 80 mm

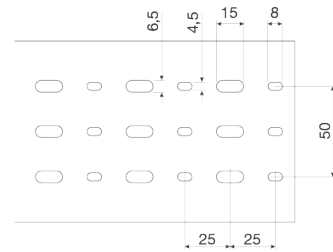

for duct width 100 mm

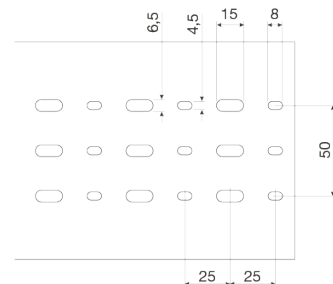

for duct width 120 mm