

# Wire Management Wiring Duct - BA7

# selos

Flammability: Self extinguishing  
UL94V-0. Maintains dimensional  
stability under heat:

Other colors available

Halogen-free version available


Includes Base and Cover  
2 Meter Lengths  
-5°C to 60°C




<b>Type</b>	<b>BA7 Grey</b>
Size	2 Meters
Color	Grey - RAL7030
Approvals	

Dimensions Width x Height mm (nominal inch)	Part Number	Std. Pack of 2 m lengths	Part Number Model Number	Part Number Model Number	Part Number Model Number
25 x 25 (1" x 1")	34.285.2525.0	25			
25 x 40 (1" x 1 1/2")	34.285.4025.0	24			
25 x 60 (1" x 2")	34.285.6025.0	30			
25 x 80 (1" x 3")	34.285.8025.0	10			
40 x 25 (1 1/2" x 1")	34.285.2540.0	24			
40 x 40 (1 1/2" x 1 1/2")	34.285.4040.0	25			
40 x 60 (1 1/2" x 2")	34.285.6040.0	20			
40 x 80 (1 1/2" x 3")	34.285.8040.0	10			
60 x 40 (2" x 1 1/2")	34.285.4060.0	20			
60 x 60 (2" x 2")	34.285.6060.0	12			
60 x 80 (2" x 3")	34.285.8060.0	10			
60 x 100 (2" x 4")	34.285.1060.0	8			
80 x 40 (3" x 1 1/2")	34.285.4080.0	15			
80 x 60 (3" x 2")	34.285.6080.0	10			
80 x 80 (3" x 3")	34.285.8080.0	6			
80 x 100 (3" x 4")	34.285.1080.0	8			
100 x 40 (4" x 1 1/2")	34.285.4100.0	10			
100 x 60 (4" x 2")	34.285.6100.0	8			
100 x 80 (4" x 3")	34.285.8100.0	6			
100 x 100 (4" x 4")	34.285.1100.0	6			
120 x 60 (5" x 2")	34.285.6120.0	6			
120 x 80 (5" x 3")	34.285.8120.0	8			


Dimensions

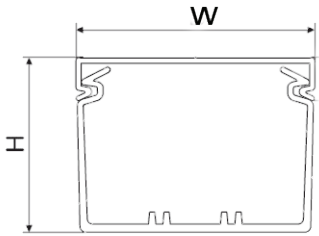


**BA7A | HA7**  
lateral punched openings

 


for duct height 25 mm

 


for duct height 40 mm

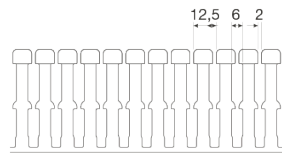

for duct height 60 mm

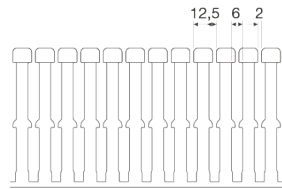


for duct height 80 mm

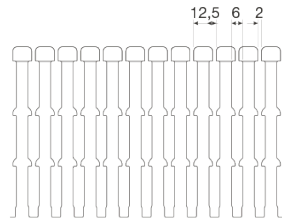


for duct height 100 mm


**BA7A | BA7B | B7A | HA7**  
bottom holes EN50085

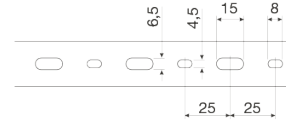


for duct width 25 mm

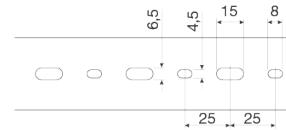


for duct width 40 mm

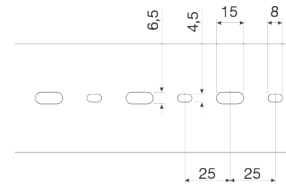


for duct width 60 mm

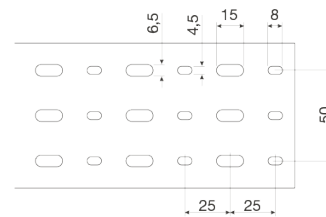

for duct width 80 mm

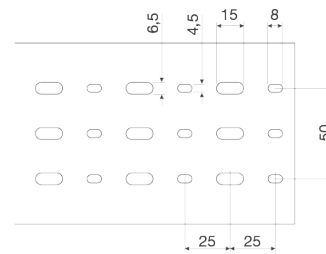

for duct width 100 mm

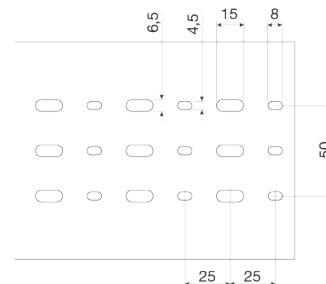

for duct width 120 mm