



B6

6" Universal Non-IC Housing

LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21

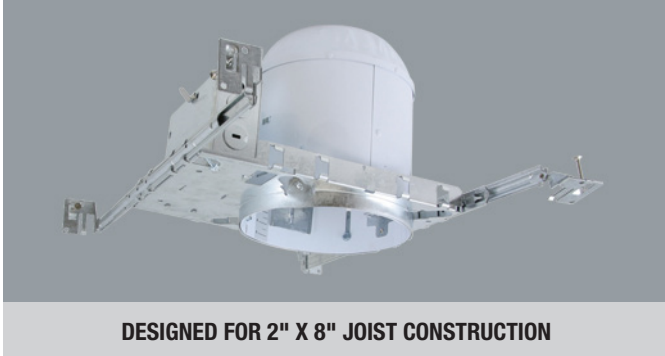

DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

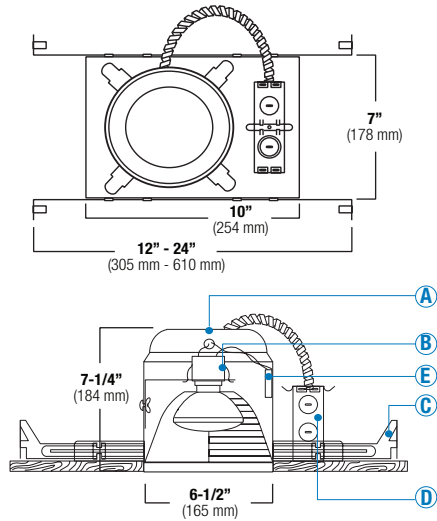

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

Thermally protected, specification grade recessed housing. For new construction non-insulated ceilings or where insulation can be kept 3" from housing. Accommodates up to 150W R40/PAR38, 120W BR40, 85W BR30 and 150W A21 lamps. Furnished with preinstalled adjustable bar hangers. Junction box is provided with four 1/2" KOs, one 3/4" KO and four Romex knockouts with strain relief.

SPECIFICATION


A. HOUSING - High temperature painted 22 gauge cold rolled steel construction for maximum heat dissipation and rust protection. Adjusts vertically in plaster frame to accommodate 1/2" to 1-3/8" ceiling. Accommodate lamps up to 150W depending on trim used.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. BAR HANGERS - Preinstalled bar hangers allow housing to be positioned and locked at any point within a 24" joist span. They can be positioned on either the long or short axis of the housing and can be shortened for 12" joists. They contain a double-headed real nail for 20° downward angle for better contact, and the 90° pivoting mounting plate makes installation fast and accurate. Bar hangers can fit onto T-Bar spline with additional slots and holes for special mounting methods if necessary.

D. JUNCTION BOX - UL and ETL listed for through-branch circuit wiring and has four 1/2" KOs, one 3/4" KO and four Romex knockouts with true pry-out slots and strain clamps.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlampping and misuse of insulation material.

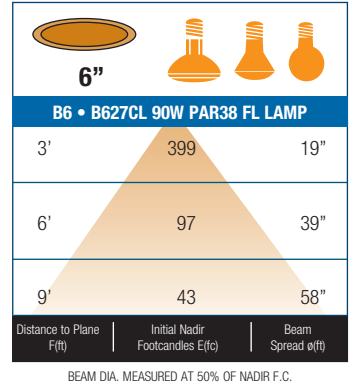

FEATURES

- Thermally Protected Non-IC housing.
- Adjustable socket bracket.
- Wire through junction box.
- Preinstalled adjustable bar hanger.
- Dependable, favorable design and effortless installation.
- 7-1/4" height allows use in 2" x 8" joist construction.
- Special screw on the frame locks bar hangers in place which prevents the housing from any movement once installed.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

UL AND C-UL/ETL AND C-ETL LISTED

- For Damp location
- For Feed-through wiring

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS
B6	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630 <input type="checkbox"/> B609 <input type="checkbox"/> B605 <input type="checkbox"/> B658 <input type="checkbox"/> B634 <input type="checkbox"/> B625 <input type="checkbox"/> B640 <input type="checkbox"/> B619 <input type="checkbox"/> B605L <input type="checkbox"/> B659 <input type="checkbox"/> B649 <input type="checkbox"/> B624 <input type="checkbox"/> B620 <input type="checkbox"/> B646 <input type="checkbox"/> B606 <input type="checkbox"/> B675 <input type="checkbox"/> AF633 <input type="checkbox"/> B681 <input type="checkbox"/> B631 <input type="checkbox"/> B616 <input type="checkbox"/> B606L <input type="checkbox"/> B676 <input type="checkbox"/> B225 <input type="checkbox"/> B687 <input type="checkbox"/> B632 <input type="checkbox"/> B663 <input type="checkbox"/> B635 <input type="checkbox"/> B612 <input type="checkbox"/> B653 <input type="checkbox"/> B682 <input type="checkbox"/> AF640 <input type="checkbox"/> B664 <input type="checkbox"/> B636 <input type="checkbox"/> B645 <input type="checkbox"/> B651 <input type="checkbox"/> B693 <input type="checkbox"/> AF632 <input type="checkbox"/> B673 <input type="checkbox"/> B642 <input type="checkbox"/> B648 <input type="checkbox"/> B611 <input type="checkbox"/> B694 <input type="checkbox"/> B610 <input type="checkbox"/> B674 <input type="checkbox"/> B641 <input type="checkbox"/> B652 <input type="checkbox"/> B647 <input type="checkbox"/> B688 <input type="checkbox"/> B607 <input type="checkbox"/> B683 <input type="checkbox"/> B656 <input type="checkbox"/> B603 <input type="checkbox"/> B644 <input type="checkbox"/> B685 <input type="checkbox"/> B627 <input type="checkbox"/> B684 <input type="checkbox"/> B657 <input type="checkbox"/> B604 <input type="checkbox"/> B650 <input type="checkbox"/> B696 <input type="checkbox"/> B608 <input type="checkbox"/> B601 <input type="checkbox"/> B637 <input type="checkbox"/> B615 <input type="checkbox"/> B622 <input type="checkbox"/> B689 <input type="checkbox"/> B602 <input type="checkbox"/> B601L <input type="checkbox"/> B643 <input type="checkbox"/> B633 <input type="checkbox"/> B623 <input type="checkbox"/> B680	<input type="checkbox"/> W <input type="checkbox"/> CL <input type="checkbox"/> WH <input type="checkbox"/> P <input type="checkbox"/> RG <input type="checkbox"/> BK <input type="checkbox"/> SN <input type="checkbox"/> W <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> MB <input type="checkbox"/> CP <input type="checkbox"/> BZ <input type="checkbox"/> BZ <input type="checkbox"/> CH <input type="checkbox"/> CP <input type="checkbox"/> PB <input type="checkbox"/> SN <input type="checkbox"/> BZ <input type="checkbox"/> SHZ	<input type="checkbox"/> Green <input type="checkbox"/> Yellow <input type="checkbox"/> Pink <input type="checkbox"/> Brown <input type="checkbox"/> Navy Blue <input type="checkbox"/> Orange <input type="checkbox"/> Blue <input type="checkbox"/> White <input type="checkbox"/> Red		

Specifications:

B6

AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS
----------	--------	-----------	--------	-----------	-----------	-------

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B6-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21)



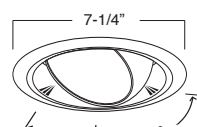
Catalog Number:

Project Name:

Type:

Note:

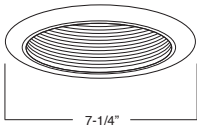

<p>B630CP-CP METAL STEPPED BAFFLE R30/PAR30</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B640SN-SN METAL STEPPED BAFFLE R40/PAR38</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B620-ORANGE GLASS TRIM</p>  <p>GLASS FINISH: GREEN, YELLOW, PINK, BROWN, NAVY BLUE, ORANGE, WHITE, RED</p> 	<p>B631P-WH R30 PREMIUM PHENOLIC BAFFLE / METAL RING</p>  <p>BAFFLE FINISH: W, P</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 
<p>B632W-WH R40 PREMIUM PHENOLIC BAFFLE / METAL RING</p>  <p>BAFFLE FINISH: W, P</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>AF640W-WH DEEP SELF FLANGE AIR-SHUT BAFFLE</p>  <p>AVAILABLE COLOR COMBINATIONS: W-WH, P-WH, SN-SN, CP-CP, BZ-BZ</p> 	<p>AF632RG-WH AIR-SHUT REFLECTOR</p>  <p>AVAILABLE COLOR COMBINATIONS: CL-WH, CL-CH, RG-WH, W-WH, MB-WH, CP-CP, SN-SN</p> 	<p>B610P-RG-WH CONE REFLECTOR/BAFFLE TRIM</p>  <p>BAFFLE FINISH: W, P</p> <p>REFLECTOR FINISH: CL, RG</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 
<p>B607CP-WH REFLECTOR R/PAR30</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B627RG-WH REFLECTOR R40/PAR38</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B608CL-WH CONE REFLECTOR A19</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B602SN EYEBALL</p>  <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 
<p>B609W-WH REGRESSED EYEBALL WITH BAFFLE</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> <p>EYEBALL FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B619RG-PB REGRESSED EYEBALL WITH REFLECTOR</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> <p>EYEBALL FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B646P-WH EYEBALL WITH BAFFLE</p>  <p>BAFFLE FINISH: W, P</p> <p>TRIM/RING FINISH: WH</p> 	<p>B616W-WH PAR20 REGRESSED EYEBALL W/ BAFFLE</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> <p>EYEBALL FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21)

Catalog Number:	
Project Name:	Type:
Note:	



<p>B663PB PAR30 GIMBAL RING</p>  <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B664CP PAR38 GIMBAL RING</p>  <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B673P-WH PAR30 BAFFLE W/ GIMBAL RING</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B674W-WH PAR38 BAFFLE W/ GIMBAL RING</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 
<p>B683CL-WH PAR30 REFLECTOR W/ GIMBAL RING</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B684RG-WH PAR38 REFLECTOR W/ GIMBAL RING</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B601CP METAL ALBALITE LENS</p>  <p>LENS: ALBALITE</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B601L PLASTIC ALBALITE LENS</p>  <p>LENS: ALBALITE</p> <p>TRIM/RING FINISH: WHITE PLASTIC</p> 
<p>B605PB METAL FRESNEL LENS</p>  <p>LENS: FRESNEL</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B605L PLASTIC FRESNEL LENS</p>  <p>LENS: FRESNEL</p> <p>TRIM/RING FINISH: WHITE PLASTIC</p> 	<p>B606CP METAL DROP OPAL LENS</p>  <p>LENS: DROP OPAL</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B606L PLASTIC DROP OPAL LENS</p>  <p>LENS: DROP OPAL</p> <p>TRIM/RING FINISH: WHITE PLASTIC</p> 
<p>B635P-WH BAFFLE W/ ALBALITE LENS</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B636W-WH BAFFLE W/ FRESNEL LENS</p>  <p>BAFFLE FINISH: W, P, SN, CP, BZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B641RG-WH REFLECTOR W/ ALBALITE LENS</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN, SHZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 	<p>B642CL-WH REFLECTOR W/ FRESNEL LENS</p>  <p>REFLECTOR FINISH: CL, RG, W, MB, CP, SN, SHZ</p> <p>TRIM/RING FINISH: WH, BK, SN, CP, CH, PB, BZ</p> 

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21)

Catalog Number:

Project Name:

Type:

Note:




B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

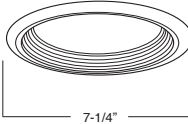


 B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

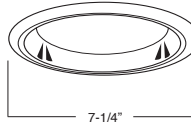


B637W-WH
BAFFLE W/ DROP OPAL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

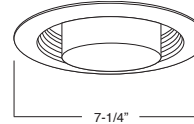


B643RG-WH
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

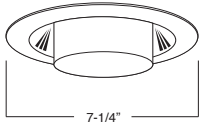


B658CL-WH
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

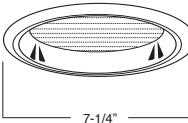


B659CL-WH
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

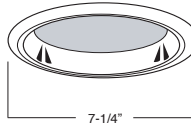


B675W-WH
BAFFLE W/ PRISMATIC LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

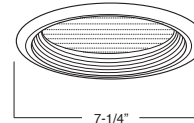


B676W-WH
BAFFLE W/ FROSTED LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

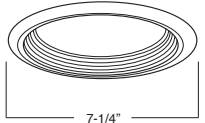


B612WH
SMOOTH FROST DOME SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

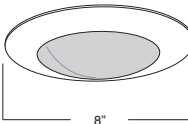


B645WH
DESIGNER POINT SHOWER LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

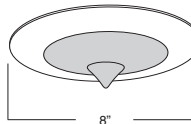


B648WH
DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

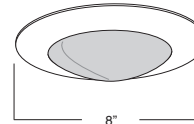


B652WH
SMOOTH FROST SHOWER LENS



LENS:
FROSTED


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

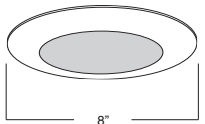

B603CP
R/PAR30 OPEN TRIM




TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

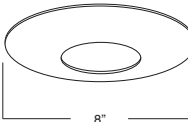


B604PB
R40/PAR38 OPEN TRIM




TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

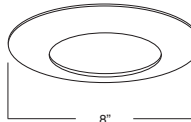

B615WH
DESIGNER PINHOLE

 


TRIM/RING FINISH:
WH, BK

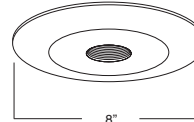

B633WH
R/PAR30 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

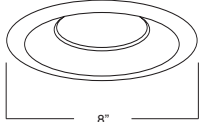

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21)

Catalog Number:


Project Name:

Type:

Note:




B634WH
R40/PAR38 SPLAY TRIM

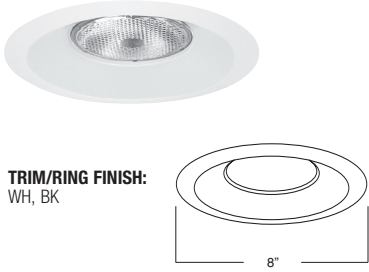


TRIM/RING FINISH:
WH, BK

B649RG-WH
PAR20 REFLECTOR

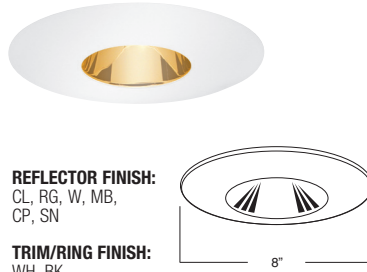

REFLECTOR FINISH:
CL, RG, W, MB,
CP, SN
TRIM/RING FINISH:
WH, BK

AF633CH
R/PAR30 OPEN TRIM

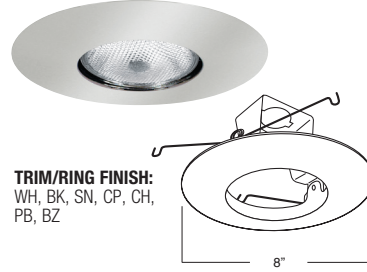


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B225WH
OPEN TRIM STEPPED BAFFLE




BAFFLE FINISH:
W, P
TRIM/RING FINISH:
WH

B653W-WH
BAFFLE WITH BAFFLE

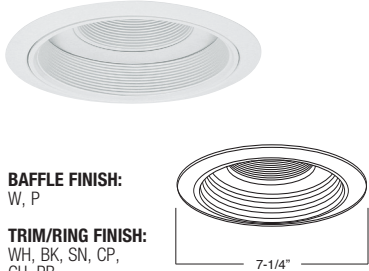

BAFFLE FINISH:
W, P
TRIM/RING FINISH:
WH, BK, SN, CP,
CH, PB

B651P-WH
PAR20 STEPPED BAFFLE

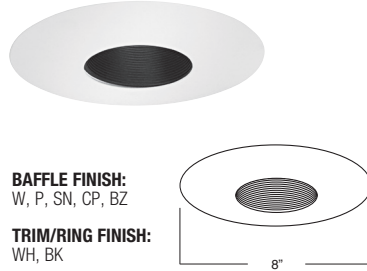


BAFFLE FINISH:
W, P, SN, CP, BZ
TRIM/RING FINISH:
WH, BK

B611W-WH
PAR30 BAFFLE WALL WASH




AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ
COVER FINISH:
WH, BK

B647P-WH
DESIGNER BAFFLE WALL WASH PAR20

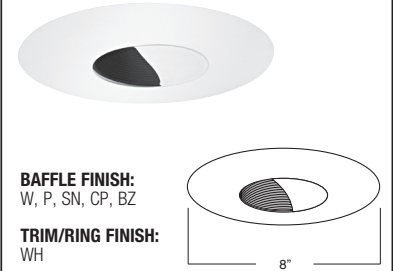


BAFFLE FINISH:
W, P, SN, CP, BZ
TRIM/RING FINISH:
WH

B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20

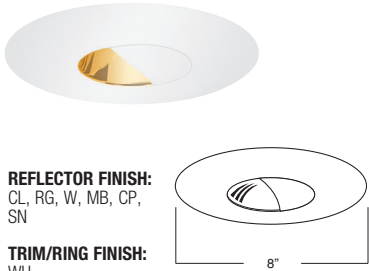


REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN
TRIM/RING FINISH:
WH

B650WH
DESIGNER WALL WASH

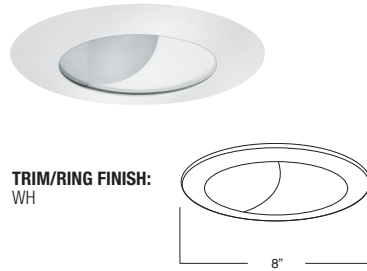

TRIM/RING FINISH:
WH

B622RG-WH
R/PAR30 WALL WASH REFLECTOR

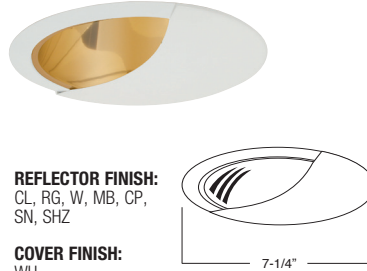

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ
COVER FINISH:
WH
TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

B623MB-WH
R40/PAR38 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ
COVER FINISH:
WH
TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

B625CL-WH
A-19 CONE REFLECTOR WALL WASH




REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ
COVER FINISH:
WH
TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

B624W-CL
CONE REFLECTOR BAFFLE WALL WASH




BAFFLE FINISH:
W, P
REFLECTOR FINISH:
CL, RG
COVER FINISH:
WH
TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

B681CP-WH
SQUARE BAFFLE TRIM

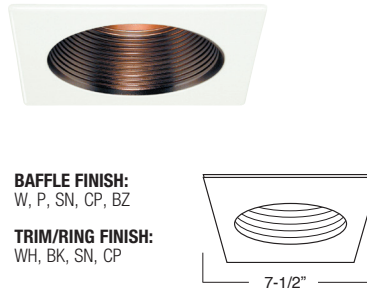

BAFFLE FINISH:
W, P, SN, CP, BZ
TRIM/RING FINISH:
WH, BK, SN, CP

B687CP-WH
SQUARE REFLECTOR TRIM

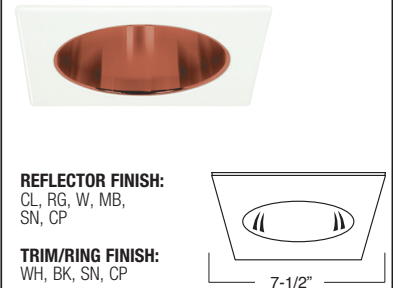

REFLECTOR FINISH:
CL, RG, W, MB,
SN, CP
TRIM/RING FINISH:
WH, BK, SN, CP



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.


 

 

 

 



 

 

 
REV: MAXLUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 150W R40/PAR38, 120W BR40, 85W BR30, 150W A21)

Catalog Number:	
Project Name:	Type:
Note:	



<p>B682WH SQUARE EYEBALL TRIM</p>  <p>TRIM/RING FINISH: WH</p> 	<p>B693WH SQUARE PAR30 GIMBAL TRIM</p>  <p>TRIM/RING FINISH: WH</p> 	<p>B694WH SQUARE PAR38 GIMBAL TRIM</p>  <p>TRIM/RING FINISH: WH</p> 	<p>B688WH SQUARE ALBALITE SHOWER TRIM</p>  <p>FOR WET LOCATION</p> <p>LENS: WHITE</p> <p>TRIM/RING FINISH: WH</p> 
<p>B685WH SQUARE FRESNEL SHOWER TRIM</p>  <p>FOR WET LOCATION</p> <p>LENS: CLEAR</p> <p>TRIM/RING FINISH: WH</p> 	<p>B696WH SQUARE DROP OIPAL SHOWER TRIM</p>  <p>FOR WET LOCATION</p> <p>LENS: WHITE</p> <p>TRIM/RING FINISH: WH</p> 	<p>B689WH SQUARE DESIGNER CONE SHOWER LENS</p>  <p>FOR WET LOCATION</p> <p>LENS: FROSTED</p> <p>TRIM/RING FINISH: WH</p> 	<p>B680WH SQUARE DESIGNER POINT LENS</p>  <p>FOR WET LOCATION</p> <p>LENS: FROSTED/CLEAR</p> <p>TRIM/RING FINISH: WH</p> 

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.