

3" MINIATURE LOW VOLTAGE NON-IC HOUSING

SPECIFICATION

HOUSING - High temperature painted 22 gauge deep drawn single piece housing. Adjusts vertically in plaster frame to accommodate 1/2" to 1-3/8" ceiling. Accommodates lamps up to 50W depending on trim used.

TRANSFORMER - Enhanced in heat dissipating cover, to provide noise free operation. Attached to junction box cover so it may be serviced from below the ceiling. Thermally protected.

- **M**-Class H dimming magnetic transformer.
- **E**-Class II dimming electronic transformer (LIGHTECH part #LET 75 BF)
- **TOR**-Class H dimming toroidal transformer, providing 35% more lumens than traditional transformers. Constructed of M3 grade silicone steel.
(Must use dimmers rated for electromagnetic transformer)

BAR HANGERS - Preinstalled bar hangers allow housing to be positioned and locked at any point within a 24" joist span and can be shortened for 12" joists.

TYPE	WATTAGE	BALLAST	VOLTAGE	OPTION
BL3	<input type="checkbox"/> 20W	<input type="checkbox"/> M=Magnetic	<input type="checkbox"/> 120	<input type="checkbox"/> AT Air-Shut
	<input type="checkbox"/> 35W	<input type="checkbox"/> E=Electronic	<input type="checkbox"/> 277	
	<input type="checkbox"/> 50W	<input type="checkbox"/> TOR=Toroidal		
	<input type="checkbox"/> 75W			

Toroidal = Available only in 120V

They contain a double-headed real nail for secure attachment into the joist. Bar hanger nails are installed on a 20° downward angle for better contact, and the 90° pivoting mounting plate makes installation fast and accurate. Bar hangers can fit onto T-Bar spline with additional slots and holes for special mounting methods if necessary.

JUNCTION BOX - ETL listed for through-branch circuit wiring and has four 1/2" KOs, one 3/4" KO and four Romex knockouts with true pry-out slots and strain clamps.

ETL and C-ETL listed
For Damp location
For Feed-through wiring



OPTION

- AIR-SHUT-**
- Gasket to prevent air flow from heated or air conditioned spaces.**


- Meets all national air flow requirements.



5-1/2" HEIGHT FOR USE IN 2" X 6" JOIST CONSTRUCTION
TRANSFORMER CAN BE SERVICED FROM BELOW THE CEILING

DESCRIPTION

Small aperture, low voltage, thermally protected Non-IC rated, specification grade recessed housing designed for new construction. Non insulated ceilings or where insulation can be kept 3" from the housing. Accommodates up to 75W MR16 lamps.

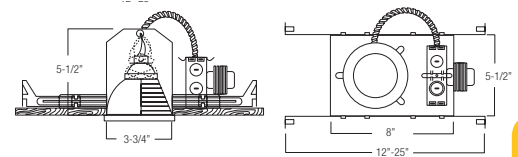

BL3R

3" MINIATURE LOW VOLTAGE NON-IC REMODEL HOUSING

SPECIFICATION

HOUSING - High temperature painted 22 gauge deep drawn single piece housing. Accommodates lamps up to 50W depending on trim used.

TRANSFORMER - Enhanced in heat dissipating cover, to provide noise free operation. Attached to junction box cover so it may be serviced from below the ceiling. Thermally protected.

- **M**-Class H dimming magnetic transformer.
- **E**-Class II dimming electronic transformer (LIGHTECH part #LET 75 BF)
- **TOR**-Class H dimming toroidal transformer, providing 35% more lumens than traditional transformers. Constructed of M3 grade silicone steel.
(Must use dimmers rated for electromagnetic transformer)

JUNCTION BOX - ETL listed for through-branch circuit wiring and has eight 1/2" KOs and four Romex knockouts with strain relief.

TYPE	WATTAGE	BALLAST	VOLTAGE	OPTION
BL3R	<input type="checkbox"/> 20W	<input type="checkbox"/> M=Magnetic	<input type="checkbox"/> 120	<input type="checkbox"/> AT Air-Shut
	<input type="checkbox"/> 35W	<input type="checkbox"/> E=Electronic	<input type="checkbox"/> 277	
	<input type="checkbox"/> 50W	<input type="checkbox"/> TOR=Toroidal		

Toroidal = Available only in 120V

INSTALLATION - Three preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".

ETL and C-ETL listed
For Damp location
For Feed-through wiring



OPTION:

- AIR-SHUT-**
- Gasket to prevent air flow from heated or air conditioned spaces.**


- Meets all national air flow requirements.



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

DESCRIPTION

Small aperture low voltage, thermally protected remodel housing. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Three remodel clips are easily retractable for fixture removal if necessary. Non insulated ceilings or where insulation can be kept 3" from the housing.

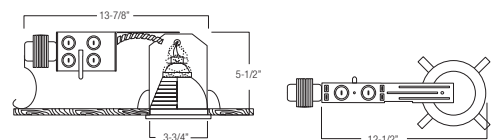

3 INCH LOW VOLTAGE NON-IC HOUSING


3" LOW VOLTAGE TRIMS

B1326CL-WH
The Illuminator II



Illuminator

AVAILABLE COLOR COMBINATIONS:
CL-WH, W-WH

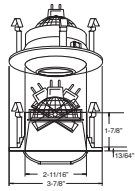


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1366CL-WH
The Illuminator



Illuminator

AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-SN

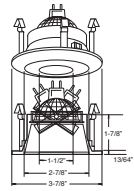


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1303WH
Slot Aperture



Apertura

TRIM:
WH, BK, CH, PB, CP,
SN, BZ

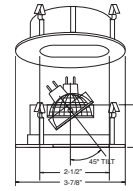


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1314P-WH
Pinhole with Baffle



Forte

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

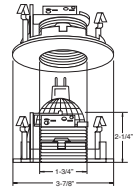


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1315RG-WH
Pinhole with Reflector



Forte

AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-SN, RG-WH,
MB-WH, W-WH, CP-CP

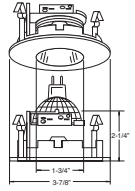


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1362WH
Shower Trim w/ Frosted Lens



Aqua

TRIM:
WH, BK, CH, PB, CP,
SN, BZ

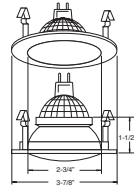

PATENT #: D510,151


HOUSING COMPATIBILITY GUIDE:
1 2 3 4

B1352WH
Shower Trim w/ Reflector



Aqua

AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-CH, CL-SN,
RG-WH, RG-PB,
MB-WH, SN-WH,
W-WH

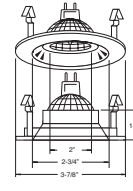


HOUSING COMPATIBILITY GUIDE:
1 2 3 4

B1306WH
Fully Adjustable (75° Tilt, 359° Rot.)



Galleria

TRIM:
WH, BK, CH, PB, CP,
SN, BZ

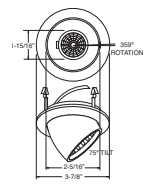


HOUSING COMPATIBILITY GUIDE:
1 2 4

B1312SN
Fully Adjustable (35° Tilt)



Galleria

TRIM:
WH, BK, CH, PB, CP,
SN, BZ

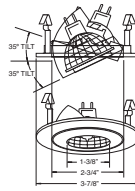


HOUSING COMPATIBILITY GUIDE:
1 2 3 4

B1368W-WH
Fully Adjustable w/ Baffle (35° Tilt)



Galleria

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

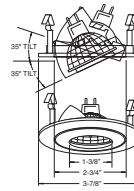


HOUSING COMPATIBILITY GUIDE:
1 2 3 4

B1304W-WH
Eyeball w/ Baffle (47° Tilt)



Galleria

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN

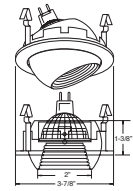


HOUSING COMPATIBILITY GUIDE:
1 2 3 4

B1377CL-WH
Crossblade Reflector



Radiance

AVAILABLE COLOR COMBINATION:
CL-WH

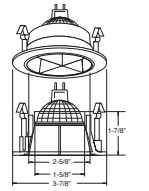


HOUSING COMPATIBILITY GUIDE:
1 2 3

B1313P-SN
Pull Down Adjustable



Galleria

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-SN,
CP-CP

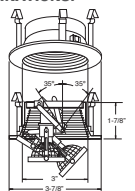

HOUSING COMPATIBILITY GUIDE:
1 2

ALL TRIMS ABOVE ARE PATENT PENDING

GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
1	BL3IC, BL3, BL3R	50W 12V MR16
2	BL3-75	75W 12V MR16
3	G3IC, G3, G3R	50W 120V GU10
4	BL30IC-E, BL3E-S, BL3RE-S	35W 12V MR16

BAFFLE FINISH:

- W** White
- P** Black
- SN** Satin Nickel
- CP** Copper
- BZ** Bronze

REFLECTOR FINISH:

- CL** Chrome
- RG** Gold
- W** White
- MB** Black

RING/TRIM FINISH:

- BZ** Bronze
- CP** Copper
- SHZ** Satin Haze
- WH** White
- BK** Black
- SN** Satin Nickel
- CP** Copper
- CH** Chrome
- PB** Polish Brass
- BZ** Bronze



General Lighting



Accent Lighting



Task Lighting



Wall Wash Lighting



Sloped Ceiling Lighting

3 INCH LOW VOLTAGE TRIMS

B1396CP 
Square Baffle w/ Square Trim Ring




Forte

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

PATENT PENDING

HOUSING COMPATIBILITY GUIDE:
1 2 3 4

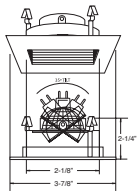

B1378SN-SN 
Stepped Baffle (35° Tilt)




Spectrum

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

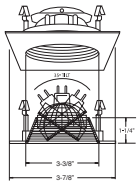

B1379CL-CH 
Reflector (35° Tilt)




Radiance

AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-CH, CL-SN,
RG-WH, SN-SN, SN-WH,
W-WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

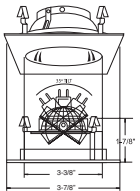

B1383WH 
Slot Aperture (35° Tilt)





Apertura

TRIM:
BZ, WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

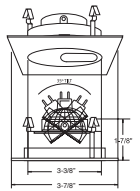

B1380WH 
Fully Adjustable (35° Tilt, 359° Rot.)





Galleria

TRIM:
WH, BK, BZ, CH, SN, CP

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

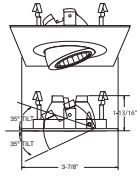

B1384P-WH 
Fully Adj. w/ Baffle (35° Tilt, 359° Rot.)





Galleria


AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

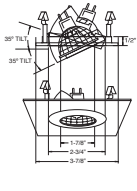

 B1386WH 
Fully Adjustable (75° Tilt, 359° Rot.)





Galleria

TRIM:
WH, BK, SN, BZ

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2

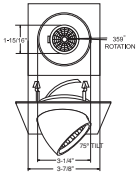

B1395CL-SN 
Semi-Frosted Shower Trim




FOR WET LOCATION

Aqua

AVAILABLE COLOR COMBINATIONS:
CL-BK, CL-SN, CL-WH,
CL-BZ, CP-CP, SN-SN

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

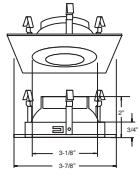

B1390WH-PEACH 
Metropolitan Ice Lite




GLASS:
BLUE, PEACH, FROSTED,
CLEAR, GREEN, AMBER

TRIM: WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

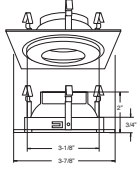

B1391P-WH 
Pinhole with Baffle




Forte

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

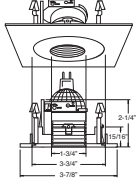

B1320WH-FROSTED 
Metropolitan Moon Lite




GLASS:
BLUE, PEACH, FROSTED,
CRYSTAL, GREEN, AMBER

TRIM: WH

PATENT #: D508,750

HOUSING COMPATIBILITY GUIDE:
1 2 3

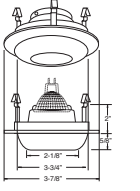

B1325WH-AMBER 
Metropolitan Step Lite




 
GLASS:
BLUE, PEACH, FROSTED,
CRYSTAL, GREEN, AMBER

TRIM: WH

PATENT #: D509,314

HOUSING COMPATIBILITY GUIDE:
1 2 3

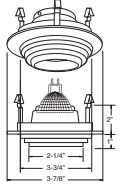

B1324WH-RED 
Metropolitan Honey Lite




GLASS:
BLUE, PEACH,
FROSTED, CRYSTAL,
GREEN, AMBER, RED

TRIM: WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

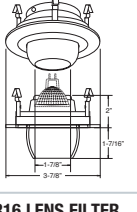

B1301CP-CP 
Stepped Baffle (35° Tilt)




Spectrum

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
CP-CP, SN-SN, BZ-BZ

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

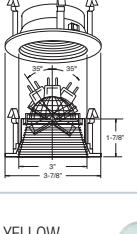

B1302CP-WH 
Reflector (35° Tilt)





Radiance

AVAILABLE COLOR COMBINATIONS:
CP-CP, CP-WH, W-WH,
RG-WH, SN-SN, SN-WH,
MB-WH, CL-WH, MB-BK,
RG-PB, CL-CH, CL-SN,
BZ-BZ

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

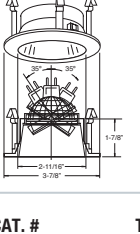

B1316CL-WH 
Reflector (35° Tilt)




Radiance

AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-SN, W-WH

PATENT #: D510,151

HOUSING COMPATIBILITY GUIDE:
1 2 3

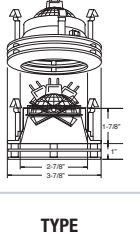

MR16 LENS FILTER
BP8MR16-BL BLUE
BP8MR16-GR GREEN
BP8MR16-PI PINK
BP8MR16-PU PURPLE
BP8MR16-DL DAY LIGHT

BP8MR16-YE YELLOW
BP8MR16-AM AMBER
BP8MR16-OR ORANGE
BP8MR16-RE RED



CAT. #
1. BP8MR16-FR FROSTED SPREAD
2. BP8MR16-SP SOFT FOCUS HONEY COMB
3. BP8MR16-SF
4. BP8MR16-HC

CAT. #
5. BP8MR16-LI LINEAR SOLITE
6. BP8MR16-SOL SOLITE
7. BP8MR16-CL CLEAR
8. BP8MR16-UV ULTRAVIOLET

ALL PRODUCTS ARE U.S. AND FOREIGN PATENT PENDING

WWW.IUSEELITE.COM • TEL: 1-877-375-5555 • FAX: 1-877-375-3333



3"

3 INCH LOW VOLTAGE TRIMS

3-inch Recessed Diamond Collection

NEW

The new crystal collection from Elite Lighting is more than just a trim, it's a form of art. Brilliant crystal jewels are aligned perfectly to provide a unique and sophisticated appearance to any space. Enhance the appearance of hallways, lobbies or waiting areas into an elegant appealing space. Different size crystals, along with a variety of colors make the Crystal Collection a beautiful masterpiece.

B1351CH
Ruby I



DESCRIPTION:

- All die-cast construction with enhanced clear crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1353CH
Ruby II



DESCRIPTION:

- All die-cast construction with enhanced clear crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1354CH
Sapphire I



DESCRIPTION:

- All die-cast construction with enhanced clear crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1355CH
Sapphire II



DESCRIPTION:

- All die-cast construction with enhanced clear crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1356CH
Emerald I



DESCRIPTION:

- All die-cast construction with enhanced color crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1357CH
Emerald II



DESCRIPTION:

- All die-cast construction with enhanced amber crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1358CH
Topaz I



DESCRIPTION:

- All die-cast construction with enhanced color crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1359CH
Topaz II



DESCRIPTION:

- All die-cast construction with enhanced color crystals
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



B1360CH
Onyx



DESCRIPTION:

- All die-cast construction with frosted glass
- Internal gasket prevents light leakage
- Chrome trim finish standard on all trims

HOUSING COMPATIBILITY GUIDE:

1 2 3 4



FINISH TRIM	TRIM OUTSIDE DIA.	GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
CH - Chrome	3-7/8"	1	BL3IC, BL3, BL3R	50W 12V MR16
		2	BL3-75	75W 12V MR16
		3	G3IC, G3, G3R	50W 120V GU10
		4	BL3ICE-S, BL30IC, BL3E-S, BL3RE-S	35W 12V MR16

