


BL20IC

2" Miniature Shallow Low Voltage "Noise-Free" IC Housing

LAMP WATTAGE: (1) MAXIMUM 12V 50W MR16



TRANSFORMER CAN BE SERVICED FROM BELOW THE CEILING

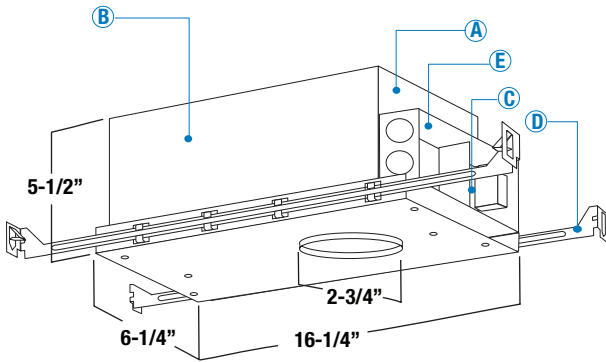

Catalog Number:	
Project Name:	Type:
Note:	

DESCRIPTION

Small aperture low voltage, thermally protected IC rated, specification grade recessed housing. Designed for new construction. Accommodates up to 50W MR16 lamps. Furnished with preinstalled adjustable bar hangers. Junction box is provided with four 1/2" KO's.

SPECIFICATION


A. OUTER HOUSING - Die-formed steel construction for maximum heat dissipating air chamber on top of the housing.

B. INNER HOUSING - Deep-drawn single piece aluminum construction for maximum heat dissipation and rust protection.

C. TRANSFORMER - Class II dimming electronic transformer enhanced in a small junction box. Transformer can be reached from inside housing.

D. BAR HANGERS - Preinstalled bar hangers allow housing to be positioned and locked at any point within a 24" joist span and can be shortened for 12" joists. They contain a double-headed real nail for secure attachment into the joist. Bar hanger nails are installed on a 20° downward angle for better contact, and the 90° pivoting mounting plate makes installation fast and accurate. Bar hangers can fit onto T-Bar spline with additional slots and holes for special mounting methods if necessary.

E. JUNCTION BOX - ETL listed for through-branch circuit wiring and has four 1/2" KOs

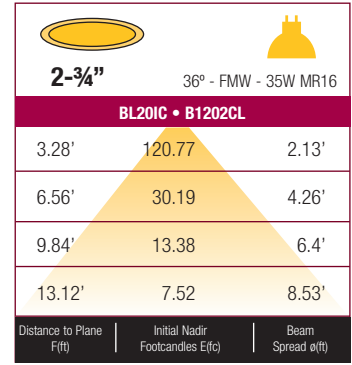

FEATURES

- Integral low voltage electronic transformer to prolong lamp life and increase lighting quality.
- Thermally Protected IC housing
- Designed for accent and task lighting applications
- Preinstalled adjustable bar hanger
- Dependable, favorable design and effortless installation

OPTIONS

1. AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

ETL AND C-ETL LISTED

For Damp location
For Feed-through wiring
For Direct contact with insulation



BL20IC - ITEM SELECTOR: (Please check the boxes below for the option desired)

WATTAGE	BALLAST	VOLTAGE	TRIM TYPE	BAFFLE	REFLECTOR	TRIM RING	MR 16 LENS FILTER
<input type="checkbox"/> 20W	<input type="checkbox"/> (E) Electronic	<input type="checkbox"/> 120	<input type="checkbox"/> B1214	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> BP8MR16-BL (Blue)
<input type="checkbox"/> 35W			<input type="checkbox"/> B1215	<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> BP8MR16-GR (Green)
<input type="checkbox"/> 50W			<input type="checkbox"/> B1201	<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> BP8MR16-PI (Pink)
			<input type="checkbox"/> B1202	<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> BP8MR16-PU (Purple)
			<input type="checkbox"/> B1203	<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> BP8MR16-DL (Day Light)
			<input type="checkbox"/> B1204		<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> BP8MR16-YE (Yellow)
			<input type="checkbox"/> B1209		<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> BP8MR16-AM (Amber)
			<input type="checkbox"/> B1212		<input type="checkbox"/> SHZ		<input type="checkbox"/> BP8MR16-OR (Orange)
			<input type="checkbox"/> B1213				<input type="checkbox"/> BP8MR16-RE (Red)
			<input type="checkbox"/> B1263				
			<input type="checkbox"/> B1262				
							<input type="checkbox"/> BP8MR16-FR (Frosted)
							<input type="checkbox"/> BP8MR16-SP (Spread)
							<input type="checkbox"/> BP8MR16-SF (Soft Focus)
							<input type="checkbox"/> BP8MR16-HC (Honey Comb)
							<input type="checkbox"/> BP8MR16-LI (Linear)
							<input type="checkbox"/> BP8MR16-SOL (Solite)
							<input type="checkbox"/> BP8MR16-CL (Clear)
							<input type="checkbox"/> BP8MR16-UV (Ultraviolet)

Specifications:

BL20IC WATT BALLAST VOLTAGE OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING FILTER (1) FILTER (2)

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.

Sample of Catalog Number: BL20IC-20W-E-B1201-W-WH-BP8MR16-BL



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-05-24-2011

2" Low Voltage Trims

(LAMP WATTAGE: 50W 12V MR16)

Catalog Number:


 
Project Name:

Type:

Note:




B1214P-BK
ADJUSTABLE STEPPED BAFFLE (35° TILT)

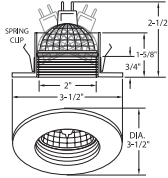



AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ

B1215RG-WH
ADJUSTABLE REFLECTOR (35° TILT)

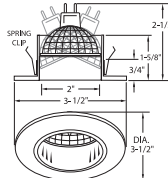


AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-WH, CL-WH, MB-BK, RG-PB, CL-CH

 B1201P-BK
REGRESSED STEPPED BAFFLE

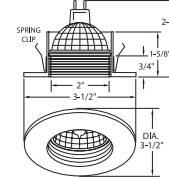


AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ

B1202RG-WH
REFLECTOR

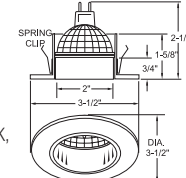


AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-WH, CL-WH, MB-BK, RG-PB, CL-CH

B1203BK
ADJUSTABLE SLOT APERTURE

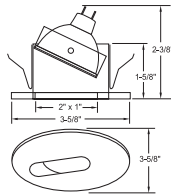


TRIM FINISH:
WH, BK, SN, CP, CH, PB, BZ

B1204PB
ADJUSTABLE EYEBALL WALL WASH (35° TILT)

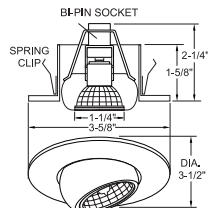



TRIM FINISH:
WH, BK, SN, CP, CH, PB, BZ

B1209CL-WH
CROSSBLADE REFLECTOR

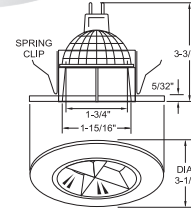



AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-BK, CL-CH

 B1212CP
ADJUSTABLE GIMBAL RING (35° TILT)

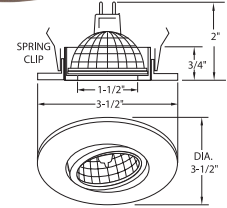


TRIM FINISH:
WH, BK, SN, CP, CH, PB, BZ

 B1213WH
ADJ. REGRESSED GIMBAL RING (35° TILT)

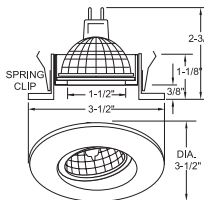


TRIM FINISH:
WH, BK, SN, CP, CH, PB, BZ

 B1263P-BK
BAFFLE SHOWER TRIM




FOR WET LOCATION

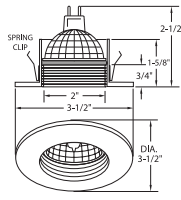


AVAILABLE COLOR COMBINATIONS:
CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ

 B1262RG-WH
REFLECTOR SHOWER TRIM



FOR WET LOCATION

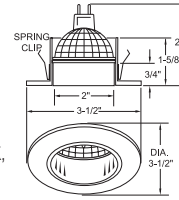

AVAILABLE COLOR COMBINATIONS:
CP-CP, W-WH, RG-WH, MB-WH, CL-WH, MB-BK, RG-PB, CL-CH

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: MAXLUME-SPEC-05-26-2011