

LED Instant Flexilight

The LED Instant Flexilight, 1/2" in diameter and rated at 100,000 hours, is the newest product in its family. Since we only use the highest-quality PVC material along with UV additives, the Instant Flexilight can be used in indoor or outdoor applications and can withstand both freezing and scorching weather.

The LED Instant Flexilight is very easy to use for a wide variety of design purposes, such as creating meaningful patterns in lighting projects; illuminating the edges of buildings, stairs, and other architectural features; or creating simple promotional signage.



No Driver Required

| | |
|------------------------|--|
| Number of wire | 2 |
| Number of bulb/foot | 12 |
| Diameter | 1/2" |
| Shape | Round |
| Colors available (PVC) | Clear: Red, Yellow, Blue, Green, Cool White, Warm White |



Specifications of LED Instant Flexilight:

| Structure | Voltage | Max. Loading Length (Color) | Cutting Unit (Color) | Bulb Spec. | Number of Bulbs/Unit | Wattage |
|-----------|----------|-----------------------------|----------------------|------------|----------------------|------------|
| | 110-120V | 600' (WW, CW, B, G) | 36" (WW, CW, B, G) | LED | 36 | 0.8W/foot |
| | | 900' (R, Y) | 54" (R, Y) | LED | 54 | 0.53W/foot |
| | 24V | 100' (WW, CW, B, G) | 6" (WW, CW, B, G) | LED | 6 | 0.88W/foot |
| | | 200' (R, Y) | 12" (R, Y) | LED | 12 | 0.44W/foot |
| | 12V | 50' (WW, CW, B, G) | 3" (WW, CW, B, G) | LED | 6 | 0.88W/foot |
| | | 100' (R, Y) | 6" (R, Y) | LED | 12 | 0.44W/foot |

Packages Available

No Driver Required/ Rectifier Included

| Item Number | Length | Package |
|----------------|--------|---------|
| ER-LED-120-150 | 150' | /Roll |
| ER-LED-24-150 | 150' | /Roll |
| ER-LED-12-150 | 150' | /Roll |

ER-LED - 120 - 150 - COLOR

Item No. Voltage Length Specify color

(Available in 150' Rolls only, no custom cut)


NOTE: Each Roll Includes; 3pcs ERIFL-XXX Power Cords, 3pcs F4 End Caps

| NOTE: | Cat# | LED Voltage | LED Length | Max. Wattage |
|--------------------------|-------------|-------------|------------|--------------|
| LED Magnetic Transformer | M100L-12-DC | 12V | 50' | 75w |
| | M100L-24-DC | 24V | 100' | 100w |

LED Instant Flexilight Accessories:

- ERIFL-F106 -120V LED Flexilight 6ft. Power Cord w/ Power Connector
- ERIFL-F107 -24V LED Flexilight 6ft. Power Cord w/ Power Connector
- ERIFL-F107 -12V LED Flexilight 6ft. Power Cord w/ Power Connector

ERIFL-F106

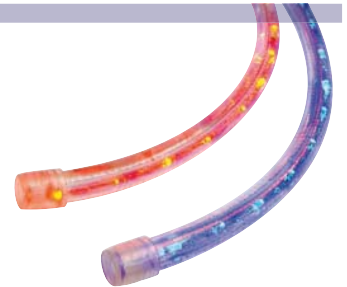

- F4 LED Flexilight End Caps
- F5 LED Flexilight Tie Strap
- F6 LED Flexilight Mounting Clip
- F7 LED Flexilight Suction Cup
- F8 LED Flexilight 6 ft. Channel
- F10 LED Flexilight Y-Cable Connector
- F14 Housing Clam for Splice Connector
- F103 LED Flexilight PVC Connector
- F22 LED Flexilight PVC T-Connector
- F23 LED Flexilight PVC X-Connector

F4



F5



F6



F7



F8



F10



F14



F22



F23



F103

