


4000
LUMENS

45
WATT

6000
LUMENS

70
WATT


* For list of qualified DLC fixture, please consult factory

APPLICATION

Parking structures, storage areas, shopping area walkways, entryway, and low level security

CONSTRUCTION

Low profile design. Sealed die-casting profile for indoor and outdoor applications

FINISH - black

CRI/CCT - CRI 75, 5000K

OPTICS - Frosted lens design guarantees zero glare at high angles




ELECTRICAL - Multiple voltage input is available, support 120-277V and 347-480V input. Three 1/2" threaded conduit and one 3/4" conduit entry points

INSTALLATION - Pendant mounting and direct surface mounting

LISTINGS - UL/cUL listed for wet locations.

WARRANTY - Limited 5 Year Warranty.

All specifications are subject to change without notice

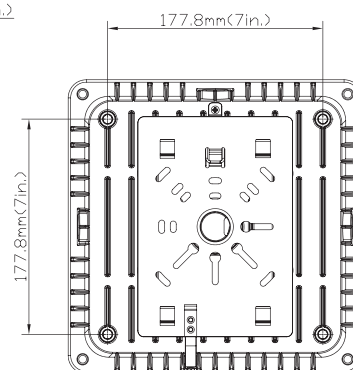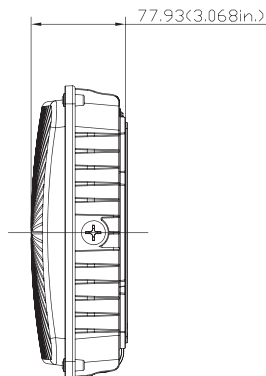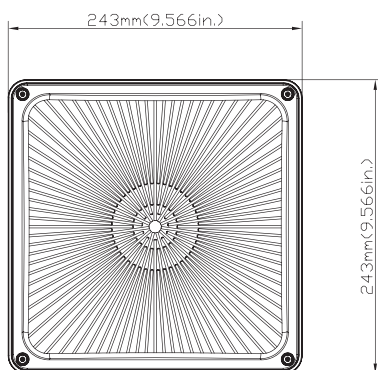

Ordering Information: Example: OVR-101-LED-6900L-MVOLT-75-40K-BK

OVR-101-LED
SERIES

OVR-101-LED

LUMENS
☐ 4000L
☐ 6000L

VOLTAGE

MVOLT

CRI

75

CCT
☐ 40K
☐ 50K

* For more CCT option, consult factory

FINISH
☐ BK - Black
☐ WH - White
☐ BZ - Bronze

For more finish option, consult factory