

















5" UNIVERSAL IC REMODEL HOUSING

INCANDESCENT LAMPS

IC20R

TRIMS/LAMPS

	Cat. No.	Description	Lamp Rating
	 215B-WH 215W-WH	BR30/PAR30 Black Baffle BR30/PAR30 White Baffle	65W BR30, 50W PAR30L, 75W PAR30 w/Socket Extender
	 216C-WH 216G-WH 216W-WH	Cone Clear Alzak® Cone Gold Alzak® Cone Gloss White	65W BR30, 50W PAR30L, 75W PAR30 w/Socket Extender, 40W A19
	 211-PW	Shower Trim	40W A19
	 212-WH 212-SC	Shower Trim Shower Trim	50W PAR30
	 201-WH	Open Frame	65W BR30
	 205B-WH 205B-PB 205W-WH	PAR30 Black Baffle PAR30 Black Baffle PAR30 White Baffle	50W PAR30
	 206C-WH 206G-WH 206B-WH	Cone Clear Alzak® Cone Gold Alzak® Cone Black Alzak®	50W PAR30
	 207C-WH 207G-WH 207B-WH 207W-WH	Cone Clear Alzak® Cone Gold Alzak® Cone Black Alzak® Cone Gloss White	50W PAR20/R20
	 208B-WH 208B-PB 208W-WH	Eyeball with Black Baffle Eyeball with Black Baffle Eyeball with White Baffle	50W PAR20/R20
	 209-WH	Gimbal Ring with Flat Trim	75W PAR30
	 688B-WH 688W-WH	Gimbal Ring with Black Baffle Gimbal Ring with White Baffle	50W PAR30
	 689C-WH 689G-WH	Gimbal Ring in Clear Cone Gimbal Ring in Gold Cone	50W PAR30

Trim Size: 6¼" O.D.

Trim Finish: WH - White, PB - Polished Brass, PW - Plastic White (for showers).

Alzak is a registered trademark of Alcoa Corp.

Note: In Canada when insulation is present, Type IC fixtures must be used.

 When the Air-Loc® symbol appears next to a trim, no gasket is required when used with IC Housing.



JUNO lighting

1300 S. Wolf Road, P.O. Box 5065, Des Plaines, IL 60017-5065 Phone 847.827.9880 FAX 847.827.2925

220 Chrysler Dr., Brampton, Ontario, Canada, L6S 6B6 Phone 905.792.7335 FAX 905.792.0064

Visit us at www.junolighting.com

Printed in U.S.A. ©2002 Juno Lighting, Inc.

JUNO® lighting

Project: _____

Fixture Type: _____

Location: _____


Contact/Phone: _____

5" UNIVERSAL IC REMODEL HOUSING

INCANDESCENT LAMPS

IC20R

PRODUCT DESCRIPTION

IC Remodel Housing Air-Loc® Ready • Energy efficient, sealed housing • IC Remodel Housing for remodel application where back side of ceiling is not accessible • Installs through an opening in the ceiling from below • Secured in place by factory installed remodel springs • Can be completely covered with insulation • When used with Air-Loc Gasket (see accessories), stops infiltration and exfiltration of air, reducing heating and cooling costs • Trims shown with Air-Loc symbol  do not require gasket.

PRODUCT SPECIFICATIONS

Lamp Lamp ratings based on trim selected—see reverse.

Socket Medium base porcelain with nickel-plated copper screw shell • Drop socket with spring to accommodate certain trim installation.

Trims Trim selection shown on reverse.

Labels U.L. listed for through-branch wiring, damp locations and IP • Product thermally protected against improper use of lamps • Union made AFL-CIO • Trims 211 and 212 are wet location approved for covered ceiling applications • UL Listed/CSA certified.

Testing All reports are based on published industry procedures; field performance may differ from laboratory performance.



Product specifications subject to change without notice.

INSTALLATION

Junction Box Pre-wired junction box, UL listed/CSA certified for through-branch wiring maximum 4 No. 12 AWG 90° C branch circuit conductors (2 in, 2 out) • Junction box provided with removable access plate, (5) 1/2" knockouts and ground wire • Knockouts equipped with pryout slots.

Housing IC housing, .032" aluminum sealed for Air-Loc Ready.

DIMENSIONS

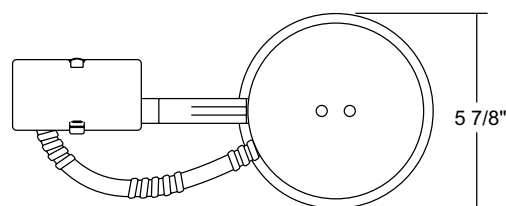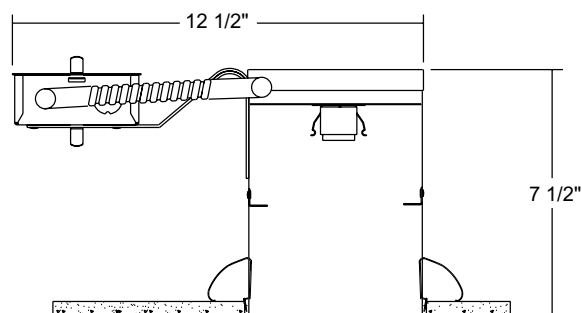

5 1/2" CEILING CUTOUT

ACCESSORIES

Catalog No.	Description
ALG5R	Air-Loc Gasket

To order, specify catalog number.

PRODUCT CODES

Catalog Number	Input Voltage	Lamp Rating (max.)
IC20R	120V	A19/BR30/PAR20/PAR30/PAR30L/R20/R30 (See reverse for max. trim rating)