

# TRAC-MASTER®

Mounting Accessories

## MONOPOINTS and SPECIAL MOUNTINGS

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

 
Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_


### PRODUCT DESCRIPTION

Special adapters permit the flexibility of mounting trac lights in various ways to meet special requirements.


### Line Voltage Monopoint Adapters



 
**T40WH, T40BL, T40SL**  
Monopoint Adapter. Mounts directly to outlet box. Accepts one 120V Juno trac fixture with standard size trac adapter.




**T40F-WH, T40F-BL, T40F-SL**  
Flush Monopoint Adapter. Mounts directly to 4" outlet box only. Accepts one 120V Juno trac fixture with standard size trac adapter.

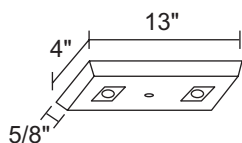

 
**T41WH, T41BL, T41SL**  
Duo-Point Adapter. Mounts directly to an outlet box. Accepts two 120V Juno trac fixtures with standard size trac adapter.



 
**T43WH, T43BL, T43SL**  
Monopoint Adapter for use with fixtures with wide trac adapter. Mounts directly to outlet box. For ceiling mount installations only.



 
**T42WH, T42BL**  
Weighted Base. For portable use. Supplied with 8' cord and plug. Accepts one 120V Juno trac fixture with standard size trac adapter.



**T46**  
Clamp/Monopoint Adapter. Clamps to pipe or planking up to 2 1/2" thick. Accepts 120V Juno trac fixture with standard size trac adapter. Supplied with 8' three-wire cord and plug.

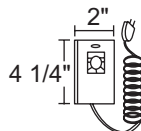

 
**T45WH, T45BL**  
Pin-Up/Monopoint Adapter. Supplied with 8' cord and plug. Accepts one 120V Juno trac fixture with standard size trac adapter.



**T57WH**  
Monopoint Line Voltage Cover. Attaches one 120V trac fixture with standard size trac adapter directly to Juno's 6" recessed universal housings.

### Line Voltage Coil - Cord Clamp-Ons

2' Coil Cord extends to 5'. 1-3/4" Clamp opening.

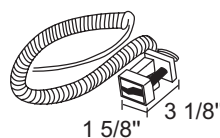

**T132WH, T132BL**  
120V Monopoint with trac adapter for electrical connection to Trac. Accepts one 120V Juno trac fixture with standard size trac adapter.

**T132WA-WH, T132WA-BL**  
Same as above but accepts one 120V Juno trac fixture with wide trac adapter.

**T133WH, T133BL**  
120V Monopoint with male plug (120V) attaches to receptacle. Accepts one 120V Juno trac fixture with standard size trac adapter. 2'

**T133WA-WH, T133WA-BL**  
Same as above but accepts one 120V Juno trac fixture with wide trac adapter.

### Line Voltage Extension Wands

**TW12, TW18, TW24, TW36, TW48**

Line Voltage Extension Wands (12", 18", 24", 36", 48") - For use with one or two circuit trac and line voltage monopoints. Accepts one 120V Juno trac fixture with standard size trac adapter. WH, BL, SL




**TW12WA, TW18WA, TW24WA, TW36WA, TW48WA**  
Same as above but accepts one 120V Juno trac fixture with wide trac adapter. WH, BL, SL

**TWS24WH, TWS24BL, TWS24SL**  
24" Wand with Slope Adapter. Accepts one 120V Juno trac fixture with standard size trac adapter.

**TWS24WA-WH, TWS24WA-BL, TWS24WA-SL**  
Same as above but accepts one 120V Juno trac fixture with wide trac adapter.

### Line Voltage Sloped Ceiling Adapter

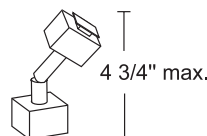


**T95WH, T95BL, T95SL**  
Sloped Ceiling Adapter. Attaches to trac, permitting Trac-Master or Trac-Lites Trac fixtures with standard size trac adapter to be hung vertically from sloped ceiling. 90° maximum adjustable.


**T95WA-WH, T95WA-BL, T95WA-SL**  
Same as above but accepts one 120V Juno trac fixture with wide trac adapter.

**TRAC-MASTER®**


Mounting Accessories

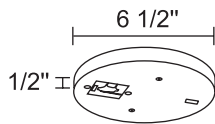**MONOPOINTS  
and SPECIAL MOUNTINGS****Low Voltage Monopoint Adapters**

 
**T58WH, T58BL, T58SL**  
Monopoint Adapter for T537, T538 or Trac-Lites R Series Low-Voltage Power Packs. Mounts directly to outlet box. Adapter is offset to accept all Power Pack styles. Power Pack latch locks in detent.




**T539WH**  
Monopoint Low Voltage Cover. Contains integral electronic transformer. Designed to accept one Juno 12V halogen low voltage trac spotlight directly to Juno's 6" recessed universal housings.

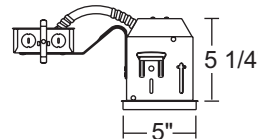**Low Voltage Recessed Monopoint Adapters**

 
**T542WH**  
Monopoint Power Pack (recessed) for remodel construction. TC housing. Includes 50VA-12V magnetic transformer, wiring box, canopy and thermal protector. Designed to accept one Juno 12V halogen low voltage trac spotlight.



**T543WH**  
Monopoint Power Pack (recessed) for new construction. TC housing. Includes 50VA-12V magnetic transformer, pre-wired recessed housing, canopy, adjustable bar hangers and thermal protector. Designed to accept one Juno 12V halogen low voltage trac spotlight.

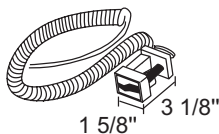**Low Voltage Coil - Cord Clamp-Ons**

 
**T135WH, T135BL**  
12V Low Voltage Monopoint attaches to T537 or T538. 2' Coil Cord extends to 5'. Accepts one Juno 12V low voltage spotlight.

**Low Voltage Extension Wands**

**TWL12, TWL18, TWL24, TWL36, TWL48**  
Low Voltage Extension Wands (12", 18", 24", 36", 48") - Accepts one Juno 12V low voltage spotlight. Attaches to T537 or T538 Power Pack. WH, BL, SL

**MH<sub>2</sub> CMH Extension Wands**

 **TMW12, TMW18, TMW24, TMW36, TMW48**  
Extension Wands. Accepts one MH<sub>2</sub> CMH Trac fixture. Attaches to TM Series Ballast or Monopoint. WH, BL, SL



**TWLED12, TWLED18, TWLED24, TWLED36, TWLED48**  
T252L Extension Wands (12", 18", 24", 36", 48") - Attaches between T252L fixture housing and LED driver housing to move the light source closer to illumination point without lowering the trac mounting height. WH, BL, SL

Product specifications subject to change without notice.



JUNO LIGHTING GROUP  
by Schneider Electric

1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925  
220 Chrysler Drive • Brampton, Ontario • Canada L6S 6B6 • Phone (905) 792-7335 • Fax (905) 792-0064  
Visit us at [www.junolightinggroup.com](http://www.junolightinggroup.com)

Printed in U.S.A. ©2014 Juno Lighting, LLC.